
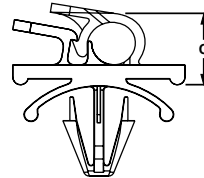


c[®] Latching Wire Clips

- Route and secure cords and cables
- Convenient releasable latch
- Available in six sizes with releasable latch
- Push barb parts are for use with a max panel thickness of 0.11" (2.7mm) and a hole diameter of 0.22" (5.6mm)
- For indoor use only
- Material: Nylon 6.6

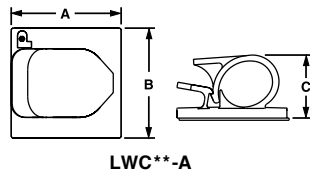

LWC**-A

LWC**-H25

| Part Number | Max. Bundle Diameter | | Length | | Width | | Height | | Color | Mounting Method | Std. Pkg. Qty. | Std. Ctn. Qty. |
|------------------------|----------------------|------|--------|------|-------|------|--------|------|---------|-----------------|----------------|----------------|
| | In. | mm | In. | mm | In. | mm | In. | mm | | | | |
| Adhesive Backed | | | | | | | | | | | | |
| LWC19-A-C | 0.19 | 4.8 | 0.85 | 21.6 | 0.61 | 15.5 | 0.39 | 9.9 | Natural | Rubber Adhesive | 100 | 1000 |
| LWC19-A-C14 | 0.19 | 4.8 | 0.85 | 21.6 | 0.61 | 15.5 | 0.39 | 9.9 | Gray | | 100 | 1000 |
| LWC19-A-C20 | 0.19 | 4.8 | 0.85 | 21.6 | 0.61 | 15.5 | 0.39 | 9.9 | Black | | 100 | 1000 |
| LWC25-A-C | 0.25 | 6.4 | 0.88 | 22.2 | 1.00 | 25.4 | 0.45 | 11.4 | Natural | | 100 | 1000 |
| LWC25-A-C14 | 0.25 | 6.4 | 0.88 | 22.2 | 1.00 | 25.4 | 0.45 | 11.4 | Gray | | 100 | 1000 |
| LWC25-A-C20 | 0.25 | 6.4 | 0.88 | 22.2 | 1.00 | 25.4 | 0.45 | 11.4 | Black | | 100 | 1000 |
| LWC38-A-C | 0.38 | 9.5 | 1.00 | 25.4 | 1.00 | 25.4 | 0.56 | 14.2 | Natural | | 100 | 1000 |
| LWC38-A-C14 | 0.38 | 9.5 | 1.00 | 25.4 | 1.00 | 25.4 | 0.56 | 14.2 | Gray | | 100 | 1000 |
| LWC38-A-C20 | 0.38 | 9.5 | 1.00 | 25.4 | 1.00 | 25.4 | 0.56 | 14.2 | Black | | 100 | 1000 |
| LWC50-A-L | 0.50 | 12.7 | 1.26 | 32.0 | 1.00 | 25.4 | 0.67 | 17.0 | Natural | | 50 | 1000 |
| LWC50-A-L14 | 0.50 | 12.7 | 1.26 | 32.0 | 1.00 | 25.4 | 0.67 | 17.0 | Gray | | 50 | 1000 |
| LWC50-A-L20 | 0.50 | 12.7 | 1.26 | 32.0 | 1.00 | 25.4 | 0.67 | 17.0 | Black | | 50 | 1000 |
| LWC75-A-L | 0.75 | 19.1 | 1.48 | 37.6 | 1.24 | 31.5 | 0.90 | 22.9 | Natural | | 50 | 1000 |
| LWC75-A-L14 | 0.75 | 19.1 | 1.48 | 37.6 | 1.24 | 31.5 | 0.90 | 22.9 | Gray | | 50 | 1000 |
| LWC75-A-L20 | 0.75 | 19.1 | 1.48 | 37.6 | 1.24 | 31.5 | 0.90 | 22.9 | Black | | 50 | 1000 |
| LWC100-A-L | 1.00 | 25.4 | 2.21 | 56.1 | 1.97 | 50.0 | 1.26 | 32.0 | Natural | | 50 | 1000 |
| LWC100-A-L14 | 1.00 | 25.4 | 2.21 | 56.1 | 1.97 | 50.0 | 1.26 | 32.0 | Gray | | 50 | 1000 |
| LWC100-A-L20 | 1.00 | 25.4 | 2.21 | 56.1 | 1.97 | 50.0 | 1.26 | 32.0 | Black | | 50 | 1000 |
| Push Mount | | | | | | | | | | | | |
| LWC19-H25-C | 0.19 | 4.8 | 0.85 | 21.6 | 0.51 | 12.8 | 0.41 | 10.4 | Natural | Push Barb | 100 | 1000 |
| LWC19-H25-C14 | 0.19 | 4.8 | 0.85 | 21.6 | 0.51 | 12.8 | 0.41 | 10.4 | Gray | | 100 | 1000 |
| LWC25-H25-C | 0.25 | 6.4 | 0.86 | 21.8 | 0.58 | 14.7 | 0.47 | 11.9 | Natural | | 100 | 1000 |
| LWC25-H25-C14 | 0.25 | 6.4 | 0.86 | 21.8 | 0.58 | 14.7 | 0.47 | 11.9 | Gray | | 100 | 1000 |
| LWC25-H25-C20 | 0.25 | 6.4 | 0.86 | 21.8 | 0.58 | 14.7 | 0.47 | 11.9 | Black | | 100 | 1000 |
| LWC38-H25-C | 0.38 | 9.5 | 0.94 | 23.9 | 0.58 | 14.7 | 0.57 | 14.5 | Natural | | 100 | 1000 |
| LWC38-H25-C14 | 0.38 | 9.5 | 0.94 | 23.9 | 0.58 | 14.7 | 0.57 | 14.5 | Gray | | 100 | 1000 |
| LWC38-H25-C20 | 0.38 | 9.5 | 0.94 | 23.9 | 0.58 | 14.7 | 0.57 | 14.5 | Black | | 100 | 1000 |
| LWC50-H25-L | 0.50 | 12.7 | 1.25 | 31.8 | 0.76 | 19.3 | 0.78 | 19.8 | Natural | | 50 | 1000 |
| LWC50-H25-L14 | 0.50 | 12.7 | 1.25 | 31.8 | 0.76 | 19.3 | 0.78 | 19.8 | Gray | | 50 | 1000 |
| LWC50-H25-L20 | 0.50 | 12.7 | 1.25 | 31.8 | 0.76 | 19.3 | 0.78 | 19.8 | Black | | 50 | 1000 |
| LWC75-H25-L | 0.75 | 19.1 | 1.45 | 36.8 | 0.87 | 22.1 | 0.97 | 24.7 | Natural | | 50 | 1000 |
| LWC75-H25-L14 | 0.75 | 19.1 | 1.45 | 36.8 | 0.87 | 22.1 | 0.97 | 24.7 | Gray | | 50 | 1000 |
| LWC75-H25-L20 | 0.75 | 19.1 | 1.45 | 36.8 | 0.87 | 22.1 | 0.97 | 24.7 | Black | | 50 | 1000 |
| LWC100-H25-L | 1.00 | 25.4 | 1.89 | 47.9 | 0.99 | 25.2 | 1.30 | 33.0 | Natural | | 50 | 1000 |
| LWC100-H25-L14 | 1.00 | 25.4 | 1.89 | 47.9 | 0.99 | 25.2 | 1.30 | 33.0 | Gray | | 50 | 1000 |
| LWC100-H25-L20 | 1.00 | 25.4 | 1.89 | 47.9 | 0.99 | 25.2 | 1.30 | 33.0 | Black | | 50 | 1000 |