




PANDUIT P/N	WEIGHT
P24B14M	10.8kg

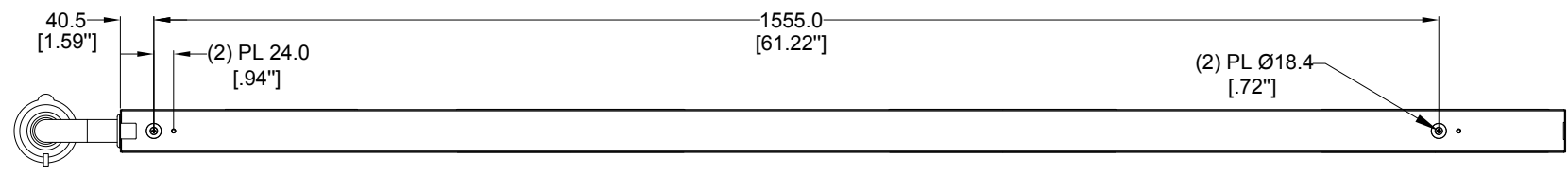

REAR VIEW

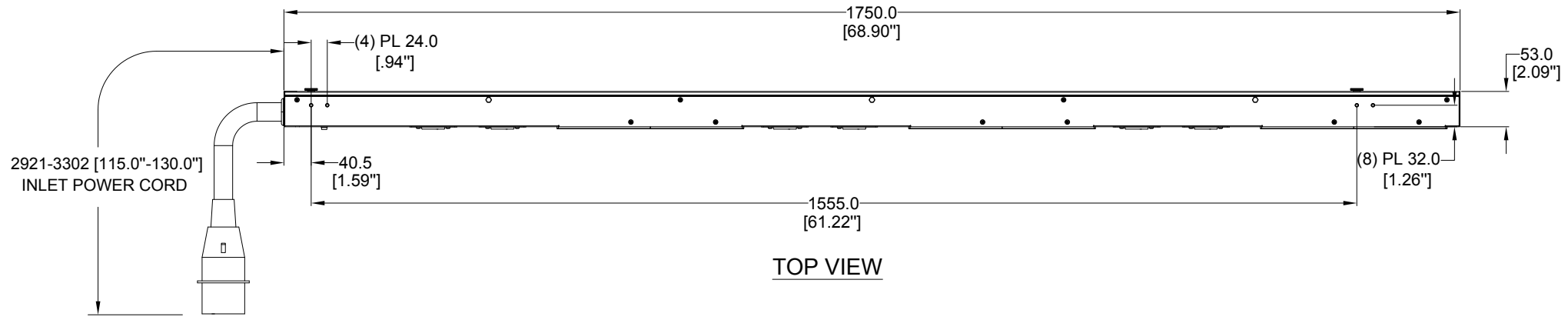

TOP VIEW

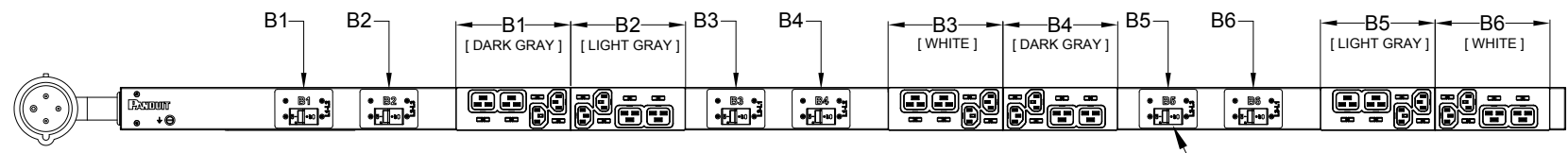


FRONT VIEW

20 AMP, DOUBLE - POLE
ELECTRO MECHANICAL
SWITCH / BREAKER (6) PLACES


NOTES:

- IDENTIFICATION:


UNIT TYPE:	BASIC
ORIENTATION:	VERTICAL, 0U FULL
OUTLET QTY&TYPE:	(12) C13, (12) C19
BREAKER QTY&TYPE:	(6) 20AMP, DOUBLE-POLE
INPUT VOLTAGE:	200-240VAC, DELTA
INPUT CURRENT:	60A (48A DERATED)
INPUT PHASE:	THREE-PHASE DELTA
RATED POWER:	17.3kVA
INPUT PLUG:	IEC 60309 3P+E 9H 60A
INPUT CORD LENGTH:	3m [10']
- ACCESSORIES:
POCKET GUIDE
- RoHS COMPLIANT
- VISIT PANDUIT'S ON-LINE CATALOG AT WWW.PANDUIT.COM FOR ADDITIONAL PRODUCT INFORMATION CONTAINED IN THE SPECIFICATION SHEET AS WELL AS A CURRENT LIST OF PRODUCTS APPLICABLE FOR USE WITH THIS PART
- MAXIMUM ALLOWABLE INPUT POWER = 17.3 kW
- INSTALLATION SHALL COMPLY WITH ALL APPLICABLE NATIONAL, STATE, AND LOCAL CODES

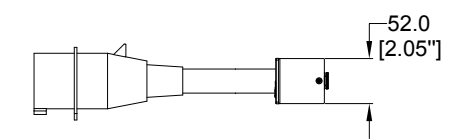


SIDE VIEW

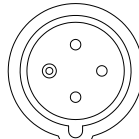

PLUG
60 AMP, 250V x 3~ DELTA
3P/4W
IEC 60309, SPLASHPROOF, IP44
2G (S); 2W (W), 9H;

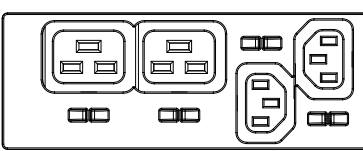

TWELVE (12)
RECEPTACLES
16 AMP, 250V
STRAIGHT BLADE
IEC 60320/C19



TWELVE (12)
RECEPTACLES
10 AMP, 250V
STRAIGHT BLADE
IEC 60320/C13

REV	DATE	BY	CHK	APR	DESCRIPTION	ECN
01B	08/21/2017	KUN	MIM	EDM	REVISED TOLERANCES	P24B14M
01A	06/28/2017	KUN	MIM	EDM	INITIAL RELEASE	P24B14M

WE ASK THAT YOU CHECK FULLY THE DIMENSIONS, NOTES, AND SIGN THE CLIENT SIGNATURE BOX. THE JOB WILL NOT PROGRESS WITHOUT SIGNED APPROVAL. PLEASE DO NOT DELAY IN RETURNING PROOF AS IT WILL AFFECT DELIVERY		SIGN
		DATE
		PRINT
TITLE: BASIC SERIES PDU P24B14M CUSTOMER DRAWING		
ITEM REVISION NAME:		
DATASHEET FILE NAME:		
UNLESS OTHERWISE SPECIFIED DIMENSIONAL TOLERANCE ARE: mm [IN]		MATERIAL/COLOR:
Tolerance(mm)		N/A
0.4<L<50 ±0.5		DRAWING NUMBER:
50<L<250 ±1.0		P24B14M_DC
250<L<500 ±1.5		SHT 1 OF 1
500<L<1000 ±2.5		SCALE
1000<L<2000 ±4.0		B
DRAWN BY	DATE	CHK
KUN	05/24/2017	SEAN
SCALE	NONE	