

THIS COPY IS PROVIDED ON A RESTRICTED BASIS AND IS NOT TO BE USED IN ANY WAY DETRIMENTAL TO THE INTERESTS OF PANDUIT CORP.

PANDUIT P/N	WEIGHT
P24G05M-XXYZ	SEE SHEET 2

SPECIFICATION:

1. STANDARD:	UNIT TYPE: MONITORED & SWITCHED PER OUTLET
	ORIENTATION: VERTICAL, 0U FULL
	OUTLET QTY&TYPE: (12) C13, (12) C19
	INPUT VOLTAGE: 200-240VAC
	INPUT CURRENT: 60A (48A DERATED)
	BREAKER QTY&TYPE: (6) 20AMP, DOUBLE-POLE
	INPUT PHASE: THREE-PHASE DELTA
	RATED POWER: 17.3kVA
	INPUT PLUG: IEC 60309 3P+E 9H 60A
	INPUT POWER CORD: SEE SHEET 2 FOR NUMBER TABLE
	REGULATORY STANDARD: RoHS COMPLIANT

2. ADDITIONAL:

NONE

3. ACCESSORIES:

(1) QUICK-START GUIDE


NOTES:

1. PRIMARY DIMENSIONS ARE IN MILLIMETERS. SECONDARY DIMENSION ARE IN [INCHES]
2. INSTALLATION SHALL COMPLY WITH ALL APPLICABLE NATIONAL, STATE, AND LOCAL CODES
3. VISIT OUR ON-LINE CATALOG AT WWW.PANDUIT.COM FOR A CURRENT LIST OF PRODUCTS APPLICABLE FOR USE WITH THIS PART
4. FOR FULL PRODUCT FUNCTIONALITY REFER TO USER MANUAL
5. DRAWING VIEWS SHOW THE INPUT CORD IN THE "TOP END FED" CONFIGURATION


IDENTIFICATION

FOR FINISHED GOOD PART NUMBER & DESCRIPTION TABLE SEE SHEET 2 CONFIGURABLE PART NUMBERS: P24G05M-XX Y Z

XX: FINISHED GOOD COLOR BL=BLACK RD=RED WH=WHITE YL=YELLOW BU=BLUE GN=GREEN	Y: INPUT FEED TYPE 1=TOP-END FED 2=BOTTOM-END FED	Z: INPUT CORD LENGTH A=1 METER B=2 METER C=3 METER
---	---	---

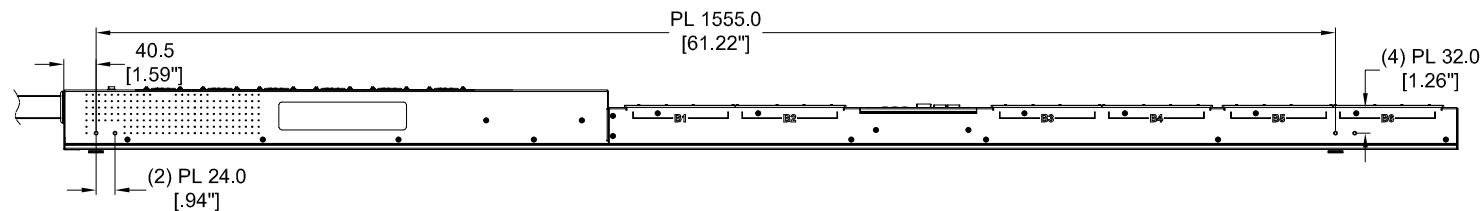


LEFT VIEW

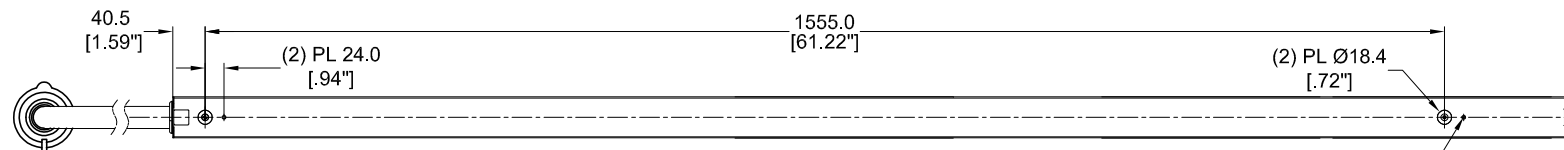


REAR VIEW

TOOLESS MOUNTING
BUTTON LOCATIONS (12) PL

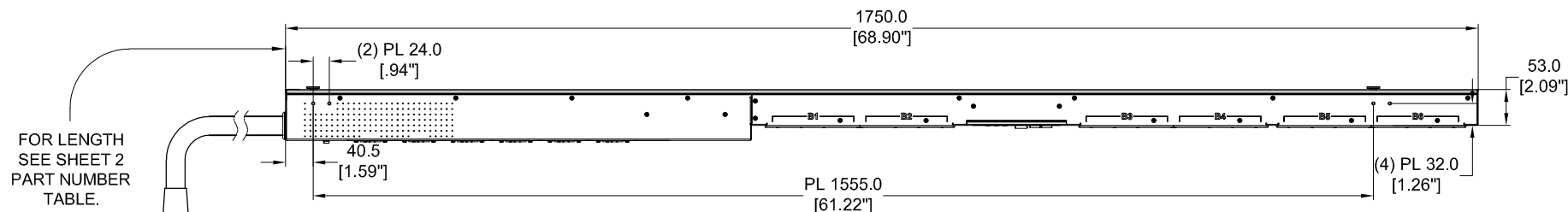

RIGHT VIEW

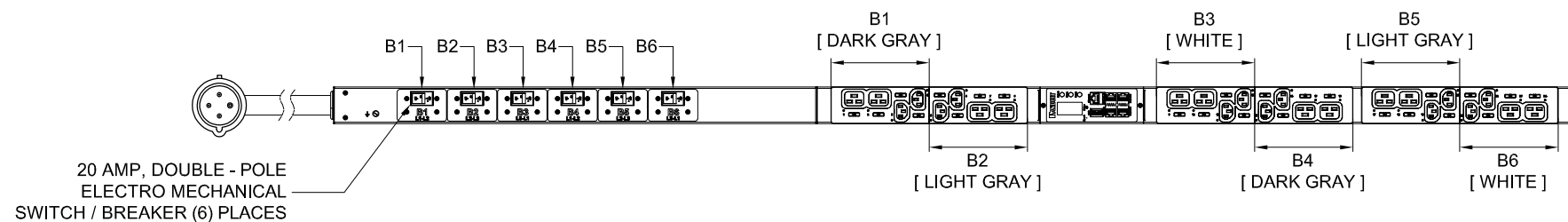


FRONT VIEW

BOTTOM VIEW

PLUG/RECEPTACLE BLOCK



 PLUG
IEC 60309, 3P 4W, 9H
IP44 (SPASHPROOF)
60A, 250V, 3-PHASE MAX RATED INPUT
48A DERATED



RECEPTACLES
IEC 60320/C19
16A, 250V MAX RATED OUTPUT



RECEPTACLES
IEC 60320/C13
10A, 250V MAX RATED OUTPUT

REV	DATE	BY	CHK	APR	DESCRIPTION	ECN
02A	06/07/2018	H.XU	MIM	JAWI	ADDED SHEET 2 WITH CONFIGURABLE PART NUMBER TABLE AND DESCRIPTION UPDATED IDENTIFICATION TO INCLUDE CONFIGURABLE OPTION DE-CODER UPDATED CIRCUIT BREAKER LABELS WITH ROTATED TEXT	P24G05M
01A	08/23/2017	GEORGE	MIM	EDM	INITIAL RELEASE	P24G05M

WE ASK THAT YOU CHECK FULLY THE DIMENSIONS, NOTES, AND SIGN THE CLIENT SIGNATURE BOX. THE JOB WILL NOT PROGRESS WITHOUT SIGNED APPROVAL. PLEASE DO NOT DELAY IN RETURNING PROOF AS IT WILL AFFECT DELIVERY	SIGN DATE PRINT
TITLE INTELLIGENT SERIES PDU P24G05M-XXYZ CUSTOMER DRAWING	
ITEM REVISION NAME: DATASHEET FILE NAME:	
UNLESS OTHERWISE SPECIFIED DIMENSIONAL TOLERANCE ARE: mm [IN] Tolerance(mm) 0<L<50 ±0.5 50<L<250 ±1.0 250<L<500 ±1.5 500<L<1000 ±2.5 1000<L<2000 ±4.0 THIRD ANGLE PROJECTION	MATERIAL/COLOR: N/A DRAWING NUMBER: P24G05M_DC
DRAWN BY: DATE: 08/23/2017 CHK: SEAN SCALE: NONE	SHT 1 OF 2 SCALE: B

2



1

THIS COPY IS PROVIDED ON A RESTRICTED BASIS AND IS NOT TO BE USED IN ANY WAY DETRIMENTAL TO THE INTERESTS OF PANDUIT CORP.

FINISHED GOOD PART NUMBER	FINISHED GOOD DESCRIPTION	COLOR	INPUT CORD LENGTH	WEIGHT
P24G05M	VERTICAL,(12) C13,(12) C19,MONITORED&SWITCHED PER OUTLET, 200-240V/60A/3 PHASE DELTA , TOP-END FED, 3 METER INPUT CORD, BLACK	BLACK (RAL 9005)	3M(+254MM-127MM) 10' [+10"/-5"]	13.9kg
P24G05M-BL1A	VERTICAL,(12) C13,(12) C19,MONITORED&SWITCHED PER OUTLET, 200-240V/60A/3 PHASE DELTA , TOP-END FED, 1 METER INPUT CORD, BLACK	BLACK (RAL 9005)	1M(+178MM-89MM) 3.3' [+3.5"/-1.75"]	11.3kg
P24G05M-BL1B	VERTICAL,(12) C13,(12) C19,MONITORED&SWITCHED PER OUTLET, 200-240V/60A/3 PHASE DELTA , TOP-END FED, 2 METER INPUT CORD, BLACK	BLACK (RAL 9005)	2M(+178MM-89MM) 6.5' [+7"/-3.5"]	12.6kg
P24G05M-RD1A	VERTICAL,(12) C13,(12) C19,MONITORED&SWITCHED PER OUTLET, 200-240V/60A/3 PHASE DELTA , TOP-END FED, 1 METER INPUT CORD, RED	RED (RAL 3020)	1M(+178MM-89MM) 3.3' [+3.5"/-1.75"]	11.3kg
P24G05M-RD1B	VERTICAL,(12) C13,(12) C19,MONITORED&SWITCHED PER OUTLET, 200-240V/60A/3 PHASE DELTA , TOP-END FED, 2 METER INPUT CORD, RED	RED (RAL 3020)	2M(+178MM-89MM) 6.5' [+7"/-3.5"]	12.6kg
P24G05M-RD1C	VERTICAL,(12) C13,(12) C19,MONITORED&SWITCHED PER OUTLET, 200-240V/60A/3 PHASE DELTA , TOP-END FED, 3 METER INPUT CORD, RED	RED (RAL 3020)	3M(+254MM-127MM) 10' [+10"/-5"]	13.9kg
P24G05M-WH1A	VERTICAL,(12) C13,(12) C19,MONITORED&SWITCHED PER OUTLET, 200-240V/60A/3 PHASE DELTA , TOP-END FED, 1 METER INPUT CORD, WHITE	WHITE (RAL 9003)	1M(+178MM-89MM) 3.3' [+3.5"/-1.75"]	11.3kg
P24G05M-WH1B	VERTICAL,(12) C13,(12) C19,MONITORED&SWITCHED PER OUTLET, 200-240V/60A/3 PHASE DELTA , TOP-END FED, 2 METER INPUT CORD, WHITE	WHITE (RAL 9003)	2M(+178MM-89MM) 6.5' [+7"/-3.5"]	12.6kg
P24G05M-WH1C	VERTICAL,(12) C13,(12) C19,MONITORED&SWITCHED PER OUTLET, 200-240V/60A/3 PHASE DELTA , TOP-END FED, 3 METER INPUT CORD, WHITE	WHITE (RAL 9003)	3M(+254MM-127MM) 10' [+10"/-5"]	13.9kg
P24G05M-YL1A	VERTICAL,(12) C13,(12) C19,MONITORED&SWITCHED PER OUTLET, 200-240V/60A/3 PHASE DELTA , TOP-END FED, 1 METER INPUT CORD, YELLOW	YELLOW (RAL 1023)	1M(+178MM-89MM) 3.3' [+3.5"/-1.75"]	11.3kg
P24G05M-YL1B	VERTICAL,(12) C13,(12) C19,MONITORED&SWITCHED PER OUTLET, 200-240V/60A/3 PHASE DELTA , TOP-END FED, 2 METER INPUT CORD, YELLOW	YELLOW (RAL 1023)	2M(+178MM-89MM) 6.5' [+7"/-3.5"]	12.6kg
P24G05M-YL1C	VERTICAL,(12) C13,(12) C19,MONITORED&SWITCHED PER OUTLET, 200-240V/60A/3 PHASE DELTA , TOP-END FED, 3 METER INPUT CORD, YELLOW	YELLOW (RAL 1023)	3M(+254MM-127MM) 10' [+10"/-5"]	13.9kg
P24G05M-BU1A	VERTICAL,(12) C13,(12) C19,MONITORED&SWITCHED PER OUTLET, 200-240V/60A/3 PHASE DELTA , TOP-END FED, 1 METER INPUT CORD, BLUE	BLUE (RAL 5005)	1M(+178MM-89MM) 3.3' [+3.5"/-1.75"]	11.3kg
P24G05M-BU1B	VERTICAL,(12) C13,(12) C19,MONITORED&SWITCHED PER OUTLET, 200-240V/60A/3 PHASE DELTA , TOP-END FED, 2 METER INPUT CORD, BLUE	BLUE (RAL 5005)	2M(+178MM-89MM) 6.5' [+7"/-3.5"]	12.6kg
P24G05M-BU1C	VERTICAL,(12) C13,(12) C19,MONITORED&SWITCHED PER OUTLET, 200-240V/60A/3 PHASE DELTA , TOP-END FED, 3 METER INPUT CORD, BLUE	BLUE (RAL 5005)	3M(+254MM-127MM) 10' [+10"/-5"]	13.9kg
P24G05M-GN1A	VERTICAL,(12) C13,(12) C19,MONITORED&SWITCHED PER OUTLET, 200-240V/60A/3 PHASE DELTA , TOP-END FED, 1 METER INPUT CORD, GREEN	GREEN (RAL 6001)	1M(+178MM-89MM) 3.3' [+3.5"/-1.75"]	11.3kg
P24G05M-GN1B	VERTICAL,(12) C13,(12) C19,MONITORED&SWITCHED PER OUTLET, 200-240V/60A/3 PHASE DELTA , TOP-END FED, 2 METER INPUT CORD, GREEN	GREEN (RAL 6001)	2M(+178MM-89MM) 6.5' [+7"/-3.5"]	12.6kg
P24G05M-GN1C	VERTICAL,(12) C13,(12) C19,MONITORED&SWITCHED PER OUTLET, 200-240V/60A/3 PHASE DELTA , TOP-END FED, 3 METER INPUT CORD, GREEN	GREEN (RAL 6001)	3M(+254MM-127MM) 10' [+10"/-5"]	13.9kg
P24G05M-BL2A	VERTICAL,(12) C13,(12) C19,MONITORED&SWITCHED PER OUTLET, 200-240V/60A/3 PHASE DELTA , BOTTOM-END FED, 1 METER INPJT CORD, BLACK	BLACK (RAL 9005)	1M(+178MM-89MM) 3.3' [+3.5"/-1.75"]	11.3kg
P24G05M-BL2B	VERTICAL,(12) C13,(12) C19,MONITORED&SWITCHED PER OUTLET, 200-240V/60A/3 PHASE DELTA , BOTTOM-END FED, 2 METER INPJT CORD, BLACK	BLACK (RAL 9005)	2M(+178MM-89MM) 6.5' [+7"/-3.5"]	12.6kg
P24G05M-BL2C	VERTICAL,(12) C13,(12) C19,MONITORED&SWITCHED PER OUTLET, 200-240V/60A/3 PHASE DELTA , BOTTOM-END FED, 3 METER INPJT CORD, BLACK	BLACK (RAL 9005)	3M(+254MM-127MM) 10' [+10"/-5"]	13.9kg
P24G05M-RD2A	VERTICAL,(12) C13,(12) C19,MONITORED&SWITCHED PER OUTLET, 200-240V/60A/3 PHASE DELTA , BOTTOM-END FED, 1 METER INPUT CORD, RED	RED (RAL 3020)	1M(+178MM-89MM) 3.3' [+3.5"/-1.75"]	11.3kg
P24G05M-RD2B	VERTICAL,(12) C13,(12) C19,MONITORED&SWITCHED PER OUTLET, 200-240V/60A/3 PHASE DELTA , BOTTOM-END FED, 2 METER INPUT CORD, RED	RED (RAL 3020)	2M(+178MM-89MM) 6.5' [+7"/-3.5"]	12.6kg
P24G05M-RD2C	VERTICAL,(12) C13,(12) C19,MONITORED&SWITCHED PER OUTLET, 200-240V/60A/3 PHASE DELTA , BOTTOM-END FED, 3 METER INPUT CORD, RED	RED (RAL 3020)	3M(+254MM-127MM) 10' [+10"/-5"]	13.9kg
P24G05M-WH2A	VERTICAL,(12) C13,(12) C19,MONITORED&SWITCHED PER OUTLET, 200-240V/60A/3 PHASE DELTA , BOTTOM-END FED, 1 METER INPUT CORD, WHITE	WHITE (RAL 9003)	1M(+178MM-89MM) 3.3' [+3.5"/-1.75"]	11.3kg
P24G05M-WH2B	VERTICAL,(12) C13,(12) C19,MONITORED&SWITCHED PER OUTLET, 200-240V/60A/3 PHASE DELTA , BOTTOM-END FED, 2 METER INPUT CORD, WHITE	WHITE (RAL 9003)	2M(+178MM-89MM) 6.5' [+7"/-3.5"]	12.6kg
P24G05M-WH2C	VERTICAL,(12) C13,(12) C19,MONITORED&SWITCHED PER OUTLET, 200-240V/60A/3 PHASE DELTA , BOTTOM-END FED, 3 METER INPUT CORD, WHITE	WHITE (RAL 9003)	3M(+254MM-127MM) 10' [+10"/-5"]	13.9kg
P24G05M-YL2A	VERTICAL,(12) C13,(12) C19,MONITORED&SWITCHED PER OUTLET, 200-240V/60A/3 PHASE DELTA , BOTTOM-END FED, 1 METER INPLT CORD, YELLOW	YELLOW (RAL 1023)	1M(+178MM-89MM) 3.3' [+3.5"/-1.75"]	11.3kg
P24G05M-YL2B	VERTICAL,(12) C13,(12) C19,MONITORED&SWITCHED PER OUTLET, 200-240V/60A/3 PHASE DELTA , BOTTOM-END FED, 2 METER INPLT CORD, YELLOW	YELLOW (RAL 1023)	2M(+178MM-89MM) 6.5' [+7"/-3.5"]	12.6kg
P24G05M-YL2C	VERTICAL,(12) C13,(12) C19,MONITORED&SWITCHED PER OUTLET, 200-240V/60A/3 PHASE DELTA , BOTTOM-END FED, 3 METER INPLT CORD, YELLOW	YELLOW (RAL 1023)	3M(+254MM-127MM) 10' [+10"/-5"]	13.9kg
P24G05M-BU2A	VERTICAL,(12) C13,(12) C19,MONITORED&SWITCHED PER OUTLET, 200-240V/60A/3 PHASE DELTA , BOTTOM-END FED, 1 METER INPUT CORD, BLUE	BLUE (RAL 5005)	1M(+178MM-89MM) 3.3' [+3.5"/-1.75"]	11.3kg
P24G05M-BU2B	VERTICAL,(12) C13,(12) C19,MONITORED&SWITCHED PER OUTLET, 200-240V/60A/3 PHASE DELTA , BOTTOM-END FED, 2 METER INPUT CORD, BLUE	BLUE (RAL 5005)	2M(+178MM-89MM) 6.5' [+7"/-3.5"]	12.6kg
P24G05M-BU2C	VERTICAL,(12) C13,(12) C19,MONITORED&SWITCHED PER OUTLET, 200-240V/60A/3 PHASE DELTA , BOTTOM-END FED, 3 METER INPUT CORD, BLUE	BLUE (RAL 5005)	3M(+254MM-127MM) 10' [+10"/-5"]	13.9kg
P24G05M-GN2A	VERTICAL,(12) C13,(12) C19,MONITORED&SWITCHED PER OUTLET, 200-240V/60A/3 PHASE DELTA , BOTTOM-END FED, 1 METER INPUT CORD, GREEN	GREEN (RAL 6001)	1M(+178MM-89MM) 3.3' [+3.5"/-1.75"]	11.3kg
P24G05M-GN2B	VERTICAL,(12) C13,(12) C19,MONITORED&SWITCHED PER OUTLET, 200-240V/60A/3 PHASE DELTA , BOTTOM-END FED, 2 METER INPUT CORD, GREEN	GREEN (RAL 6001)	2M(+178MM-89MM) 6.5' [+7"/-3.5"]	12.6kg
P24G05M-GN2C	VERTICAL,(12) C13,(12) C19,MONITORED&SWITCHED PER OUTLET, 200-240V/60A/3 PHASE DELTA , BOTTOM-END FED, 3 METER INPUT CORD, GREEN	GREEN (RAL 6001)	3M(+254MM-127MM) 10' [+10"/-5"]	13.9kg

B



A

B



A

								WE ASK THAT YOU CHECK FULLY THE DIMENSIONS, NOTES, AND SIGN THE CLIENT SIGNATURE BOX. THE JOB WILL NOT PROGRESS WITHOUT SIGNED APPROVAL. PLEASE DO NOT DELAY IN RETURNING PROOF AS IT WILL AFFECT DELIVERY.		SIGN DATE PRINT			
								TITLE INTELLIGENT SERIES PDU P24G05M-XXYZ CUSTOMER DRAWING					
								ITEM REVISION NAME:					
								DATASHEET FILE NAME:					
02A	06/07/2018	H.XU	MIM	JAWI	ADDED SHEET 2 WITH CONFIGURABLE PART NUMBER TABLE AND DESCRIPTION UPDATED IDENTIFICATION TO INCLUDE CONFIGURABLE OPTION DE-CODER UPDATED CIRCUIT BREAKER LABELS WITH ROTATED TEXT	P24G05M		UNLESS OTHERWISE SPECIFIED DIMENSIONAL TOLERANCE ARE: mm [IN] THIRD ANGLE PROJECTION Tolerance(mm) 0<L<50 ±0.5 50<L<250 ±1.0 250<L<500 ±1.5 500<L<1000 ±2.5 1000<L<2000 ±4.0		MATERIAL/COLOR: N/A			
01A	08/23/2017	GEORGE	MIM	EDM	INITIAL RELEASE	P24G05M				DRAWING NUMBER: P24G05M_DC			
REV	DATE	BY	CHK	APR	DESCRIPTION	ECN		DRAWN BY GEORGE	DATE 08/23/2017	CHK SEAN	SCALE NONE	SHT 2 OF 2	SCALE B

2



1