






THIS COPY IS PROVIDED ON A RESTRICTED BASIS AND IS NOT TO BE USED IN ANY WAY DETRIMENTAL TO THE INTERESTS OF PANDUIT CORP.

PANDUIT P/N	WEIGHT
P24G04M-XXYZ	SEE SHEET 2

- SPECIFICATION:**
- STANDARD:
 - UNIT TYPE: MONITORED & SWITCHED PER OUTLET
 - ORIENTATION: VERTICAL, 0U FULL
 - OUTLET QTY & TYPE: (12) C13, (12) C19
 - INPUT VOLTAGE: 200-240VAC
 - INPUT CURRENT: (6) 20AMP, DOUBLE-POLE
 - BREAKER QTY & TYPE: 50A (40A DERATED)
 - INPUT PHASE: THREE-PHASE, DELTA
 - RATED POWER: 14.4 KVA
 - INPUT PLUG: CS8365
 - INPUT POWER CORD: SEE SHEET 2 FOR PART NUMBER TABLE
 - REGULATORY STANDARD: RoHS COMPLIANT
 - ADDITIONAL: NONE
 - ACCESSORIES: (1) QUICK-START GUIDE

- NOTES:**
- PRIMARY DIMENSIONS ARE IN MILLIMETERS. SECONDARY DIMENSION ARE IN [INCHES].
 - INSTALLATION SHALL COMPLY WITH ALL APPLICABLE NATIONAL, STATE, AND LOCAL CODES.
 - VISIT OUR ON-LINE CATALOG AT WWW.PANDUIT.COM FOR A CURRENT LIST OF PRODUCTS APPLICABLE FOR USE WITH THIS PART.
 - FOR FULL PRODUCT FUNCTIONALITY REFER TO USER MANUAL.
 - DRAWING VIEWS SHOW THE INPUT CORD IN THE "TOP END FED" CONFIGURATION.

IDENTIFICATION
 FOR FINISHED GOOD PART NUMBER & DESCRIPTION TABLE SEE SHEET 2 CONFIGURABLE PART NUMBERS: P24G04M-XX Y Z

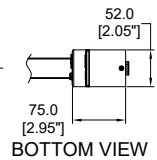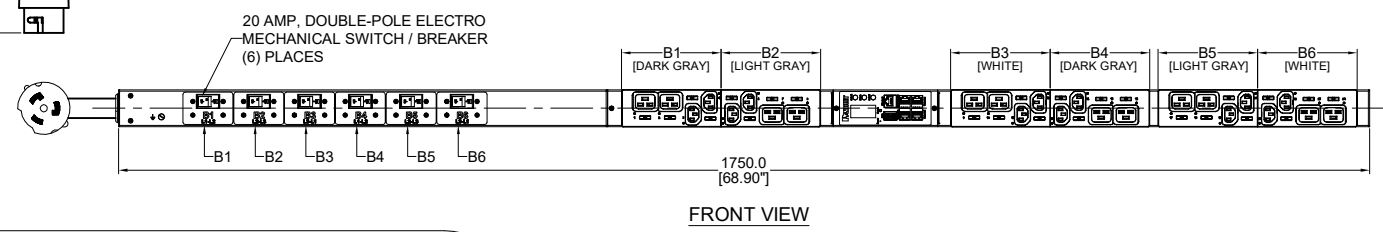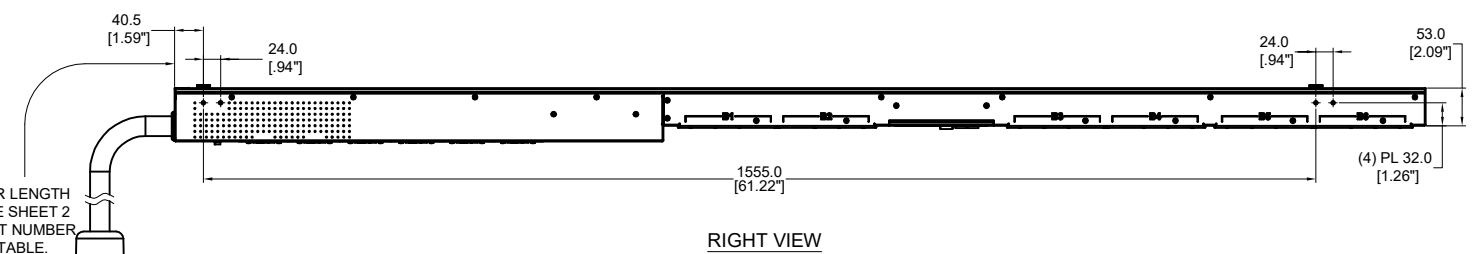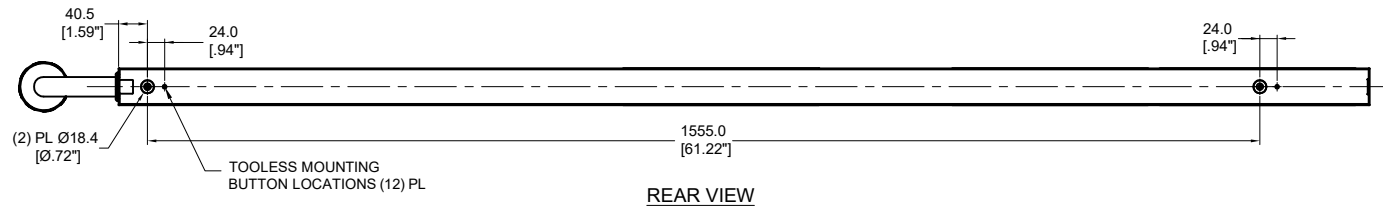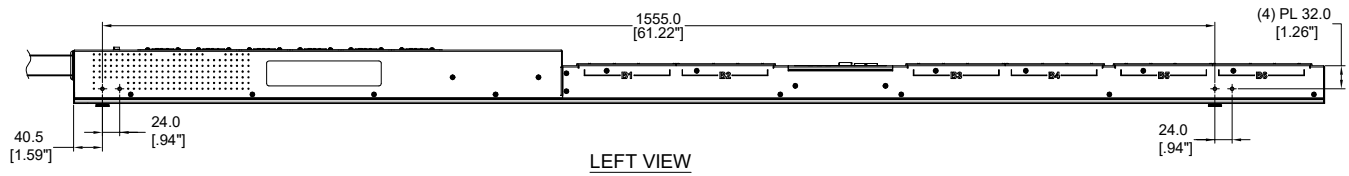

XX: FINISHED GOOD COLOR BL=BLACK YL=YELLOW RD=RED BU=BLUE WH=WHITE GN=GREEN	Y: INPUT FED TYPE 1=TOP-END FED 2=BOTTOM-END FED	Z: INPUT CORD LENGTH A=1 METER B=2 METER C=3 METER
--	--	---

PLUG/RECEPTACLE BLOCK

PLUG
CS8365, 3P 4W
50A, 250V, 3-PHASE MAX RATED INPUT
40A DERATED

RECEPTACLE
IEC 60320/C19
16A, 250V MAX RATED OUTPUT

RECEPTACLE
IEC 60320/C13
10A, 250V MAX RATED OUTPUT

REV	DATE	BY	CHK	APR	DESCRIPTION	ECN
03A	03/26/2020	Leo	MIM	JAWI	1. INPUT PLUG CS8365 WAS SHOWN CS8265	P24G04M
02A	06/07/2018	H.XU	MIM	JAWI	ADDED SHEET 2 WITH CONFIGURABLE PART NUMBER TABLE AND DESCRIPTION UPDATED IDENTIFICATION TO INCLUDE CONFIGURABLE OPTION DE-CODER UPDATED CIRCUIT BREAKER LABELS WITH ROTATED TEXT	P24G04M
01A	10/09/2017	WSJ	MIM	EDM	INITIAL RELEASE	P24G04M

WE ASK THAT YOU CHECK FULLY THE DIMENSIONS, NOTES, AND SIGN THE CLIENT SIGNATURE BOX. THE JOB WILL NOT PROGRESS WITHOUT SIGNED APPROVAL. PLEASE DO NOT DELAY IN RETURNING PROOF AS IT WILL AFFECT DELIVERY.

SIGN _____ DATE _____ PRINT _____

TITLE: INTELLIGENT SERIES PDU
P24G04M-XXYZ
CUSTOMER DRAWING

ITEM REVISION NAME: _____
DATASHEET FILE NAME: _____

UNLESS OTHERWISE SPECIFIED DIMENSIONAL TOLERANCE ARE: mm [IN]

Tolerance(mm)	
04<50	±0.5
50<250	±1.0
250<450	±1.5
500<1000	±2.5
1000<2000	±4.0

MATERIAL/COLOR: N/A

DRAWING NUMBER: P24G04M_DC

THIRD ANGLE PROJECTION

DRAWN BY: WSJ DATE: 10/09/2017 CHK: SEAN SCALE: NONE

SHT 1 OF 2 SCALE: B

THIS COPY IS PROVIDED ON A RESTRICTED BASIS AND IS NOT TO BE USED IN ANY WAY DETRIMENTAL TO THE INTERESTS OF PANDUIT CORP.

FINISHED GOOD PART NUMBER	FINISHED GOOD DESCRIPTION	COLOR	INPUT CORD LENGTH	WEIGHT
P24G04M	VERTICAL,(12) C13,(12) C19,MONITORED&SWITCHED PER OUTLET, 200-240V/50A/3 PHASE DELTA , TOP-END FED, 3 METER INPUT CORD, BLACK	BLACK (RAL 9005)	3M(+254MM/-127MM) 10'[+10"-5"]	13.7kg
P24G04M-BL1A	VERTICAL,(12) C13,(12) C19,MONITORED&SWITCHED PER OUTLET, 200-240V/50A/3 PHASE DELTA , TOP-END FED, 1 METER INPUT CORD, BLACK	BLACK (RAL 9005)	1M(+178MM/-89MM) 3.3'[+3.5"-1.75"]	11.1kg
P24G04M-BL1B	VERTICAL,(12) C13,(12) C19,MONITORED&SWITCHED PER OUTLET, 200-240V/50A/3 PHASE DELTA , TOP-END FED, 2 METER INPUT CORD, BLACK	BLACK (RAL 9005)	2M(+178MM/-89MM) 6.5'[+7"-3.5"]	12.4kg
P24G04M-RD1A	VERTICAL,(12) C13,(12) C19,MONITORED&SWITCHED PER OUTLET, 200-240V/50A/3 PHASE DELTA , TOP-END FED, 1 METER INPUT CORD, RED	RED (RAL 3020)	1M(+178MM/-89MM) 3.3'[+3.5"-1.75"]	11.1kg
P24G04M-RD1B	VERTICAL,(12) C13,(12) C19,MONITORED&SWITCHED PER OUTLET, 200-240V/50A/3 PHASE DELTA , TOP-END FED, 2 METER INPUT CORD, RED	RED (RAL 3020)	2M(+178MM/-89MM) 6.5'[+7"-3.5"]	12.4kg
P24G04M-RD1C	VERTICAL,(12) C13,(12) C19,MONITORED&SWITCHED PER OUTLET, 200-240V/50A/3 PHASE DELTA , TOP-END FED, 3 METER INPUT CORD, RED	RED (RAL 3020)	3M(+254MM/-127MM) 10'[+10"-5"]	13.7kg
P24G04M-WH1A	VERTICAL,(12) C13,(12) C19,MONITORED&SWITCHED PER OUTLET, 200-240V/50A/3 PHASE DELTA , TOP-END FED, 1 METER INPUT CORD, WHITE	WHITE (RAL 9003)	1M(+178MM/-89MM) 3.3'[+3.5"-1.75"]	11.1kg
P24G04M-WH1B	VERTICAL,(12) C13,(12) C19,MONITORED&SWITCHED PER OUTLET, 200-240V/50A/3 PHASE DELTA , TOP-END FED, 2 METER INPUT CORD, WHITE	WHITE (RAL 9003)	2M(+178MM/-89MM) 6.5'[+7"-3.5"]	12.4kg
P24G04M-WH1C	VERTICAL,(12) C13,(12) C19,MONITORED&SWITCHED PER OUTLET, 200-240V/50A/3 PHASE DELTA , TOP-END FED, 3 METER INPUT CORD, WHITE	WHITE (RAL 9003)	3M(+254MM/-127MM) 10'[+10"-5"]	13.7kg
P24G04M-YL1A	VERTICAL,(12) C13,(12) C19,MONITORED&SWITCHED PER OUTLET, 200-240V/50A/3 PHASE DELTA , TOP-END FED, 1 METER INPUT CORD, YELLOW	YELLOW (RAL 1023)	1M(+178MM/-89MM) 3.3'[+3.5"-1.75"]	11.1kg
P24G04M-YL1B	VERTICAL,(12) C13,(12) C19,MONITORED&SWITCHED PER OUTLET, 200-240V/50A/3 PHASE DELTA , TOP-END FED, 2 METER INPUT CORD, YELLOW	YELLOW (RAL 1023)	2M(+178MM/-89MM) 6.5'[+7"-3.5"]	12.4kg
P24G04M-YL1C	VERTICAL,(12) C13,(12) C19,MONITORED&SWITCHED PER OUTLET, 200-240V/50A/3 PHASE DELTA , TOP-END FED, 3 METER INPUT CORD, YELLOW	YELLOW (RAL 1023)	3M(+254MM/-127MM) 10'[+10"-5"]	13.7kg
P24G04M-BU1A	VERTICAL,(12) C13,(12) C19,MONITORED&SWITCHED PER OUTLET, 200-240V/50A/3 PHASE DELTA , TOP-END FED, 1 METER INPUT CORD, BLUE	BLUE (RAL 5005)	1M(+178MM/-89MM) 3.3'[+3.5"-1.75"]	11.1kg
P24G04M-BU1B	VERTICAL,(12) C13,(12) C19,MONITORED&SWITCHED PER OUTLET, 200-240V/50A/3 PHASE DELTA , TOP-END FED, 2 METER INPUT CORD, BLUE	BLUE (RAL 5005)	2M(+178MM/-89MM) 6.5'[+7"-3.5"]	12.4kg
P24G04M-BU1C	VERTICAL,(12) C13,(12) C19,MONITORED&SWITCHED PER OUTLET, 200-240V/50A/3 PHASE DELTA , TOP-END FED, 3 METER INPUT CORD, BLUE	BLUE (RAL 5005)	3M(+254MM/-127MM) 10'[+10"-5"]	13.7kg
P24G04M-GN1A	VERTICAL,(12) C13,(12) C19,MONITORED&SWITCHED PER OUTLET, 200-240V/50A/3 PHASE DELTA , TOP-END FED, 1 METER INPUT CORD, GREEN	GREEN (RAL 6001)	1M(+178MM/-89MM) 3.3'[+3.5"-1.75"]	11.1kg
P24G04M-GN1B	VERTICAL,(12) C13,(12) C19,MONITORED&SWITCHED PER OUTLET, 200-240V/50A/3 PHASE DELTA , TOP-END FED, 2 METER INPUT CORD, GREEN	GREEN (RAL 6001)	2M(+178MM/-89MM) 6.5'[+7"-3.5"]	12.4kg
P24G04M-GN1C	VERTICAL,(12) C13,(12) C19,MONITORED&SWITCHED PER OUTLET, 200-240V/50A/3 PHASE DELTA , TOP-END FED, 3 METER INPUT CORD, GREEN	GREEN (RAL 6001)	3M(+254MM/-127MM) 10'[+10"-5"]	13.7kg
P24G04M-BL2A	VERTICAL,(12) C13,(12) C19,MONITORED&SWITCHED PER OUTLET, 200-240V/50A/3 PHASE DELTA , BOTTOM-END FED, 1 METER INPUT CORD, BLACK	BLACK (RAL 9005)	1M(+178MM/-89MM) 3.3'[+3.5"-1.75"]	11.1kg
P24G04M-BL2B	VERTICAL,(12) C13,(12) C19,MONITORED&SWITCHED PER OUTLET, 200-240V/50A/3 PHASE DELTA , BOTTOM-END FED, 2 METER INPUT CORD, BLACK	BLACK (RAL 9005)	2M(+178MM/-89MM) 6.5'[+7"-3.5"]	12.4kg
P24G04M-BL2C	VERTICAL,(12) C13,(12) C19,MONITORED&SWITCHED PER OUTLET, 200-240V/50A/3 PHASE DELTA , BOTTOM-END FED, 3 METER INPUT CORD, BLACK	BLACK (RAL 9005)	3M(+254MM/-127MM) 10'[+10"-5"]	13.7kg
P24G04M-RD2A	VERTICAL,(12) C13,(12) C19,MONITORED&SWITCHED PER OUTLET, 200-240V/50A/3 PHASE DELTA , BOTTOM-END FED, 1 METER INPUT CORD, RED	RED (RAL 3020)	1M(+178MM/-89MM) 3.3'[+3.5"-1.75"]	11.1kg
P24G04M-RD2B	VERTICAL,(12) C13,(12) C19,MONITORED&SWITCHED PER OUTLET, 200-240V/50A/3 PHASE DELTA , BOTTOM-END FED, 2 METER INPUT CORD, RED	RED (RAL 3020)	2M(+178MM/-89MM) 6.5'[+7"-3.5"]	12.4kg
P24G04M-RD2C	VERTICAL,(12) C13,(12) C19,MONITORED&SWITCHED PER OUTLET, 200-240V/50A/3 PHASE DELTA , BOTTOM-END FED, 3 METER INPUT CORD, RED	RED (RAL 3020)	3M(+254MM/-127MM) 10'[+10"-5"]	13.7kg
P24G04M-WH2A	VERTICAL,(12) C13,(12) C19,MONITORED&SWITCHED PER OUTLET, 200-240V/50A/3 PHASE DELTA , BOTTOM-END FED, 1 METER INPUT CORD, WHITE	WHITE (RAL 9003)	1M(+178MM/-89MM) 3.3'[+3.5"-1.75"]	11.1kg
P24G04M-WH2B	VERTICAL,(12) C13,(12) C19,MONITORED&SWITCHED PER OUTLET, 200-240V/50A/3 PHASE DELTA , BOTTOM-END FED, 2 METER INPUT CORD, WHITE	WHITE (RAL 9003)	2M(+178MM/-89MM) 6.5'[+7"-3.5"]	12.4kg
P24G04M-WH2C	VERTICAL,(12) C13,(12) C19,MONITORED&SWITCHED PER OUTLET, 200-240V/50A/3 PHASE DELTA , BOTTOM-END FED, 3 METER INPUT CORD, WHITE	WHITE (RAL 9003)	3M(+254MM/-127MM) 10'[+10"-5"]	13.7kg
P24G04M-YL2A	VERTICAL,(12) C13,(12) C19,MONITORED&SWITCHED PER OUTLET, 200-240V/50A/3 PHASE DELTA , BOTTOM-END FED, 1 METER INPUT CORD, YELLOW	YELLOW (RAL 1023)	1M(+178MM/-89MM) 3.3'[+3.5"-1.75"]	11.1kg
P24G04M-YL2B	VERTICAL,(12) C13,(12) C19,MONITORED&SWITCHED PER OUTLET, 200-240V/50A/3 PHASE DELTA , BOTTOM-END FED, 2 METER INPUT CORD, YELLOW	YELLOW (RAL 1023)	2M(+178MM/-89MM) 6.5'[+7"-3.5"]	12.4kg
P24G04M-YL2C	VERTICAL,(12) C13,(12) C19,MONITORED&SWITCHED PER OUTLET, 200-240V/50A/3 PHASE DELTA , BOTTOM-END FED, 3 METER INPUT CORD, YELLOW	YELLOW (RAL 1023)	3M(+254MM/-127MM) 10'[+10"-5"]	13.7kg
P24G04M-BU2A	VERTICAL,(12) C13,(12) C19,MONITORED&SWITCHED PER OUTLET, 200-240V/50A/3 PHASE DELTA , BOTTOM-END FED, 1 METER INPUT CORD, BLUE	BLUE (RAL 5005)	1M(+178MM/-89MM) 3.3'[+3.5"-1.75"]	11.1kg
P24G04M-BU2B	VERTICAL,(12) C13,(12) C19,MONITORED&SWITCHED PER OUTLET, 200-240V/50A/3 PHASE DELTA , BOTTOM-END FED, 2 METER INPUT CORD, BLUE	BLUE (RAL 5005)	2M(+178MM/-89MM) 6.5'[+7"-3.5"]	12.4kg
P24G04M-BU2C	VERTICAL,(12) C13,(12) C19,MONITORED&SWITCHED PER OUTLET, 200-240V/50A/3 PHASE DELTA , BOTTOM-END FED, 3 METER INPUT CORD, BLUE	BLUE (RAL 5005)	3M(+254MM/-127MM) 10'[+10"-5"]	13.7kg
P24G04M-GN2A	VERTICAL,(12) C13,(12) C19,MONITORED&SWITCHED PER OUTLET, 200-240V/50A/3 PHASE DELTA , BOTTOM-END FED, 1 METER INPUT CORD, GREEN	GREEN (RAL 6001)	1M(+178MM/-89MM) 3.3'[+3.5"-1.75"]	11.1kg
P24G04M-GN2B	VERTICAL,(12) C13,(12) C19,MONITORED&SWITCHED PER OUTLET, 200-240V/50A/3 PHASE DELTA , BOTTOM-END FED, 2 METER INPUT CORD, GREEN	GREEN (RAL 6001)	2M(+178MM/-89MM) 6.5'[+7"-3.5"]	12.4kg
P24G04M-GN2C	VERTICAL,(12) C13,(12) C19,MONITORED&SWITCHED PER OUTLET, 200-240V/50A/3 PHASE DELTA , BOTTOM-END FED, 3 METER INPUT CORD, GREEN	GREEN (RAL 6001)	3M(+254MM/-127MM) 10'[+10"-5"]	13.7kg


B

B

A

A

REV	DATE	BY	CHK	APR	DESCRIPTION	ECN
03A	03/26/2020	Leo	MIM	JAWI	1. INPUT PLUG CS8365 WAS SHOWN CS8265	P24G04M
02A	06/07/2018	H.XU	MIM	JAWI	ADDED SHEET 2 WITH CONFIGURABLE PART NUMBER TABLE AND DESCRIPTION UPDATED IDENTIFICATION TO INCLUDE CONFIGURABLE OPTION DE-CODER UPDATED CIRCUIT BREAKER LABELS WITH ROTATED TEXT	P24G04M
01A	10/09/2017	WSJ	MIM	EDM	INITIAL RELEASE	P24G04M

WE ASK THAT YOU CHECK FULLY THE DIMENSIONS, NOTES, AND SIGN THE CLIENT SIGNATURE BOX. THE JOB WILL NOT PROGRESS WITHOUT SIGNED APPROVAL. PLEASE DO NOT DELAY IN RETURNING PROOF AS IT WILL AFFECT DELIVERY.		SIGN
		DATE
		PRINT
TITLE INTELLIGENT SERIES PDU P24G04M-XXYZ CUSTOMER DRAWING		
ITEM REVISION NAME		
DATASHEET FILE NAME:		
UNLESS OTHERWISE SPECIFIED DIMENSIONAL TOLERANCE ARE: mm [IN]		MATERIAL/COLOR:
 THIRD ANGLE PROJECTION		Tolerance(mm) 04-50 40.5 50-4250 11.0 250-4500 11.5 500-4100 22.5 1000-42000 44.0
DRAWN BY: WSJ		DATE: 10/09/2017
CHK: SEAN		SCALE: NONE
SHT 2 OF 2		SCALE: B