

A

B

C

D

E


F

MODEL No. Configuration

ADP-001□

(empty) : Extension Cord not included

C : Extension Cord included

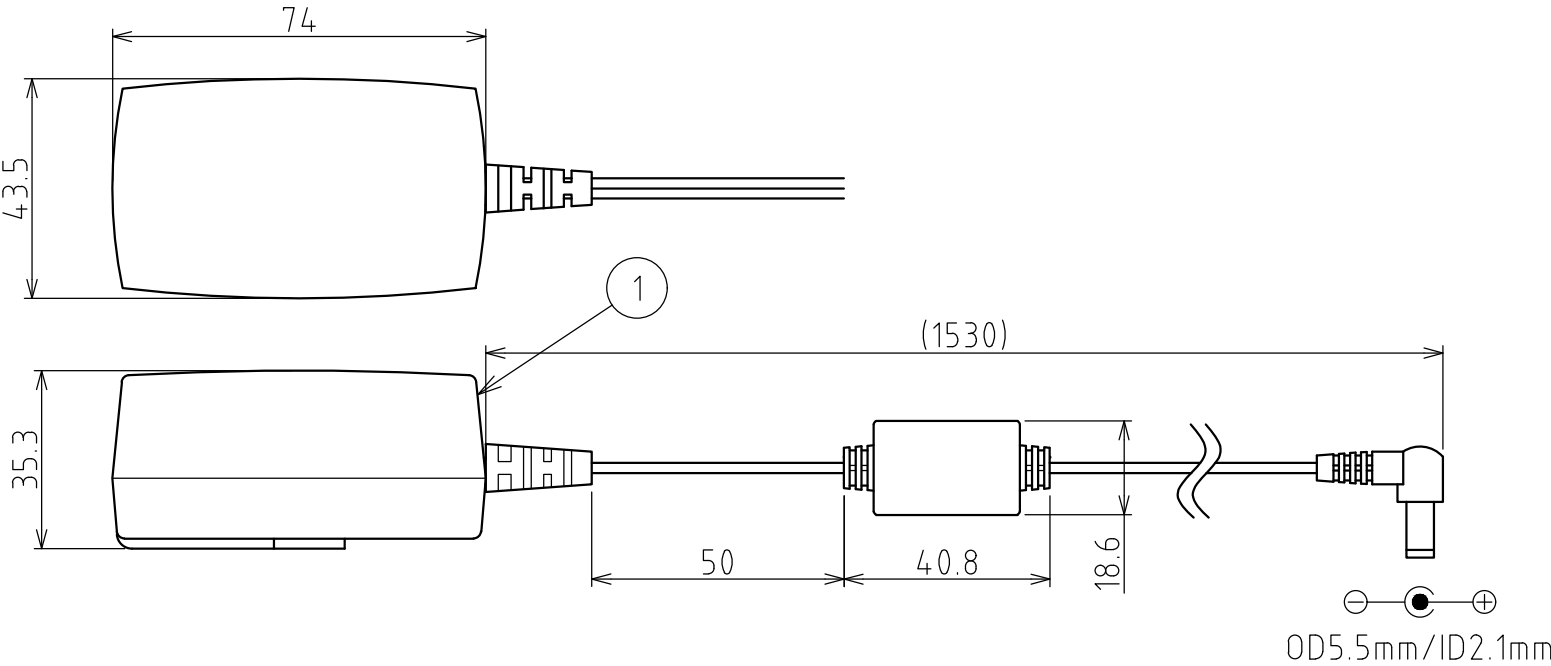


Specifications

Rated Input	AC100V - 240V 50/60Hz	
Rated Output	DC24V 1A	
Operating Ambient Temperature	0 - 40℃	
Storage Ambient Temperature	-10 - 70℃	
Mounting Location	Indoor Only	
Mass	AC Adaptor	123 ±15g
	AC Plug	UL:Approx.7g, VDE:Approx.15g, UK:Approx.16g, CCC:Approx.7g, KC:Approx.17g
	Extension Cord	Approx.38g
Conformity Standards and Certification	PSE UL Listed (File No.E163743) KC / CCC / BSMI U.S.Depaetment of Energy(DOE) &California's Energy Efficiency Standards LEVEL VI Natural Resources Canada(Nrcan) Energy Efficiency Regulations Code of Conduct on Energy Efficiency of External Power Supply Version 5 (CoC Tier2) FCC Part 15 Subpart B class B EN 62368-1, EN 55032, EN 55035, EN IEC 63000	
Remarks	Conforms to the CE Requirements Conforms to the UKCA Requirements	


指定公差 General Tolerance	角度公差 Angular tolerance ±[°]				寸法公差 Dimensional tolerance ±[mm]						図番 Drawing No.			ページ Page	
					ADP-001-W18									1/1	
	短辺長さ Length of short side														
	~	~	~	100	~	6	30	120	300	1000	改訂 Rev.	年 月 日 Date	改 訂 履 歴 Revisions		
	10	50	100	~	精 f	0.05	0.1	0.2	0.4	0.6					
	f	1	0.5	0.3	0.1	中 m	0.1	0.3	0.5	0.7	1				
	粗 v	3	1.5	1	0.5	粗 c	0.3	0.5	1	1.2	2				
													△		

Accessory


● AC Plug

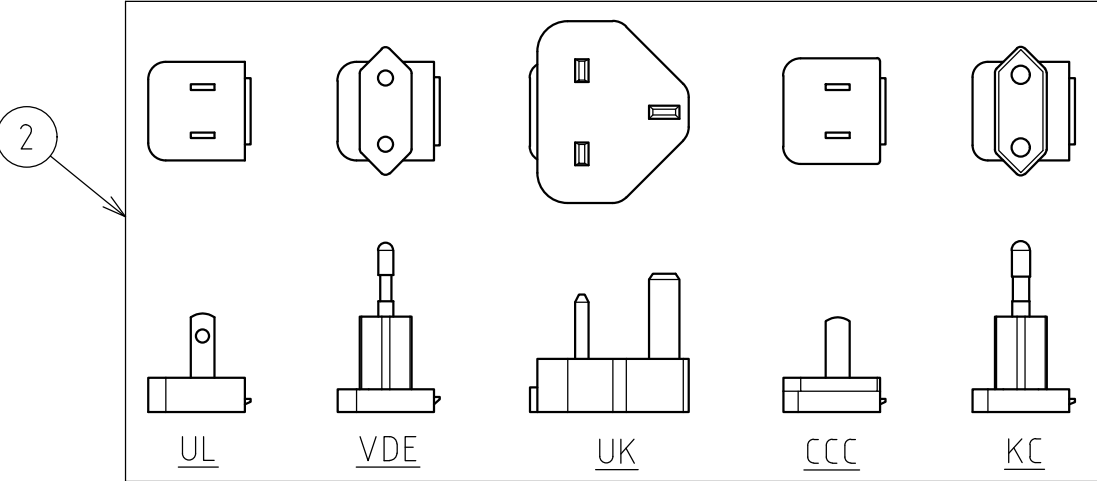

● Extension Cord

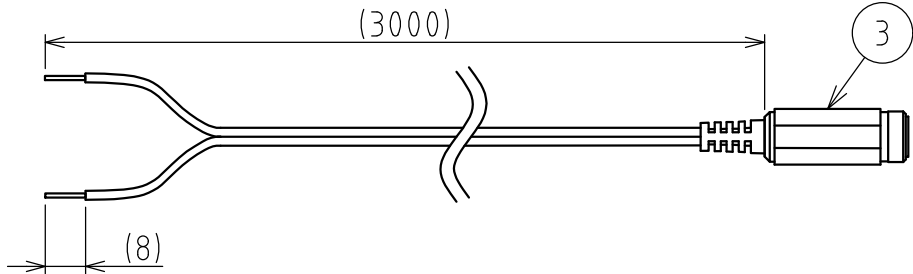

● Cable Tie

 

※ Only ADP-001C included

1	AC Adaptor	1		
2	AC Plug	5	UL,VDE,UK,CCC,KC	
3	Extension Cord	1	UL2468 AWG22	
4	Cable Tie	1		
番号 No.	部品名 Part Name	数量 Qty.	記事 Remarks	
機種 Model	ADP-001(C)		特注No. S.P.No.	-
図名 Name	Specifications			
品目コード Part No.	-		尺度 Scale -	三角法 3rd Angle P.
		単位 Unit mm	株式会社 PATLITE Corporation	パトライト

F

Ver.2.0