

Bronze Ground Clamp Connectors



Type GT

- Clamp is manufactured from high copper content alloy
- Used to connect a range of parallel conductors perpendicular to rod, water pipe, or structured tube
- Furnished with silicon bronze bolt, nuts, and lockwashers for corrosion resistance
- Use one groove for run and other for tap to equipment
- Suitable for direct burial in earth or concrete
- Single wrench installation
- UL 467 listed




CATALOG NUMBER	ACCOMMODATES		CONDUCTOR RANGE	APPROXIMATE DIMENSIONS (IN.)				BOLT SIZE
	ROD	IPS		A	B	C	D	
GT-1	1/2	1/4	8 Sol. - 4 Str.	1.63	2.00	1.63	1.00	3/8
GT-2			4 Sol. - 2/0 Str.	2.00	2.13	1.75	1.00	3/8
GT-3			2/0 Sol. - 250 kcmil	2.50	2.25	1.88	1.00	3/8
GT-4	5/8 or 3/4	3/8	8 Sol. - 4 Str.	1.63	2.13	1.63	1.13	3/8
GT-5			4 Sol. - 2/0 Str.	2.00	2.50	1.75	1.13	3/8
GT-6			2/0 Sol. - 250 kcmil	2.50	2.63	1.88	1.13	3/8
GT-7			300 - 500 kcmil	2.75	2.75	2.00	1.13	3/8
GT-8	7/8 or 1	1/2 or 3/4	8 Sol. - 4 Str.	1.63	2.50	1.63	1.50	3/8
GT-9			4 Sol. - 2/0 Str.	2.00	3.31	1.75	1.50	3/8
GT-10			2/0 Sol. - 250 kcmil	2.50	3.31	1.88	1.50	3/8
GT-11			300 - 500 kcmil	2.75	3.00	2.00	1.50	3/8
GT-12			500 - 750 kcmil	3.13	3.75	2.25	1.63	1/2
GT-13	-	1	8 Sol. - 4 Str.	1.63	2.75	1.63	1.75	3/8
GT-14			4 Sol. - 2/0 Str.	2.00	3.00	1.75	1.75	3/8
GT-15			2/0 Sol. - 250 kcmil	2.50	3.88	3.13	1.75	3/8
GT-16			300 - 500 kcmil	2.75	3.75	2.00	1.75	3/8
GT-17			500 - 750 kcmil	3.13	4.13	2.25	1.88	1/2
GT-18	-	1 1/4	8 Sol. - 4 Str.	1.63	3.00	1.88	2.06	3/8
GT-19			4 Sol. - 2/0 Str.	2.00	3.25	2.00	2.06	3/8
GT-20			2/0 Sol. - 250 kcmil	2.50	3.50	2.13	2.06	3/8
GT-21			300 - 500 kcmil	2.75	4.13	2.25	2.19	1/2
GT-22			500 - 750 kcmil	3.75	4.38	2.50	2.31	5/8
GT-23			750 - 1000 kcmil	4.00	4.63	2.75	2.31	5/8
GT-24	-	1 1/2	8 Sol. - 4 Str.	1.63	3.25	2.25	2.38	3/8
GT-25			4 Sol. - 2/0 Str.	2.00	3.50	2.38	2.38	3/8
GT-26			2/0 Sol. - 250 kcmil	2.50	3.88	2.50	2.38	3/8
GT-27			300 - 500 kcmil	2.75	4.38	2.63	2.50	1/2
GT-28			500 - 750 kcmil	3.75	4.75	2.75	2.63	5/8
GT-29			750 - 1000 kcmil	4.00	5.00	2.88	2.63	5/8

• UL listing is limited to maximum wire size of 250 kcmil

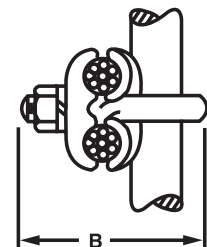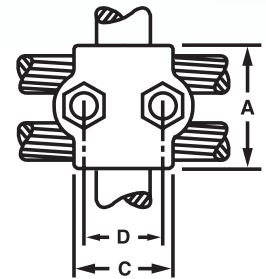

GROUNDING CONNECTORS

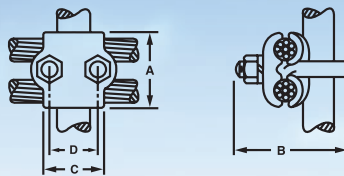

Bronze Ground Clamp Connectors Type GT (continued)

CATALOG NUMBER	ACCOMMODATES		CONDUCTOR RANGE	APPROXIMATE DIMENSIONS (IN.)				BOLT SIZE
	ROD	IPS		A	B	C	D	
GT-30	-	2	8 Sol. - 4 Str.	1.75	3.88	2.75	2.81	3/8
GT-31			4 Sol. - 2/0 Str.	2.00	4.13	2.88	2.81	3/8
GT-32			2/0 Sol. - 250 kcmil	2.63	4.25	3.00	2.81	3/8
GT-33 •			300 - 500 kcmil	2.88	4.63	3.13	2.94	1/2
GT-34 •			500 - 750 kcmil	3.75	5.25	3.25	3.06	5/8
GT-35 •			750 - 1000 kcmil	4.00	5.50	3.25	3.06	5/8
GT-36	-	2 1/2	8 Sol. - 4 Str.	1.75	4.38	3.38	3.63	3/8
GT-37			4 Sol. - 2/0 Str.	2.00	4.50	3.38	3.31	3/8
GT-38			2/0 Sol. - 250 kcmil	2.63	4.75	3.50	3.31	3/8
GT-39 •			300 - 500 kcmil	2.88	5.13	3.63	3.44	1/2
GT-40 •			500 - 750 kcmil	3.75	5.63	3.75	3.56	5/8
GT-41 •			750 - 1000 kcmil	4.00	5.75	3.75	3.56	5/8
GT-42	-	3	8 Sol. - 4 Str.	1.75	5.00	3.63	3.94	3/8
GT-43			4 Sol. - 2/0 Str.	2.00	5.25	3.75	3.94	3/8
GT-44			2/0 Sol. - 250 kcmil	2.63	5.50	3.75	3.94	3/8
GT-45 •			300 - 500 kcmil	2.88	5.88	3.88	4.06	1/2
GT-46 •			500 - 750 kcmil	3.75	6.50	4.13	4.19	5/8
GT-47 •			750 - 1000 kcmil	4.00	6.75	4.13	4.19	5/8
GT-48	-	3 1/2	8 Sol. - 4 Str.	1.75	5.50	3.88	4.44	3/8
GT-49			4 Sol. - 2/0 Str.	2.00	5.88	3.88	4.44	3/8
GT-50			2/0 Sol. - 250 kcmil	2.63	6.13	4.00	4.44	3/8
GT-51 •			300 - 500 kcmil	2.88	6.50	4.25	4.56	1/2
GT-52 •			500 - 750 kcmil	3.75	7.13	4.63	4.69	5/8
GT-53 •			750 - 1000 kcmil	4.00	7.38	4.63	4.69	5/8
GT-54 •	1250 - 1500 kcmil	4.25	7.63	4.75	4.69	5/8		
GT-55	-	4	2/0 Sol. - 250 kcmil	2.63	6.50	4.75	4.94	3/8
GT-56 •			300 - 500 kcmil	2.88	7.00	5.00	5.06	1/2

• UL listing is limited to maximum wire size of 250 kcmil