

Bronze Variable Gutter Taps

Type VX

For parallel taps, tee connections, cross connections, or end to end connections

- Upper and lower clamping members are made of high strength bronze alloy
- Spacer is made from high conductivity copper alloy
- Furnished with high strength silicon bronze bolts and lockwashers



RoHS
COMPLIANT

CATALOG NUMBER	FIG. NO.	CONDUCTOR RANGE A RUN	CONDUCTOR RANGE B TAP	APPROXIMATE DIMENSIONS (IN.)	
				J (BOLT SIZE)	M
VX-0	1	10 Sol. - 10 Str.	10 Sol. - 10 Str.	5/16	1.31
VX-1	1	6 Str. - 2 Str.	6 Str. - 2 Str.	5/16	1.31
VX-3	1	1 Str. - 4/0 Str.	6 Str. - 4/0 Str.	3/8	1.75
VX-4	1	250 - 500 kcmil	6 Str. - 2 Str.	3/8	2.19
VX-5S	1	250 - 500 kcmil	1/0 Str. - 300 kcmil	3/8	2.19
VX-6	1	250 - 500 kcmil	1 Str. - 500 kcmil	1/2	2.63
VX-7	1	500 - 1000 kcmil	6 Str. - 2/0 Str.	3/8	2.63
VX-8	1	500 - 1000 kcmil	1 Str. - 4/0 Str.	3/8	2.63
VX-8S	1	500 - 1000 kcmil	1/0 Str. - 300 kcmil	3/8	2.63
VX-10	2	500 - 1000 kcmil	250 - 1000 kcmil	3/8	2.86
VX-10S	2	750 - 1000 kcmil	750 - 1000 kcmil	1/2	3.00
VX-11	2	750 - 1000 kcmil	500 - 1000 kcmil	3/8	2.94
VX-12	2	750 - 1500 kcmil	750 - 1500 kcmil	1/2	3.25
VX-13	2	1000 - 2000 kcmil	1000 - 2000 kcmil	1/2	3.44

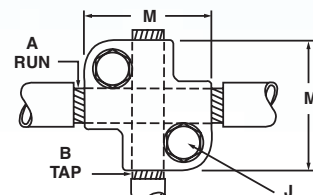


FIG. 1
2-Bolt

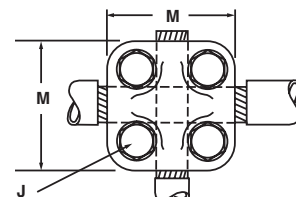


FIG. 2
4-Bolt

Terminal Connector

Type CTB

For cable range or tubing range to flat four hole NEMA mounting

- Manufactured from high strength bronze alloy
- Reversible, range taking, high strength cap
- Front or side entrance available by rotating cap 90°
- Furnished with silicon bronze bolts, nuts, and lockwashers
- Bolts with sufficient length for mounting to pads up to 1/2 in. thick



CATALOG NUMBER	CONDUCTOR RANGE	IPS RANGE
CTB-100	6 Sol. - 1000 kcmil	1/8 - 3/4

