
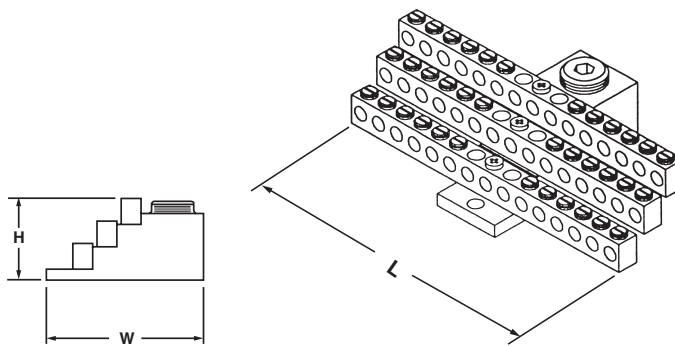


Aluminum Stacked Neutral Bars

Type SNB

For aluminum or copper conductors

- Assembly is suitable for grounding applications
- Preassembled, stacked neutral bars provide a compact design offering range taking flexibility
- Electro-tin plated neutral bars and stacking lugs provide low contact resistance suitable for bimetallic applications
- The stacking lugs are UL 486A-486B listed AL9CU
- The neutral bars are UL component recognized
- Available with phenolic base, catalog number R-16

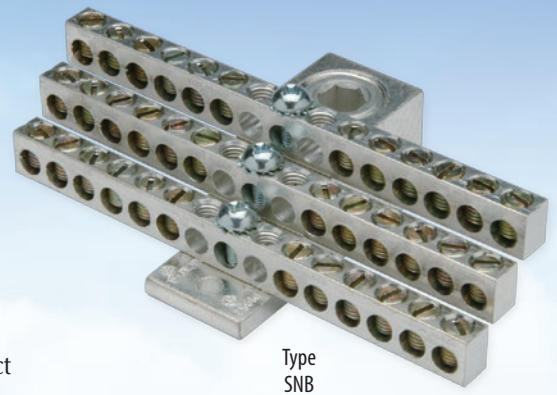

CATALOG NUMBER	CONDUCTOR RANGE (AWG)		NUMBER OF TAPS	APPROXIMATE DIMENSIONS (IN.)		
	MAIN	TAP		H	W	L
SNB350-12	6 Str. - 350 kcmil	14 Str. - 6 Str.	12	1.53	2.53	4.73
SNB350-24			24			4.73
SNB350-30			30			4.08
SNB350-36			36			4.73
SNB350-42			42			5.31
R-16	Mounting block of general purpose phenolic suitable for mounting any SNB neutral bars			1.00	2.50	2.50