


## Bronze Eyebolt Connectors

### Types LS and LSN

- Manufactured from high strength copper alloy
- Designed to secure copper cable to flat studs, transformer spades, or copper bus
- Furnished with silicon bronze hardware for corrosion resistance
- Single wrench installation
- For tin plating, suffix catalog number with “-TN”

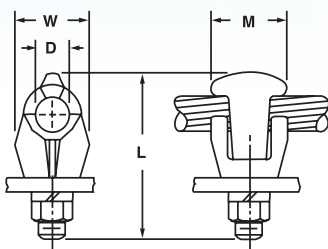

#### For 1/4" Thick Bar

CATALOG NUMBER	CONDUCTOR RANGE	APPROXIMATE DIMENSIONS (IN.)				BOLT SIZE
		D	L	M	W	
LSN-2/0N	8 Sol. - 2/0 Str.	.44	2.38	1.38	1.00	1/2
LS-2/0	8 Sol. - 2/0 Str.	.44	2.00	1.25	1.00	3/8
LSN-025N	6 Sol. - 250 kcmil	.63	2.56	1.25	1.06	1/2
LSN-035N	2 Sol. - 350 kcmil	.81	3.06	1.25	1.31	1/2
LSN-050N	1/0 Sol. - 500 kcmil	.94	3.25	1.25	1.44	1/2
LSN-075	350 - 750 kcmil	1.06	3.19	1.50	1.59	1/2
LSN-100N	2/0 Sol. - 1000 kcmil	1.25	4.25	1.72	1.69	1/2

#### For 1/4" to 3/4" Thick Bar

CATALOG NUMBER	CONDUCTOR RANGE	APPROXIMATE DIMENSIONS (IN.)				BOLT SIZE
		D	L	M	W	
LS-C1E	10 Sol. - 1 Str.	.34	2.38	1.06	.88	3/8
LSN-2/0NE	8 Sol. - 2/0 Str.	.44	2.75	1.38	1.00	1/2
LS-2/0E	8 Sol. - 2/0 Str.	.44	2.50	1.25	1.00	3/8
LSN-025NE	6 Sol. - 250 kcmil	.63	3.06	1.25	1.06	1/2
LSN-035NE	2 Sol. - 350 kcmil	.81	3.31	1.25	1.31	1/2
LSN-050NE	1/0 Sol. - 500 kcmil	.94	3.75	1.25	1.44	1/2
LSN-075E	350 - 750 kcmil	1.06	3.69	1.50	1.56	1/2
LSN-100NE	2/0 Sol. - 1000 kcmil	1.25	4.50	1.72	1.69	1/2
LS-150E	1000 - 1500 kcmil	1.50	4.38	2.25	2.50	1/2
LS-200E	500 - 2000 kcmil	1.72	5.25	2.25	2.75	1/2

"N" in prefix qualifies terminal for mounting on NEMA pads