


Bronze Terminals

Type RA

For copper tube to flat

- Manufactured from high strength cast copper alloy
- Furnished with silicon bronze bolts, nuts, and lockwashers for corrosion resistance
- Side formed contact surfaces are standard to allow clearance for flush mounting
- Drilling in pads conforms to NEMA standards for 1/2" hardware
- For tin plating, suffix catalog number with "-TN"

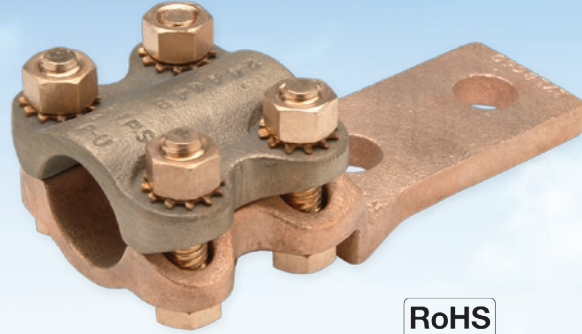

RoHS
COMPLIANT

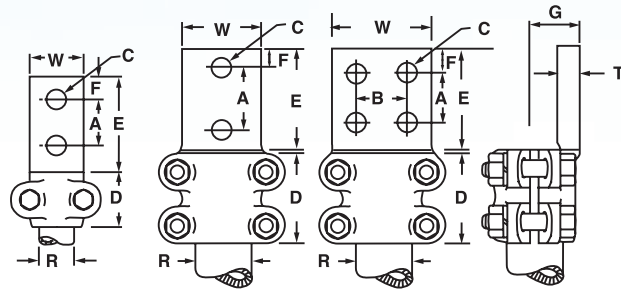


Fig. 1

Fig. 2

Fig. 3

CATALOG NUMBER	FIG. NO.	R IPS SIZE	APPROXIMATE DIMENSIONS (IN.)									BOLT SIZE
			W	A	B	C	D	E	F	T	G	
RA-03-2B*	1	3/8	1.38	1.00	-	.44	1.38	2.00	.44	.25	.88	3/8
RA-03-2N	1		1.38	1.75	-	.56	1.38	3.00	.56	.28	.88	3/8
RA-05-2B*	1	1/2	1.50	1.13	-	.44	1.50	2.00	.44	.31	.88	3/8
RA-05-2N	2		1.50	1.75	-	.56	2.25	3.00	.56	.31	.88	3/8
RA-07-2B*	2	3/4	1.50	1.38	-	.44	2.00	2.25	.44	.31	.81	3/8
RA-07-2N	2		1.50	1.75	-	.56	2.00	3.00	.56	.31	.81	3/8
RA-07-F	3		3.00	1.75	1.75	.56	2.00	3.00	.56	.38	.88	3/8
RA-10-2B*	2	1	2.00	1.38	-	.44	2.25	2.38	.44	.38	1.00	3/8
RA-10-D	2		2.00	1.75	-	.56	2.25	3.25	.56	.38	1.00	3/8
RA-10-F	3		3.00	1.75	1.75	.56	2.25	3.25	.56	.31	.94	3/8
RA-12-D	2	1 1/4	2.00	1.75	-	.56	2.75	3.00	.56	.44	1.25	1/2
RA-12-F	3		3.00	1.75	1.75	.56	2.75	3.00	.56	.34	1.16	1/2
RA-12-E	3		4.00	1.75	1.75	.56	2.75	4.00	1.13	.31	1.13	1/2
RA-15-D	2	1 1/2	2.00	1.75	-	.56	2.75	3.00	.56	.44	1.25	1/2
RA-15-F	3		3.00	1.75	1.75	.56	2.75	3.00	.56	.50	1.31	1/2
RA-15-E	3		4.00	1.75	1.75	.56	2.75	4.00	1.13	.38	1.19	1/2
RA-20-D	2	2	2.00	1.75	-	.56	2.75	3.00	.56	.50	1.69	1/2
RA-20-F	3		3.00	1.75	1.75	.56	2.75	3.00	.56	.50	1.69	1/2
RA-20-E	3		4.00	1.75	1.75	.56	2.75	4.00	1.13	.44	1.63	1/2
RA-25-D	2	2 1/2	2.00	1.75	-	.56	2.75	3.00	.56	.69	2.00	1/2
RA-25-F	3		3.00	1.75	1.75	.56	2.75	3.00	.56	.69	2.00	1/2
RA-25-E	3		4.00	1.75	1.75	.56	2.75	4.00	1.13	.63	1.94	1/2
RA-30-F	3	3	3.00	1.75	1.75	.56	3.25	3.00	.56	.69	2.50	5/8
RA-30-E	3		4.00	1.75	1.75	.56	3.25	4.00	1.13	.63	2.44	5/8
RA-35-F	3	3 1/2	3.00	1.75	1.75	.56	3.25	3.00	.56	.75	2.69	5/8
RA-35-E	3		4.00	1.75	1.75	.56	3.25	4.00	1.13	.75	2.69	5/8
RA-40-F	3	4	3.00	1.75	1.75	.56	3.25	3.00	.56	.75	3.13	5/8
RA-40-E	3		4.00	1.75	1.75	.56	3.25	4.00	1.13	.75	3.13	5/8

* Two hole pad drilling accommodates 3/8" hardware