
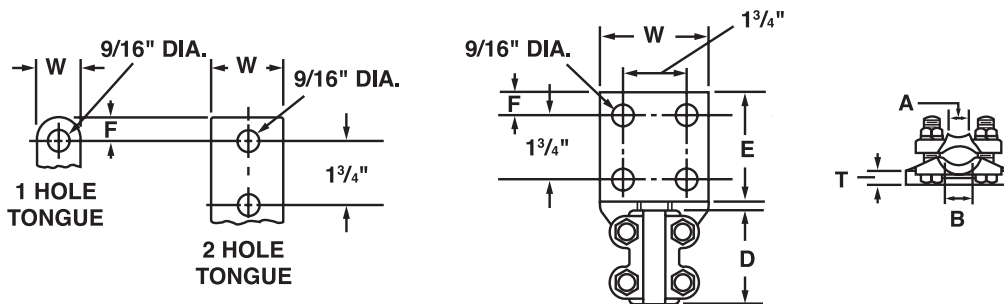


Bronze Terminals

Type RAR

For copper cable to flat

- Manufactured from high strength cast copper alloy
- Furnished with silicon bronze bolts, nuts, and lockwashers for corrosion resistance
- Reversible cap allows for expanded conductor range
- Side formed contact surfaces are standard and allow clearance for flush mounting
- Drilling in pads conforms to NEMA standards for 1/2" hardware
- For tin plating, suffix catalog number with "-TN"

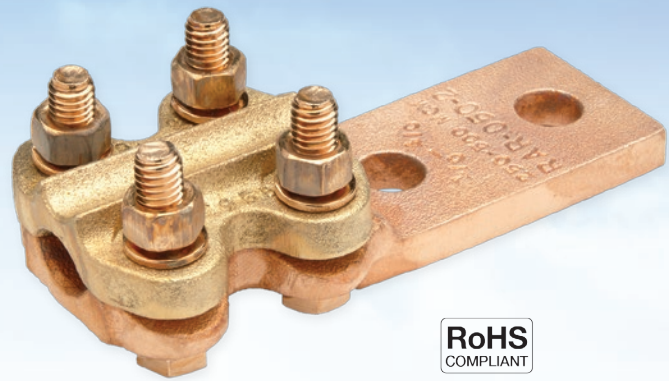

| CATALOG NUMBER | A COPPER CONDUCTOR RANGE | B COPPER CONDUCTOR RANGE | NO. OF HOLES IN TONGUE | APPROXIMATE DIMENSIONS (IN.) | | | | | BOLT SIZE |
|----------------|-----------------------------|-----------------------------|------------------------|------------------------------|------|-----|-----|------|-----------|
| | | | | D | E | F | T | W | |
| RAR-021-S | 8 Sol. - 1 Str. | 1/0 Str. - 4/0 Str. | 1 | 2.25 | 1.75 | .75 | .31 | 1.50 | 3/8 |
| RAR-021-D | 6 Str. - 1 Str. | 1/0 Str. - 4/0 Str. | 2 | 2.25 | 3.00 | .63 | .25 | 1.50 | 3/8 |
| RAR-025-D | 6 Sol. - 1 Str. | 1/0 Str. - 250 kcmil | 2 | 2.50 | 3.00 | .63 | .25 | 1.50 | 3/8 |
| RAR-025-DH | | | 2 | 2.50 | 3.00 | .63 | .25 | 1.50 | 1/2 |
| RAR-025-F | 4 Sol. - 1/0 Str. | 2/0 Str. - 250 kcmil | 4 | 2.50 | 3.00 | .63 | .25 | 3.00 | 3/8 |
| RAR-025-FH | | | 4 | 2.50 | 3.00 | .63 | .25 | 3.00 | 1/2 |
| RAR-050-D | 1/0 Str. - 4/0 Str. | 250 - 500 kcmil | 2 | 2.50 | 3.00 | .63 | .38 | 1.75 | 3/8 |
| RAR-050-DH | | | 2 | 2.50 | 3.00 | .63 | .38 | 1.75 | 1/2 |
| RAR-050-F | | | 4 | 2.50 | 3.00 | .63 | .38 | 3.00 | 3/8 |
| RAR-050-FH | | | 4 | 2.50 | 3.00 | .63 | .38 | 3.00 | 1/2 |
| RAR-080-D | 2 Sol. - 4/0 Str. | 250 - 800 kcmil | 2 | 2.50 | 3.00 | .63 | .41 | 2.00 | 1/2 |
| RAR-080-F | | | 4 | 2.50 | 3.00 | .63 | .41 | 3.00 | 1/2 |
| RAR-100-D | 4/0 Str. - 550 kcmil | 600 - 1000 kcmil | 2 | 3.00 | 3.00 | .63 | .44 | 2.00 | 1/2 |
| RAR-100-F | | | 4 | 3.00 | 3.00 | .63 | .38 | 3.00 | 1/2 |
| RAR-200-D | 500 - 1000 kcmil | 1100 - 2000 kcmil | 2 | 5.25 | 3.00 | .63 | .56 | 1.50 | 1/2 |
| RAR-200-F | | | 4 | 5.25 | 3.00 | .63 | .50 | 3.00 | 1/2 |