



CONNECTING YOUR TOMORROW.™

HOME : SALES LOCATIONS : PRODUCTS : CUSTOMER SERVICE : COMPANY : CONTACT US



PRODUCT QUICK SEARCH:

Penn Union Search:

Competitor Search:

Now In: [Penn-Union Products](#) → [Mechanical Lugs & Splices](#) → [Copper Solderless & Soldering Lugs](#) → [SLU - Solderless Lug - Single Collar](#) → [SLU-70 - Copper Solderless Lug](#)



SLU-70 - Copper Solderless Lug

One hole, single collar


For copper stranded wire

100% pure electrolytic copper for utmost efficiency

Unique design of the concave pressure bar and V-bottom collar assures positive contact and firm, permanent grip

For tin plating, suffix catalog number with "-TN"

Product Drawing:

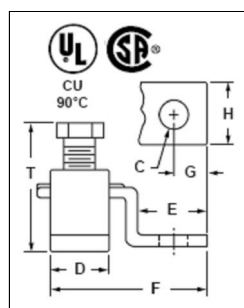

Click to expand.

| | |
|-----------------|-----------------|
| Conductor Type | Conductor Range |
| Copper Stranded | 8 - 2 Str. |

Additional Details

| | |
|----------------|---------|
| Ampere Rating: | 70-90 |
| UL Listing: | CU 90°C |
| CSA Listing: | Yes |

Approximate Dimensions

| | |
|----------|--------|
| C (in.): | 17/64 |
| D (in.): | 1/2 |
| E (in.): | 11/16 |
| F (in.): | 1 7/16 |
| G (in.): | 1/4 |
| H (in.): | 1/2 |
| T (in.): | 1 |

© 2017 Penn-Union Corp. · 229 Waterford Street · Edinboro, PA 16412
 Phone: 814-734-1631 · Fax: 814-734-4946 · info@penn-union.com

Designed & Developed by O-Web Technologies, Ltd.