



Model Number

NCN8-18GM40-Z0

Features

- Comfort series
- 8 mm non-flush
- 2-wire DC

Accessories

BF 18

Mounting flange, 18 mm

Technical Data

General specifications

Switching function	Normally open (NO)
Output type	Two-wire
Rated operating distance	s_n 8 mm
Installation	non-flush
Output polarity	DC
Assured operating distance	s_a 0 ... 6.5 mm
Actual operating distance	s_r 7.2 ... 8.8 mm typ. 8 mm
Reduction factor r_{Al}	0.44
Reduction factor r_{Cu}	0.4
Reduction factor r_{304}	0.7
Output type	2-wire

Nominal ratings

Operating voltage	U_B 5 ... 60 V
Switching frequency	f 0 ... 300 Hz
Hysteresis	H 1 ... 10 typ. 5 %
Reverse polarity protection	reverse polarity tolerant
Short-circuit protection	pulsing
Voltage drop	U_d \leq 5 V
Operating current	I_L 2 ... 100 mA
Lowest operating current	I_m 2 mA
Off-state current	I_r 0 ... 0.5 mA typ.
Switching state indicator	all direction LED, yellow

Functional safety related parameters

MTTF _d	1739 a
Mission Time (T _M)	20 a
Diagnostic Coverage (DC)	0 %

Ambient conditions

Ambient temperature	-25 ... 70 °C (-13 ... 158 °F)
---------------------	--------------------------------

Mechanical specifications

Connection type	cable PUR, 2 m
Core cross-section	0.34 mm ²
Housing material	Stainless steel 1.4305 / AISI 303
Sensing face	PBT
Degree of protection	IP67


Compliance with standards and directives

Standard conformity	
Standards	EN 60947-5-2:2007 IEC 60947-5-2:2007 Non-standard connector assignment

Approvals and certificates

UL approval	cULus Listed, General Purpose
CSA approval	cCSAus Listed, General Purpose
CCC approval	Certified by China Compulsory Certification (CCC)

Dimensions

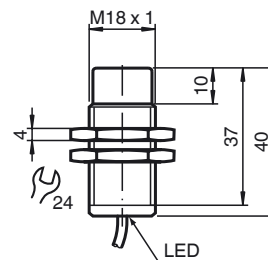

Electrical Connection

