



Model Number


1/2" NPT-V12-G-S-.3M

Male receptacle, 1/2" UNF / 1/2" NPT, 3-pin

Features

- Operating voltage AC

Dimensions

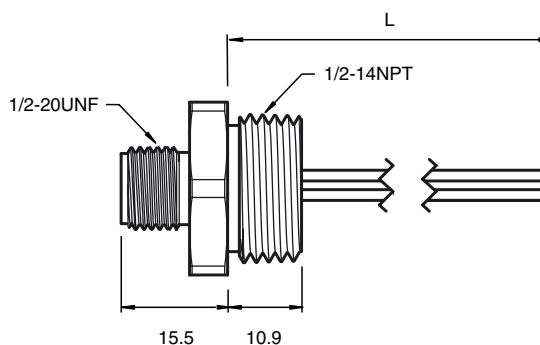

Technical data

General specifications

Number of pins	3
Construction type	straight
Connection 1	Male connector
Threading 1	1/2"
Connection 2	cable end
Threading 2	1/2"

Electrical specifications

Operating voltage	U_B	max. 300 V AC/DC
Operating current		max. 4 A

Ambient conditions

Ambient temperature	-40 ... 105 °C (-40 ... 221 °F)
---------------------	---------------------------------

Mechanical specifications

Degree of protection	IP67
Connection	Single strand leads
Material	clear anodized aluminum
Contacts	Gold plated copper alloy
Sleeve connector	Polyamide (PA)
Cable	
Cores	3 x 0.34 mm ² , 22 AWG
Length	L 0.3 m
Note	1/2" - 14 NPT installation thread

Approvals and certificates

UL approval	cULus Listed, General Purpose
-------------	-------------------------------

Electrical connection



Electrical connection

1	GN/YE
2	RD/BK
3	RD/WH