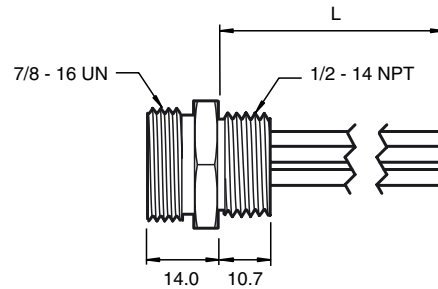


**Model Number****1/2" NPT-V95-G-.3M**Female receptacle, 7/8" UN / 1/2" NPT,
5-pin**Dimensions****Technical data****General specifications**

Number of pins	5
Construction type	straight
Connection 1	socket
Threading 1	7/8"

Electrical specifications

Operating voltage	U _B	max 600 V AC/DC
Operating current		8 A

Ambient conditions


Ambient temperature	-40 ... 105 °C (-40 ... 221 °F)
---------------------	---------------------------------

Mechanical specifications

Protection degree	IP67
Connection	7/8"-16 UN connector
Material	clear anodized aluminum
Contacts	gold plated copper alloy
Cable	
Cores	5 x 1.5 mm ²
Length	L 0.3 m
Note	1/2" - 14 NPT installation thread

Approvals and certificates

UL approval	cULus Listed, General Purpose
-------------	-------------------------------

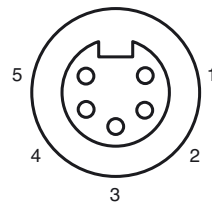Electrical connection**Electrical connection**

1	—	WH
2	—	RD
3	—	GN/YE
4	—	OR
5	—	BK