




**Dimensions**

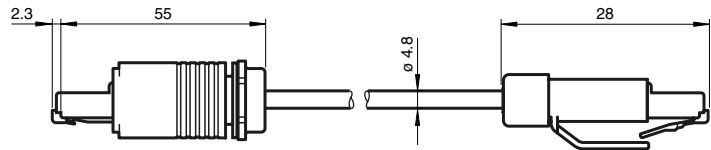

**Model Number**

**V45-GP-10M-PUR-ABG-V45-G**

Connecting cable, RJ-45 to RJ-45, PUR cable

**Features**

- Industrial-strength push pull EtherNet connector for field installations
- Hard-wearing PUR cable
- CAT5 cable
- Suitable for drag chains

**Technical data**

**Ambient conditions**

Ambient temperature	-40 ... 80 °C (-40 ... 176 °F) , stationary
	-30 ... 70 °C (-22 ... 158 °F) , moving

**Mechanical specifications**

Degree of protection	Device end: IP67 Switch cabinet end: IP20
Connection	Ethernet: RJ-45 , Category 5 , up to 100 MHz

<b>Material</b>	
Cable	PUR
Core insulation	PE
Cable	
Sheath diameter	6.5 mm
Bending radius	15 x cable diameter, moving
Color	green
Shield	Tinned copper braiding
Length	L 10 m
<b>Flammability</b>	
Cable	Flame-retardant as per IEC 60332-1