




### Model Number

#### V8HAN-G

Female connector, Harting, 8-pin, field attachable

### Dimensions

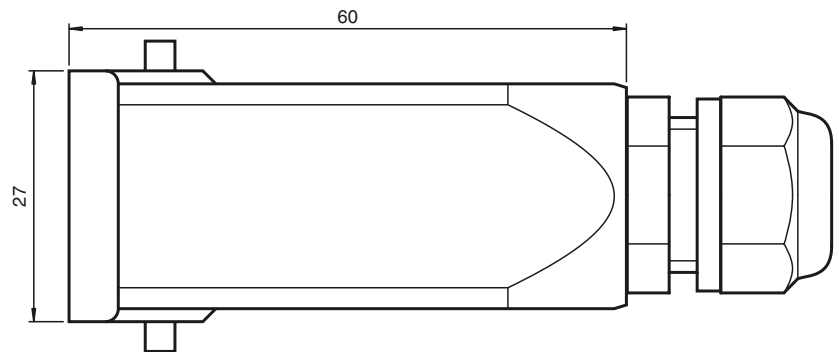

### Technical data

#### General specifications

Number of pins	8
Construction type	Socket, straight Harting Han 8D, size 3 A

#### Electrical specifications

Rated operating voltage	$U_e$	230/400 V
Operating voltage	$U_B$	50 V
Operating current		10 A
Volume resistance		< 3 m $\Omega$

#### Ambient conditions

Ambient temperature	-40 ... 125 °C (-40 ... 257 °F)
Pollution Degree	3

#### Mechanical specifications

Pin diameter	1 mm
Degree of protection	IP65
Connection	8 jacks, Harting 8 D Crimp connection for max. $\varnothing$ 1.1 mm, 8 mm stripped insulation PG11 cable gland

#### Material

Contacts	Cu alloy
Contact surface	Au
Body	aluminum and polycarbonate
Flammability	
Housing	94 V-0

#### Compliance with standards and directives

Standard conformity	
Degree of protection	EN 60529

### Electrical connection

