




**Dimensions**

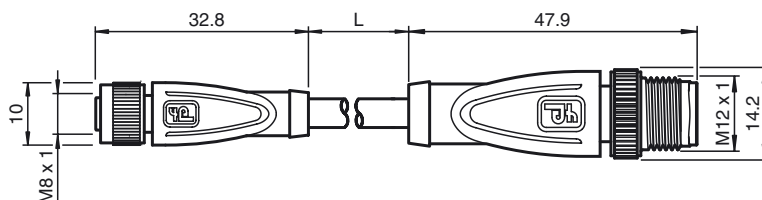

**Model Number**

**V3-GM-0,6M-PUR-V11-G**  
 Connection cable, M8 to M12, PUR cable, 3-pin


**Features**

- Knurled nut suitable for tool assembly
- Immunity to vibration, with mechanical latching
- Gold plated contacts
- Halogen-free
- Suitable for 2- and 3-wire technology

**Technical data**

<b>General specifications</b>		
Number of pins		3
<b>Electrical specifications</b>		
Operating voltage	$U_B$	max. 60 V AC/DC
Test voltage		> 1500 V <sub>eff</sub> AC
Operating current	$I_B$	max. 3 A
Volume resistance		< 5 mΩ
<b>Ambient conditions</b>		
Ambient temperature		cable, fixed: -40 ... 80 °C (-40 ... 176 °F) cable, flexing: -20 ... 80 °C (-4 ... 176 °F)
Pollution degree		3
<b>Mechanical specifications</b>		
Contact elements		spring-loaded contact socket
Pin diameter		1 mm
Degree of protection		IP67
<b>Material</b>		
Contacts		CuSn / Au
Contact surface		Au
Body		TPU, black
Cable		PUR
Slotted nut		Diecast zinc
Sleeve connector		Diecast zinc
Core insulation		PP
Cable		fine-strand, flexible
Sheath diameter		Ø 4.3 mm
Bending radius		> 15 x cable diameter, moving > 8 x cable diameter, fixed
Color		grey
Cores		3 x 0.25 mm <sup>2</sup>
Conductor construction		14 x 0.15 mm Ø
Length	L	0.6 m

**Electrical connection**

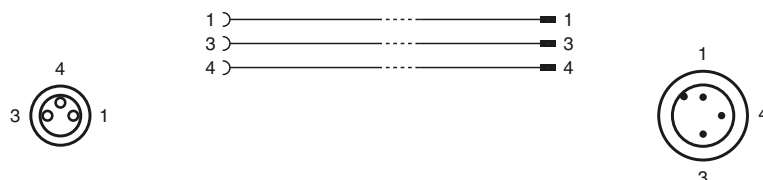

Release date: 2016-09-26 15:18 Date of issue: 2016-09-26 213932\_eng.xml