



Model Number

NBN15-30GK60-UR-3M

Features

- Relay output
- Sensing range 15 mm
- SPDT output
- AC/DC Model
- Switch load currents to 6 Amps

Accessories

BF 30
Mounting flange, 30 mm

AB-30
Mounting aid

Technical Data

General specifications

Switching function		change-over contact
Output type		relay
Rated operating distance	s_n	15 mm
Installation		non-flush
Output polarity		DC
Reduction factor r_{Al}		0.4
Reduction factor r_{Cu}		0.37
Reduction factor r_{304}		0.73
Output type		Relay output
Mechanical life		No load: 2×10^7 operations Full load: 1×10^5 switching cycles

Nominal ratings

Operating voltage	U_B	20 ... 132 V AC/DC
Hysteresis	H	1 ... 12 %
Reverse polarity protection		reverse polarity tolerant
Short-circuit protection		no
Operating current	I_L	≤ 50 mA
Switching state indicator		LED, red 360°

Output

Switching voltage		max 28 V DC , 250 V AC
Switching current		6 A , AC/DC, resistive load
Switching power		max 180 W

Ambient conditions

Ambient temperature		-40 ... 70 °C (-40 ... 158 °F)
---------------------	--	--------------------------------

Mechanical specifications

Connection type		3-meter cable, PVC heavy jacket, 5-conductor, #18 AWG
Core cross-section		0.75 mm ²
Housing material		PBT
Sensing face		PBT
Degree of protection		IP68


Compliance with standards and directives

Standard conformity		
Standards		EN 60947-5-2:2007 IEC 60947-5-2:2007

Approvals and certificates

UL approval		cULus Listed, General Purpose
CSA approval		cCSAus Listed, General Purpose

Dimensions

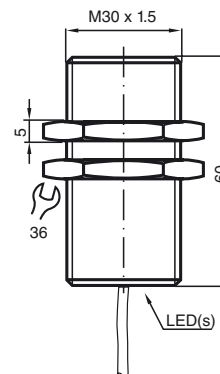

Electrical Connection

