



### Model Number


**V15-G-BK3M-PUR-U**

Female cordset, M12, 5-pin, PUR cable

### Features

- UL Recognized Component
- Knurled nut suitable for tool assembly
- Immunity to vibration, with mechanical latching
- Degree of protection IP67 / IP68 / IP69K
- Flame resistant cable
- Halogen-free

### Dimensions

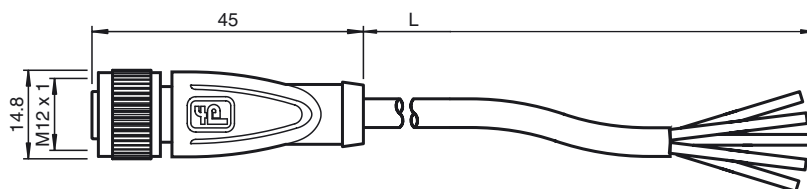

### Technical data

#### General specifications

Number of pins	5
Connection 1	socket
Construction type 1	straight
Threading 1	M12
Connection 2	cable end
UL File Number	E231213

#### Electrical specifications

Operating voltage	$U_B$	max. 48 V AC / 60 V DC
Operating current	$I_B$	max. 4 A
Volume resistance		< 5 m $\Omega$

#### Ambient conditions

Ambient temperature	Body: -40 ... 90 °C (-40 ... 194 °F) cable, fixed: -40 ... 80 °C (-40 ... 176 °F) cable, flexing: -25 ... 80 °C (-13 ... 176 °F)
Pollution degree	3


#### Mechanical specifications

Degree of protection	IP67 / IP68 / IP69k
Material	
Contacts	CuSn
Contact surface	Ni/Au
Body	TPU, black
Cable	PUR
Slotted nut	Zinc die-casting, nickel-plated
Core insulation	PP
Cable	extra-fine wire, flexible
Sheath diameter	$\varnothing$ 5 mm
Bending radius	> 10 x cable diameter, moving > 5 x cable diameter, fixed
Color	dark grey (RAL 7021)
Cores	22 AWG
Number of cores	5
Core cross-section	0.34 mm <sup>2</sup>
Conductor construction	42 x 0.1 mm $\varnothing$
Length	L 3 m
Flammability	
Contact carrier	HB
Housing	V-2
Cable	FT2

#### Compliance with standards and directives

Standard conformity	
Degree of protection	EN 60529:2000

### Electrical connection

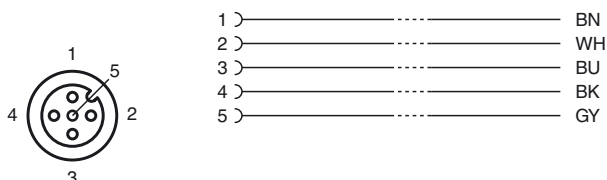

Flammability	Body: UL 94 Line: UL 1581 Section 1061; IEC 60332-1-2:2004
Halogen-free	IEC 60754-1:1994
Specification	connector M12 x 1 : IEC 61076-2-101
<b>Approvals and certificates</b>	
UL approval	UL Recognized General purpose
Maximum permissible operating voltage	≤ 30 V
Maximum permissible ambient temperature	≤ 80 °C (≤ 176 °F)

**Accessories**

**MH V1-SCREWDRIVER**  
torque screwdriver (0.6 Nm)

**MH V1-BIT M12**  
plug-in cap M12

**V1/V3-LABELHOLDER**  
Label holder

**V1/V3-LABEL**  
Label plate

**MH V1-Holder**  
Modular universal holder for M12 connectors

**V1-MARKING-RING-BLUE**  
Marking ring for M12 plug

**V1-MARKING-RING-GREEN**  
Marking ring for M12 plug

**V1-MARKING-RING-ORANGE**  
Marking ring for M12 plug

**V1-MARKING-RING-RED**  
Marking ring for M12 plug

**V1-MARKING-RING-WHITE**  
Marking ring for M12 plug

**V1-MARKING-RING-YELLOW**  
Marking ring for M12 plug