



### Model Number


**V93-G-YE10M-STOOW**

Female cordset, 7/8", 3-pin, STOOW cable

### Features

- Thread 7/8 inch

### Dimensions

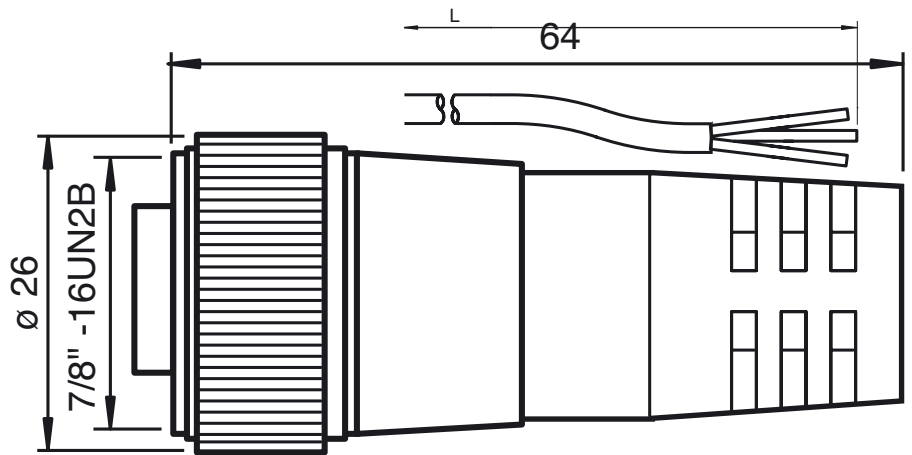

### Technical data

#### General specifications

|                     |           |
|---------------------|-----------|
| Number of pins      | 3         |
| Connection 1        | socket    |
| Construction type 1 | straight  |
| Threading 1         | 7/8 inch  |
| Connection 2        | cable end |

#### Electrical specifications

|                   |       |                |
|-------------------|-------|----------------|
| Operating voltage | $U_B$ | max. 600 V     |
| Operating current | $I_B$ | 13 A           |
| Volume resistance |       | < 5 m $\Omega$ |

#### Ambient conditions

|                     |                                 |
|---------------------|---------------------------------|
| Ambient temperature | -40 ... 105 °C (-40 ... 221 °F) |
|---------------------|---------------------------------|


#### Mechanical specifications

|                      |                                  |
|----------------------|----------------------------------|
| Degree of protection | IP67                             |
| Material             |                                  |
| Contacts             | Cu alloy gold plated             |
| Body                 | PVC, yellow                      |
| Cable                | PVC                              |
| Slotted nut          | nickel-plated brass              |
| Core insulation      | PVC                              |
| Cable                | fine-strand, flexible            |
| Sheath diameter      | Ø 9.9 mm                         |
| Bending radius       | 10 x cable diameter              |
| Color                | yellow                           |
| Cores                | 3 x 1.5 mm <sup>2</sup> (16 AWG) |
| Length               | L 10 m                           |
| Note                 | STOOW UL Standard                |

#### Approvals and certificates

|             |                               |
|-------------|-------------------------------|
| UL approval | cULus Listed, General Purpose |
|-------------|-------------------------------|

### Electrical connection

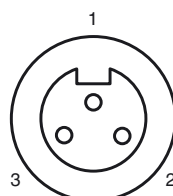

|   |       |
|---|-------|
| 1 | GN/YE |
| 2 | BK    |
| 3 | WH    |