




Model Number

V94-W-YE4M-STOOW

Female cordset, 7/8", 4-pin, STOOW cable

Dimensions

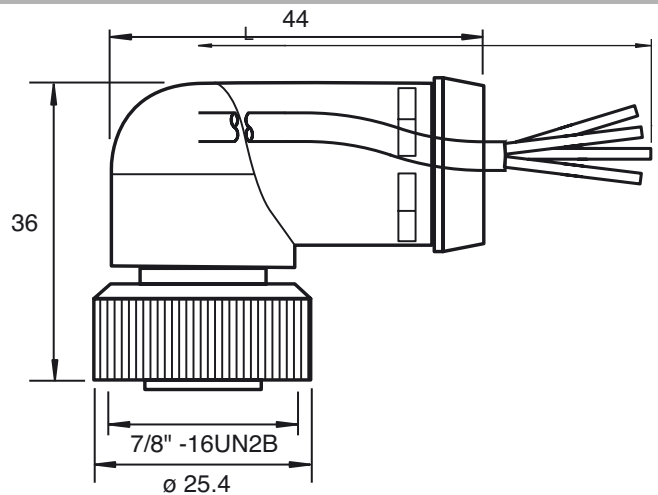

Technical data

General specifications

Number of pins	4
Connection 1	socket
Construction type 1	right angle
Threading 1	7/8 inch
Connection 2	cable end

Electrical specifications

Operating voltage	U_B	max. 600 V
Operating current	I_B	10 A
Volume resistance		< 5 m Ω

Ambient conditions

Ambient temperature	-40 ... 105 °C (-40 ... 221 °F)
---------------------	---------------------------------

Mechanical specifications

Degree of protection	IP67
Material	
Contacts	Cu alloy gold plated
Body	PVC, yellow
Cable	PVC
Slotted nut	nickel-plated brass
Core insulation	PVC
Cable	fine-strand, flexible
Sheath diameter	Ø 10.7 mm
Bending radius	10 x cable diameter
Color	yellow
Cores	4 x 1.5 mm ² (16 AWG)
Length	L 4 m
Note	STOOW UL Standard

Approvals and certificates

UL approval	cULus Listed, General Purpose
-------------	-------------------------------

Electrical connection

