



Model Number


V95-W-YE4M-STOOW

Female cordset, 7/8", 5-pin, STOOW cable

Features

- Thread 7/8 inch

Dimensions

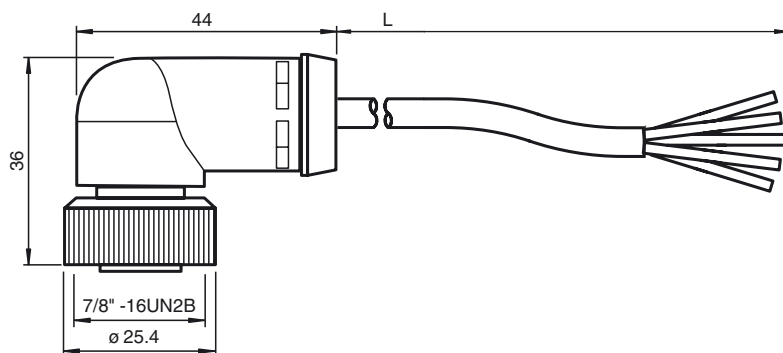

Technical data

General specifications

Number of pins	5
Connection 1	socket
Construction type 1	right angle
Threading 1	7/8 inch
Connection 2	cable end

Electrical specifications

Operating voltage	U_B	max. 600 V
Operating current	I_B	8 A
Volume resistance		< 5 m Ω

Ambient conditions

Ambient temperature	-40 ... 105 °C (-40 ... 221 °F)
---------------------	---------------------------------

Mechanical specifications

Degree of protection	IP67	
Material		
Contacts	Cu alloy gold plated	
Body	PVC, yellow	
Cable	PVC	
Slotted nut	nickel-plated brass	
Core insulation	PVC	
Cable	fine-strand, flexible	
Sheath diameter	Ø 12.9 mm	
Bending radius	10 x cable diameter	
Color	yellow	
Cores	5 x 1.5 mm ² (16 AWG)	
Length	L	4 m
Note	STOOW UL Standard	

Approvals and certificates

UL approval	cULus Listed, General Purpose
-------------	-------------------------------

Electrical connection

