



Model Number


V1-Y-V11S/V11S

Y-Splitter, M12 socket to 2 x M12 plug

Features

- Immunity to vibration

Dimensions

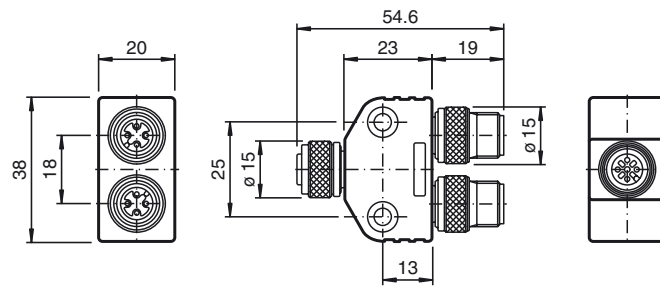

Technical data

General specifications

Number of pins	5
Coding	A

Electrical specifications

Operating voltage	U_B	60 V
Operating current	I_B	4 A
Volume resistance		< 5 m Ω

Ambient conditions

Ambient temperature	-25 ... 90 °C (-13 ... 194 °F)
Pollution degree	3

Mechanical specifications

Degree of protection	IP65/IP67
Connection	2 x M12 straight plug 1 x M12 straight socket

Material

Contacts	CuZn
Contact surface	Ni/Au
Body	TPU
Slotted nut	Zinc die-casting, nickel-plated
Flammability	
Housing	94 V-2

Compliance with standards and directives

Standard conformity	
Degree of protection	EN 60529

Electrical connection

