



Model Number


V19-G-BK30M-PUR-U/ABG

Female cordset, M12, 8-pin, shielded, PUR cable

Features

- UL Recognized Component
- Knurled nut suitable for tool assembly
- Immunity to vibration, with mechanical latching
- Flame resistant cable
- Halogen-free
- Shield attached to coupling nut

Dimensions

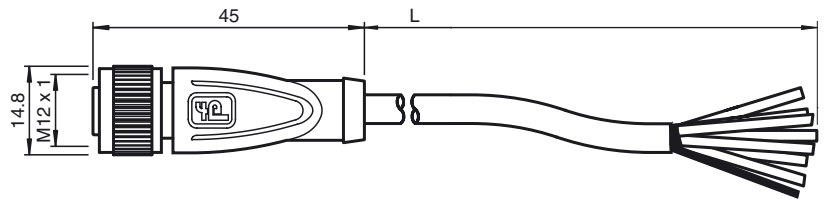

Technical data

General specifications

Number of pins	8 + shield
UL File Number	E231213

Electrical specifications

Operating voltage	U_B	max. 30 V DC
Operating current	I_B	max. 2 A
Volume resistance		< 5 m Ω

Ambient conditions

Ambient temperature	-40 ... 90 °C (-40 ... 194 °F) cable, fixed: -40 ... 80 °C (-40 ... 176 °F) cable, flexing: -20 ... 80 °C (-4 ... 176 °F)
---------------------	---------------------------------------------------------------------------------------------------------------------------------

Pollution degree	3
------------------	---

Mechanical specifications

Contact elements	spring-loaded contact socket
Pin diameter	0,8 mm
Degree of protection	IP67

Material

Contacts	CuSn / Au
Contact surface	Au
Body	TPU, black
Cable	PUR
Slotted nut	Diecast zinc
Core insulation	PP

Cable fine-strand, flexible

Sheath diameter	\varnothing 6 mm
Bending radius	> 10 x cable diameter, moving
Color	black
Number of cores	8
Core cross-section	0.25 mm ²
Conductor construction	14 x 0.15 mm \varnothing
Shield	grid covering 85 %
Length	L 30 m

Flammability

Contact carrier	94 HB
Housing	94 V-2

Approvals and certificates

UL approval	cURus AWM 20549 AWM I/II A/B 80°C 300V FT2 (cable)
-------------	----------------------------------------------------

Electrical connection

