

## PSS u2 ES 16DI

328303



Electronic module digital inputs and outputs, with standard function, 16 inputs.

### Technical details

Certifications:	CE
Application range:	Standard
Width dimension:	12.5 mm
Height dimension:	110.8 mm
Depth dimension:	72.5 mm
Gross weight:	50 g
Net weight:	33 g
Ambient temperature:	0 - 60 °C

### Accessories



328840

PSS u2 T 8 (1 pc.)



328850


PSS u2 T 16 (1 pc.)

### Optional accessories



328911

PSS u2 A LC E2 (10 pcs.)

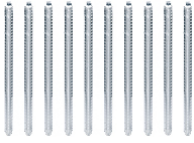

328912

PSS u2 A LC T3 (10 pcs.)



328811

PSS u2 B 1



328851

PSS u2 T 16 (10 pcs.)



328914

PSS u2 A LA E2 (10 pcs.)



328910

PSS u2 A LC E1 (10 pcs.)



328860

PSS u2 A CE E (10 pcs.)




328810

PSS u2 B 4



328913

PSS u2 A LA E1 (10 pcs.)

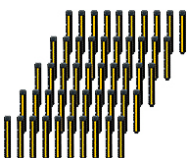

328852

PSS u2 T 16 (5 x 10 pcs.)