

PSS u2 ES 6DI 120V AC

328308



Standard I/O-Electronic Module, 6 Digital Inputs 120V AC

Technical details

Certifications:	CE;cULus Listed
Application range:	Standard
Width dimension:	12.5 mm
Height dimension:	110.8 mm
Depth dimension:	72.5 mm
Gross weight:	52 g
Net weight:	35 g
Ambient temperature:	0 - 60 °C

Accessories



328840

PSS u2 T 8 (1 pc.)

XXXXXXXXXX

328861


PSS u2 A CE T (10 pcs.)

Optional accessories



328911

PSS u2 A LC E2 (10 pcs.)

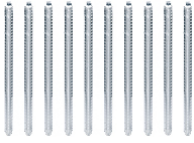

328912

PSS u2 A LC T3 (10 pcs.)



328811

PSS u2 B 1



328914

PSS u2 A LA E2 (10 pcs.)



328910

PSS u2 A LC E1 (10 pcs.)



328860

PSS u2 A CE E (10 pcs.)



328810

PSS u2 B 4




328841

PSS u2 T 8 (10 pcs.)



328913

PSS u2 A LA E1 (10 pcs.)

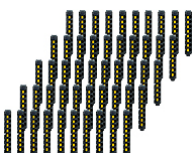

328842

PSS u2 T 8 (5 x 10 pcs.)