

PSEN ma1.4p-57/ 1switch

506311



Magnetic safety switch 2 N/O, 1 signal contact N/O, square design, LED, IP67, operating distance depending on the actuator, for series connection with PSEN ix1, height design 18 mm. PU = 1 actuator.

Technical details

Housing material:	PBT
Certifications:	CE;cULus Listed;EAC (Eurasian);TÜV
Sensor principle:	magnetic
Number of N/O:	2
Connection type:	M8, 8pol. male
Switching voltage:	24 V
Type of switching voltage:	DC
Assured switching distance:	3.0 mm
Assured release distance:	12.0 mm
Protection type, housing:	IP65;IP67
Status indicator:	With LED
Design:	square
Width dimension:	26.4 mm
Height dimension:	37.0 mm
Depth dimension:	18.0 mm
Gross weight:	51 g
Net weight:	35 g
Ambient temperature:	-10 - 55 °C
Operating modes:	Series connection

Accessories



533110

PSEN Kabel Winkel/cable angleplug 2m



533111

PSEN Kabel Gerade/cable straightplug 2m



533120

PSEN Kabel Winkel/cable angleplug 5m



533121

PSEN Kabel Gerade/cable straightplug 5m



533130

PSEN Kabel Winkel/cable angleplug 10m



533131

PSEN Kabel Gerade/cable straightplug 10m



533140

PSEN Kabel Winkel/cable angleplug 30m




533141

PSEN Kabel Gerade/cable straightplug 30m




535120

PSEN ix1 Interface for 4 PSEN 1

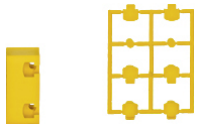

506300

PSEN ma1.4-03mm 1actuator

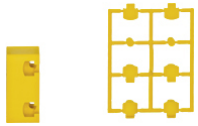

506301

PSEN ma1.4-10mm 1actuator

Optional accessories



533150

PSEN cable M8-8sf, 2m



533151

PSEN cable M8-8sf, 5m



533152

PSEN cable M8-8sf, 10m



533153

PSEN cable M8-8sf, 20m



533154

PSEN cable M8-8sf, 30m



533155

PSEN cable M8-8sf M8-sm, 0.5m



533156

PSEN cable M8-8sf M8-8sm, 1m



533157

PSEN cable M8-8sf M8-8sm, 2m



535120

PSEN ix1 Interface for 4 PSEN 1



540329

PSEN converter M8-8sf -- M12-8sm



533162

PSEN cable M8-8af, 10m



533159

PSEN cable M8-8sf M8-8sm, 10m



533158

PSEN cable M8-8sf M8-8sm, 5m



533160

PSEN cable M8-8sf M8-8sm, 20m



533161

PSEN cable M8-8sf M8-8sm, 30m