

PSEN ma1.4n-51/ 1switch

506313



Magnetic safety switch 2 N/O, 1 signal contact N/O, 5-pin M12 connector, square design, LED IP67, operating distance depending on the actuator, height design 18 mm. PU = 1 actuator.

Technical details

Housing material:	PBT
Certifications:	CE;cULus Listed;EAC (Eurasian);TÜV
Sensor principle:	magnetic
Number of N/O:	2
Connection type:	M12, 5pol. male
Switching voltage:	24 V
Type of switching voltage:	DC
Assured switching distance:	3.0 mm
Assured release distance:	12.0 mm
Protection type, housing:	IP65;IP67
Status indicator:	With LED
Design:	square
Width dimension:	26.4 mm
Height dimension:	37.0 mm
Depth dimension:	18.0 mm
Gross weight:	60 g
Net weight:	35 g
Ambient temperature:	-10 - 55 °C
Operating modes:	Single connection

Accessories



630297

PSEN op cable axial M12 5-pole 30m



630310

PSEN op cable axial M12 5-pole 3m



630311

PSEN op cable axial M12 5-pole 5m



630312

PSEN op cable axial M12 5-pole 10m



630347

PSEN op cable angle M12 5-pole 3m



630348

PSEN op cable angle M12 5-pole 5m



630349

PSEN op cable angle M12 5-pole 10m




630350

PSEN op cable angle M12 5-pole 30m




630298

PSEN cable M12-5sf 20m

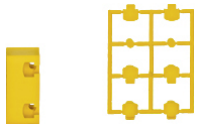

506300

PSEN ma1.4-03mm 1actuator

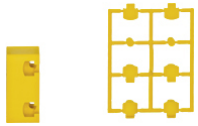

506301

PSEN ma1.4-10mm 1actuator

Optional accessories



380208

PSS67 Cable M12sf M12sm, 3m



380209

PSS67 Cable M12sf M12sm, 5m



380210

PSS67 Cable M12sf M12sm, 10m



380211

PSS67 Cable M12sf M12sm, 30m



380212

PSS67 Cable M12af M12am, 3m



380213

PSS67 Cable M12af M12am, 5m



380214

PSS67 Cable M12af M12am, 10m



380215

PSS67 Cable M12af M12am, 30m



630297

PSEN op cable axial M12 5-pole 30m



630310

PSEN op cable axial M12 5-pole 3m



630311

PSEN op cable axial M12 5-pole 5m



630312

PSEN op cable axial M12 5-pole 10m



630347

PSEN op cable angle M12 5-pole 3m



630348

PSEN op cable angle M12 5-pole 5m



630349

PSEN op cable angle M12 5-pole 10m



630350

PSEN op cable angle M12 5-pole 30m



773600

PDP67 F 8DI ION



380220

PSS67 cable M12-5sf, M12-5sm, 20m



630298

PSEN cable M12-5sf 20m



380713

PDP67 Cable M12-5sf M12-5sm, 2m



380710

PDP67 Cable M12-5sf M12-5sm, 0.5m



380712

PDP67 Cable M12-5sf M12-5sm, 1.5m



380711

PDP67 Cable M12-5sf M12-5sm, 1m



630365

PSEN op cable angle M12 5-pole 50m



630364

PSEN op cable axial M12 5-pole 50m
