


PSEN op4F-s-14-030/1

630741

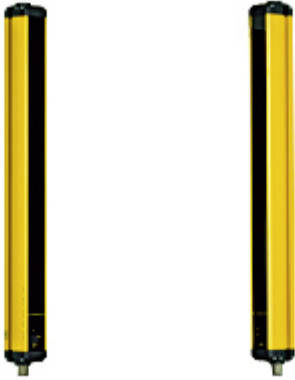

Safety light curtain, type 4, PL e, finger protection (resolution 14 mm)
Protected field height 300 mm, supply voltage 24 V, connector M12,
sender: 4-pin, receiver: 8-pin, Connection cable not supplied with the unit.

Technical details

Certifications:	CE;cULus Listed;EAC (Eurasian);TÜV
Sensor principle:	Optical
Type in accordance with EC 61496:	4
Number of beams:	32
Resolution of safety device:	14 mm
Resolution, protection type:	Finger
Height of protected field:	300 mm
Operating range (m):	0,2 - 6,0
Reaction time:	15.00 ms
Number of OSSD outputs:	2
Muting:	No
Blanking:	No
Supply voltage (V):	24,0
Supply voltage type:	DC
Protection type, housing:	IP65
Application in accordance with:	CLC/TS 61496-2;EN 61496-1
Width dimension:	32.3 mm
Height dimension:	383.2 mm
Depth dimension:	36.9 mm
Gross weight:	2440 g

Net weight:	1740 g
Ambient temperature:	0 - 55 °C

Accessories



630303

PSEN op cable axial M12 4-p. shield. 3m



630304

PSEN op cable axial M12 4-p. shield. 5m



630305

PSEN op cable axial M12 4-p. shield. 10m



630306

PSEN op cable angle M12 4-p. shield. 3m



630307

PSEN op cable angle M12 4-p. shield. 5m



630308

PSEN op cable angle M12 4-p. shield. 10m











630309

PSEN op cable axial M12 4-p. shield. 30m



630313

PSEN op cable axial M12 8-p. shield. 3m

	630314	PSEN op cable axial M12 8-p. shield. 5m
	630315	PSEN op cable axial M12 8-p. shield. 10m
	630316	PSEN op cable angle M12 8-p. shield. 3m
	630317	PSEN op cable angle M12 8-p. shield. 5m
	630318	PSEN op cable angle M12 8-p. shield. 10m
	630319	PSEN op cable angle M12 4-p. shield. 30m
	630328	PSEN op cable axial M12 8-p. shield. 30m
	630329	PSEN op cable angle M12 8-p. shield. 30m