


PSEN op4B-T-080/1

630811

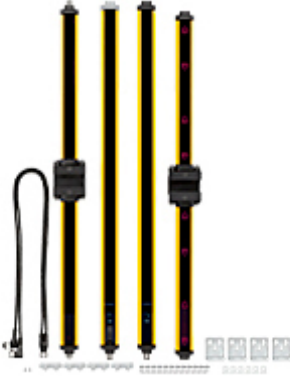

Set of light curtain, bracket and Muting arm T-type in accordance with DIN EN 61496, type 4, 800 mm Supply voltage 24 V, connector M12.

Technical details

Certifications:	CE;cULus Listed;TÜV
Sensor principle:	Optical
Type in accordance with EC 61496:	4
Number of beams:	3
Resolution of safety device:	415 mm
Height of protected field:	815 mm
Operating range (m):	0,5 - 3,0
Reaction time:	14.00 ms
Number of OSSD outputs:	2
Supply voltage (V):	24,0
Supply voltage type:	DC
Protection type, housing:	IP65
Application in accordance with:	EN 61496-1;IEC 61496-2
Width dimension:	35.0 mm
Height dimension:	953.0 mm
Depth dimension:	41.2 mm
Gross weight:	7100 g
Net weight:	6500 g
Ambient temperature:	-10 - 55 °C