


Contacts type: R = snap action L = slow action LA = slow action closer	With stainless steel roller on request 	3x3 mm square rod 		With stainless steel roller on request
Contact blocks	45 R FA 4531-KDM (⊕) 1NO+1NC 46 L FA 4631-KDM (⊕) 1NO+1NC 48 LA FA 4831-KDM (⊕) 1NO+1NC 41 R FA 4131-KDM 1NO+1NC	45 R FA 4533-KDM 1NO+1NC 46 L FA 4633-KDM 1NO+1NC 48 LA FA 4833-KDM 1NO+1NC 41 R FA 4133-KDM 1NO+1NC	45 R FA 4534-KDM 1NO+1NC 46 L FA 4634-KDM 1NO+1NC 48 LA FA 4834-KDM 1NO+1NC 41 R FA 4134-KDM 1NO+1NC	45 R FA 4540-KDM (⊕) 1NO+1NC 46 L FA 4640-KDM (⊕) 1NO+1NC 48 LA FA 4840-KDM (⊕) 1NO+1NC 41 R FA 4140-KDM 1NO+1NC
Max speed	page 6/7 - type 1	1,5 m/s	1,5 m/s	page 6/7 - type 1
Min. force	0,03 Nm (0,25 Nm ⊕)	0,03 Nm	0,03 Nm	0,03 Nm (0,25 Nm ⊕)
Travel diagrams	page 6/8 - group 4	page 6/8 - group 4	page 6/8 - group 4	page 6/8 - group 4

Ø 3 mm stainless steel round rod 	With stainless steel roller on request 	With stainless steel roller on request 	With stainless steel roller on request 	
Contact blocks	45 R FA 4550-KDM 1NO+1NC 46 L FA 4650-KDM 1NO+1NC 48 LA FA 4850-KDM 1NO+1NC 41 R FA 4150-KDM 1NO+1NC	45 R FA 4551-KDM (⊕) 1NO+1NC 46 L FA 4651-KDM (⊕) 1NO+1NC 48 LA FA 4851-KDM (⊕) 1NO+1NC 41 R FA 4151-KDM 1NO+1NC	45 R FA 4552-KDM (⊕) 1NO+1NC 46 L FA 4652-KDM (⊕) 1NO+1NC 48 LA FA 4852-KDM (⊕) 1NO+1NC 41 R FA 4152-KDM 1NO+1NC	45 R FA 4554-KDM (⊕) 1NO+1NC 46 L FA 4654-KDM (⊕) 1NO+1NC 48 LA FA 4854-KDM (⊕) 1NO+1NC 41 R FA 4154-KDM 1NO+1NC
Max speed	1,5 m/s	page 6/7 - type 1	page 6/7 - type 1	page 6/7 - type 1
Min. force	0,03 Nm	0,03 Nm (0,25 Nm ⊕)	0,03 Nm (0,25 Nm ⊕)	0,03 Nm (0,25 Nm ⊕)
Travel diagrams	page 6/8 - group 4	page 6/8 - group 4	page 6/8 - group 4	page 6/8 - group 4

With stainless steel roller on request 	With stainless steel roller on request 	With stainless steel roller on request 	Glass fibre rod 	
Contact blocks	45 R FA 4555-KDM (⊕) (1) 1NO+1NC 46 L FA 4655-KDM (⊕) (1) 1NO+1NC 48 LA FA 4855-KDM (⊕) (1) 1NO+1NC 41 R FA 4155-KDM 1NO+1NC	45 R FA 4556-KDM (⊕) 1NO+1NC 46 L FA 4656-KDM (⊕) 1NO+1NC 48 LA FA 4856-KDM (⊕) 1NO+1NC 41 R FA 4156-KDM 1NO+1NC	45 R FA 4557-KDM (⊕) 1NO+1NC 46 L FA 4657-KDM 1NO+1NC 48 LA FA 4857-KDM (⊕) 1NO+1NC 41 R FA 4157-KDM 1NO+1NC	45 R FA 4569-KDM 1NO+1NC 46 L FA 4669-KDM 1NO+1NC 48 LA FA 4869-KDM 1NO+1NC 41 R FA 4169-KDM 1NO+1NC
Max speed	page 6/7 - type 1	page 6/7 - type 1	page 6/7 - type 1	1,5 m/s
Min. force	0,03 Nm (0,25 Nm ⊕)	0,03 Nm (0,25 Nm ⊕)	0,03 Nm (0,25 Nm ⊕)	0,03 Nm
Travel diagrams	page 6/8 - group 4	page 6/8 - group 4	page 6/8 - group 4	page 6/8 - group 4

Accessories

Article	Description
VF D16	Spacers for FA-FF series

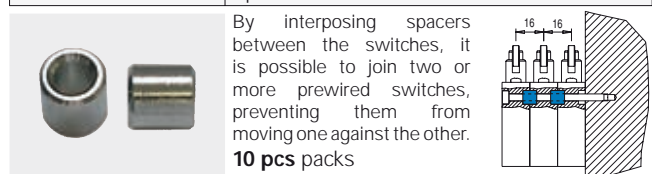

Article	Description
VF CA...M	Female wired connectors

