

Contact type:

R = snap action
L = slow action

Contact type	Other rollers available. See on page 56	Rope switch for signalling
3 R	FC 357-M2 1NO-1NC	FC 376-M2 1NO-1NC
33 L	FC 3357-M2 ⊕ 1NO+1NC	FC 3376-M2 1NO+1NC
34 L	FC 3457-M2 ⊕ 2NC	FC 3476-M2 2NC
Max. speed	page 237 - type 1	0.5 m/s
Min. force	0.09 Nm (0.25 Nm ⊕)	initial 20 N - final 40 N
Travel diagrams	page 238 - group 4	page 238 - group 6

All measures in the drawings are in mm

Position switches with revolving lever without actuator

All measures in the drawings are in mm

Contact type	Regular head	Compact head
3 R	FC 338-M2 1NO-1NC	FC 358-M2 1NO-1NC
33 L	FC 3338-M2 ⊕ 1NO+1NC	FC 3358-M2 ⊕ 1NO+1NC
34 L	FC 3438-M2 ⊕ 2NC	FC 3458-M2 ⊕ 2NC
Min. force	0.09 Nm (0.25 Nm ⊕)	0.05 Nm (0.25 Nm ⊕)
Travel diagrams	page 238 - group 4	page 238 - group 4

IMPORTANT

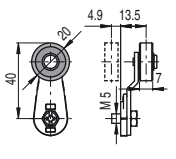
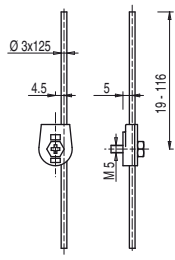
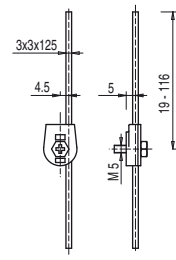
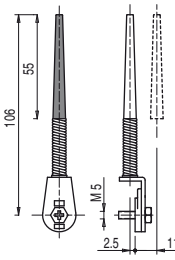
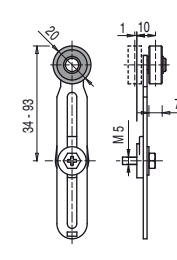
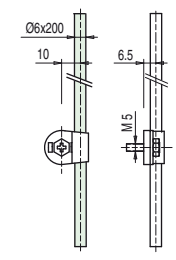
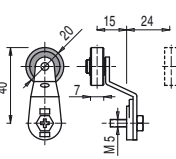
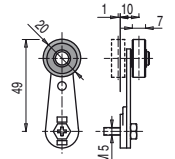
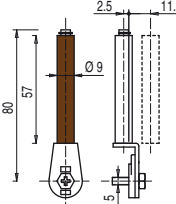
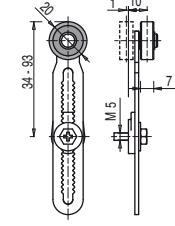
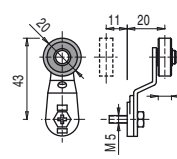
For safety applications: join only switches and actuators marked with symbol ⊕ aside the product code.
For more information about safety applications see details on page 235.

All measures in the drawings are in mm

Loose actuators

All measures in the drawings are in mm

IMPORTANT: These loose actuators can be used with items of series FD, FP, FL, FC only.

Technopolymer roller Ø 20 mm	Adjustable round rod Ø 3x125 mm	Adjustable square rod 3x3x125 mm	Flexible rod with pointed end	Adjustable actuator with technopolymer roller	Adjustable fiber glass rod
					
VF L31 ⊕	VF L32 (3)	VF L33 (3)	VF L34	VF L35 ⊕ (1) (3)	VF L36 (3)
Technopolymer roller Ø 20 mm	Technopolymer roller Ø 20 mm	Porcelain roller	Adjustable safety actuator with technopolymer roller	Technopolymer roller Ø 20 mm	
					
VF L51 ⊕	VF L52 ⊕	VF L53 ⊕ (2)	VF L56 ⊕ (3)	VF L57 ⊕	

Items with code on green background are stock items

Accessories See page 225