
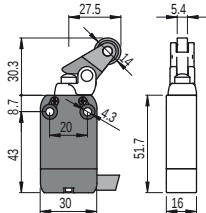
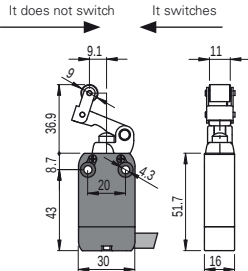
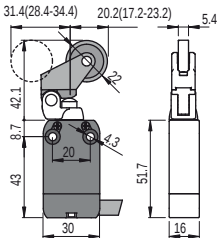
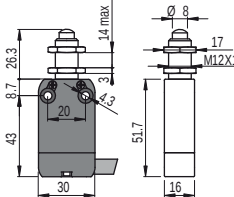
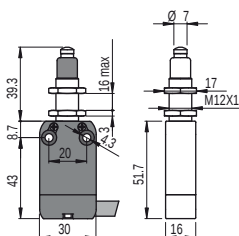
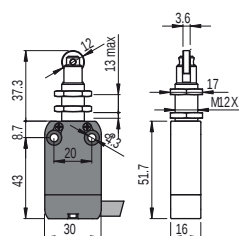
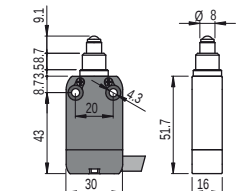


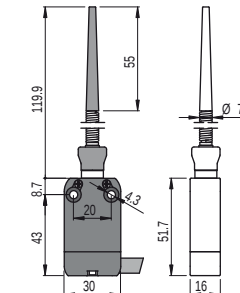

		With stainless steel roller on request		Operation in one direction				Fixed only by threaded head	
Contact type:									
Contact blocks									
B11	R	NA B110CH-DN2	➔ 1NO+1NC	NA B110CP-DN2	➔ 1NO+1NC	NA B110CV-DN2	➔ 1NO+1NC	NA B110EB-DN2	➔ 1NO+1NC
B02	R	NA B020CH-DN2	➔ 2NC	NA B020CP-DN2	➔ 2NC	NA B020CV-DN2	➔ 2NC	NA B020EB-DN2	➔ 2NC
B12	R	NA B120CH-DN2	➔ 1NO+2NC	NA B120CP-DN2	➔ 1NO+2NC	NA B120CV-DN2	➔ 1NO+2NC	NA B120EB-DN2	➔ 1NO+2NC
B22	R	NA B220CH-DN2	➔ 2NO+2NC	NA B220CP-DN2	➔ 2NO+2NC	NA B220CV-DN2	➔ 2NO+2NC	NA B220EB-DN2	➔ 2NO+2NC
G11	L	NA G110CH-DN2	➔ 1NO+1NC	NA G110CP-DN2	➔ 1NO+1NC	NA G110CV-DN2	➔ 1NO+1NC	NA G110EB-DN2	➔ 1NO+1NC
G02	L	NA G020CH-DN2	➔ 2NC	NA G020CP-DN2	➔ 2NC	NA G020CV-DN2	➔ 2NC	NA G020EB-DN2	➔ 2NC
G12	L	NA G120CH-DN2	➔ 1NO+2NC	NA G120CP-DN2	➔ 1NO+2NC	NA G120CV-DN2	➔ 1NO+2NC	NA G120EB-DN2	➔ 1NO+2NC
G22	L	NA G220CH-DN2	➔ 2NO+2NC	NA G220CP-DN2	➔ 2NO+2NC	NA G220CV-DN2	➔ 2NO+2NC	NA G220EB-DN2	➔ 2NO+2NC
Max. speed		page 243 - type 3		page 243 - type 3		page 243 - type 3		page 243 - type 4	
Min. force		5 N (25 N ➔)		3 N (25 N ➔)		3 N (25 N ➔)		7 N (25 N ➔)	
Travel diagrams		page 244 - group 2		page 244 - group 6		page 244 - group 3		page 244 - group 1	

Contact blocks	Fixed only by threaded head				Fixed only by threaded head				Plunger with Ø 6 mm ball				With external rubber gasket			
																
B11	R	NA B110EE-DN2	➔ 1NO+1NC	NA B110FB-DN2	➔ 1NO+1NC	NA B110GB-DN2	➔ 1NO+1NC	NA B110HB-DN2	➔ 1NO+1NC							
B02	R	NA B020EE-DN2	➔ 2NC	NA B020FB-DN2	➔ 2NC	NA B020GB-DN2	➔ 2NC	NA B020HB-DN2	➔ 2NC							
B12	R	NA B120EE-DN2	➔ 1NO+2NC	NA B120FB-DN2	➔ 1NO+2NC	NA B120GB-DN2	➔ 1NO+2NC	NA B120HB-DN2	➔ 1NO+2NC							
B22	R	NA B220EE-DN2	➔ 2NO+2NC	NA B220FB-DN2	➔ 2NO+2NC	NA B220GB-DN2	➔ 2NO+2NC	NA B220HB-DN2	➔ 2NO+2NC							
G11	L	NA G110EE-DN2	➔ 1NO+1NC	NA G110FB-DN2	➔ 1NO+1NC	NA G110GB-DN2	➔ 1NO+1NC									
G02	L	NA G020EE-DN2	➔ 2NC	NA G020FB-DN2	➔ 2NC	NA G020GB-DN2	➔ 2NC	NA G020HB-DN2	➔ 2NC							
G12	L	NA G120EE-DN2	➔ 1NO+2NC	NA G120FB-DN2	➔ 1NO+2NC	NA G120GB-DN2	➔ 1NO+2NC									
G22	L	NA G220EE-DN2	➔ 2NO+2NC	NA G220FB-DN2	➔ 2NO+2NC	NA G220GB-DN2	➔ 2NO+2NC									
Max. speed		page 243 - type 4		page 243 - type 2		page 243 - type 2		1 m/s								
Min. force		7 N (25 N ➔)		7 N (25 N ➔)		7 N (25 N ➔)		0.03 Nm								
Travel diagrams		page 244 - group 1		page 244 - group 1		page 244 - group 1		page 244 - group 4								

All measures in the drawings are in mm