



Accessories

Article	Description
VN DT1F	Spacer for NA-NF series
VF D16B	Spacer for NB series

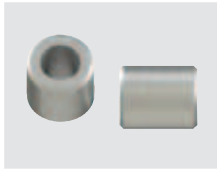

By interposing the spacers between one switch and the next, it is possible to have 2 or more prewired switches, preventing them from moving in relation to one another.

10 pcs. packs

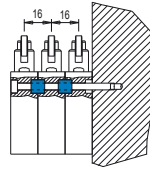

M12 connectors with cable

for details see page 225



Technical data:

- Polyurethane connector body (4/5/8 poles)
- Polypropylene connector body (12 poles)
- Class 6 rated copper of the wires according to IEC 60228 for mobile installation (4/5/8 poles)
- Class 5 rated copper of the wires according to IEC 60228 for fixed installation (12 poles)
- Gold-plated contacts (resistance < 5 mΩ)
- Self locking ring nut
- High flexibility wire suitable to be used in movable chains, with PVC sheath conforming to IEC 60332-3 and CEI 20-22II standards. With polyurethane sheath on request (4/5/8 poles)
- PVC cable, fixed installation (12 poles)

Code structure

Attention! The feasibility of a code number does not mean the effective availability of a product. Please contact our sales office.

VF CA4PD3M

No. of poles	
4	4 poles
5	5 poles
8	8 poles
12	12 poles

Sheath coating	
P	PVC (standard)
U	PUR

Connector type	
D	straight (standard)
G	angled

Connection type		No. of poles			
M	M12x1				
Cable length (L)		4	5	8	12
1	1 metre				
2	2 metres				
3	3 metres (standard)	•	•		
4	4 metres				
5	5 metres (standard)	•	•	•	•
...					
0	10 metres (standard)	•	•	•	•

Other lengths on request

Stock items

VF CA4PD3M
VF CA4PD5M
VF CA4PD0M
VF CA5PD3M
VF CA5PD5M
VF CA5PD0M
VF CA8PD5M
VF CA8PD0M
VF CA12PD5M
VF CA12PD0M

Attention! No stock item, minimum order quantity 100 pcs.

M12 sockets, field wireable



General data

Technopolymer connector body
Gold-plated contacts
Screw terminals for wiring
Max. operating voltages 250 Vac/dc (4 and 5 poles)
30 Vac/dc (8 poles)
Maximum current 4 A
Protection degree IP67 according to EN 60529
Ambient temperature -25°C ... +85°C
Wire cross-section from 0.25 mm² (24 AWG) to 0.5 mm² (20 AWG)

Article	Description	no. of poles
VF CBMP4DM04	Field wireable M12 socket, straight, for multipolar cables from Ø 4 to Ø 6.5 mm	4
VF CBMP5DM04	Field wireable M12 socket, straight, for multipolar cables from Ø 4 to Ø 6.5 mm	5
VF CBMP8DM04	Field wireable M12 socket, straight, for multipolar cables from Ø 4 to Ø 7 mm	8

Items with code on **green** background are stock items