
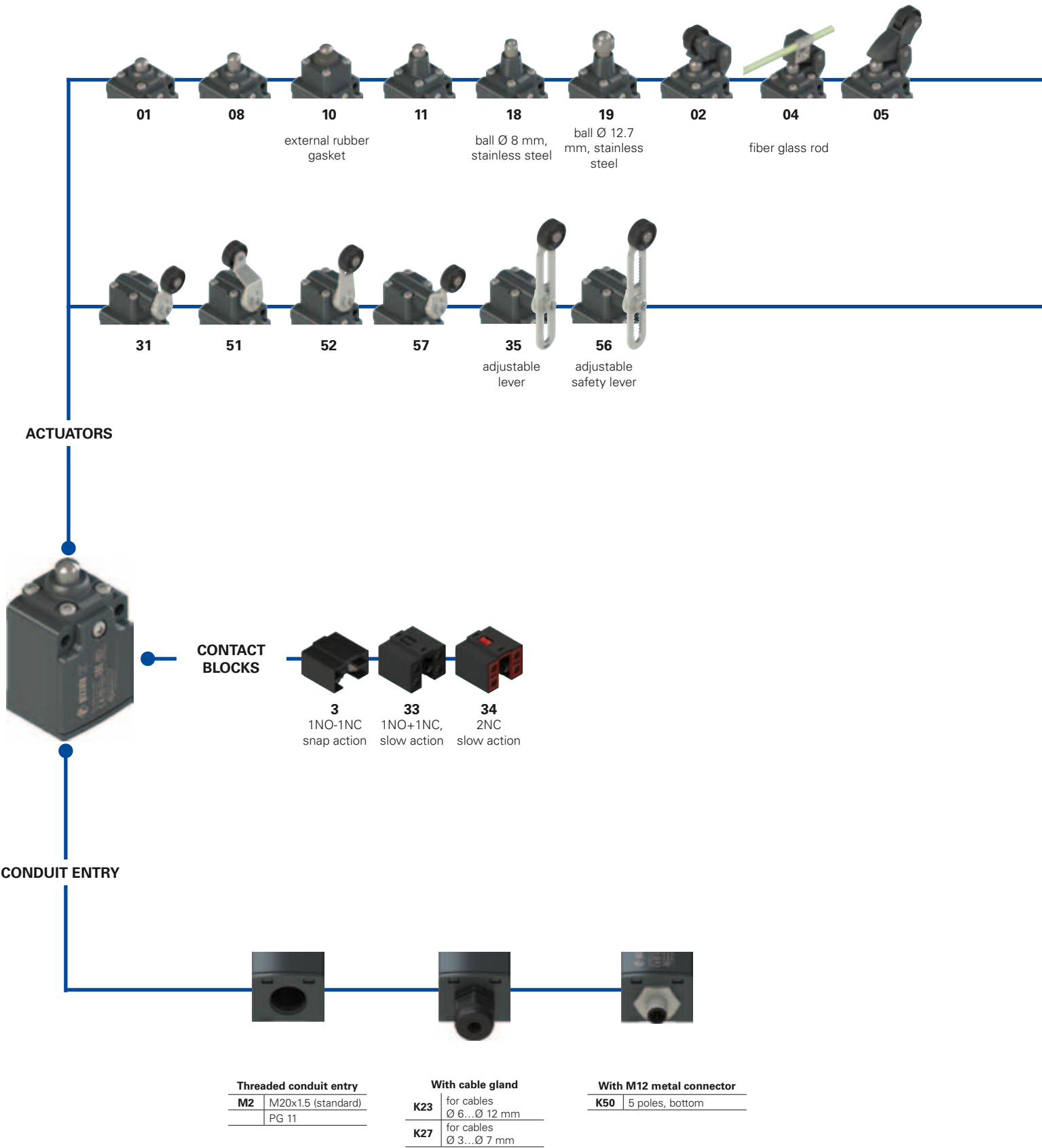


Selection diagram

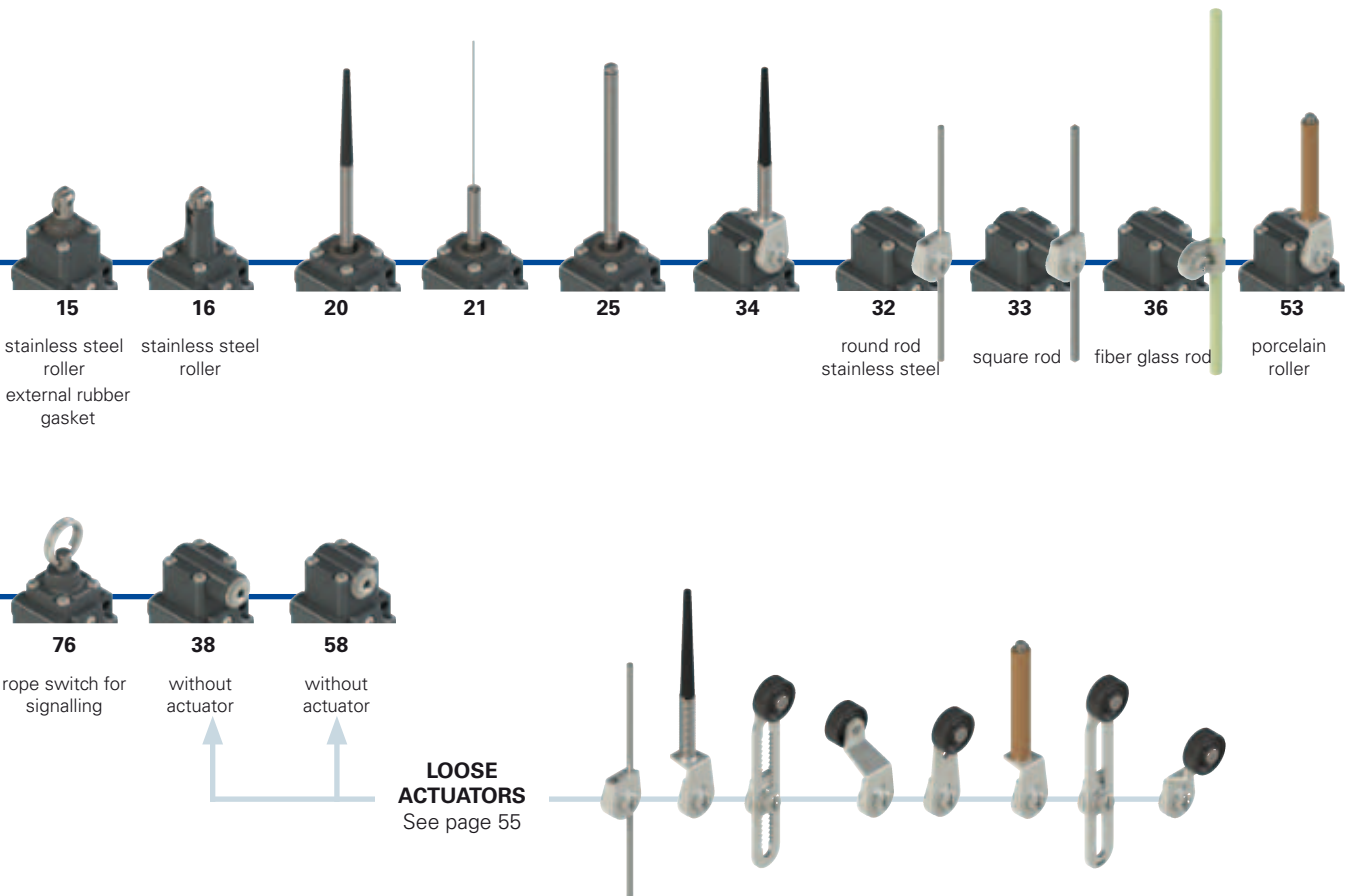

● product options
→ accessory sold separately


Code structure

Attention! The feasibility of a code number does not mean the effective availability of a product. Please contact our sales office.

article options options
FC 302-GM2K50R24T6

Housing	
FC	metal, one conduit entry

Contact blocks	
3	1NO-1NC, snap action
33	1NO+1NC, slow action
34	2NC, slow action

Actuators	
01	short plunger
02	roller lever
05	angled roller lever
...

Contact type	
	silver contacts (standard)
G	silver contacts with 1 µm gold coating (not for contact block 3)

Threaded conduit entry	
M2	M20x1.5 (standard)
	PG11

Ambient temperature	
	-25°C ... +80°C (standard)
T6	-40°C ... +80°C

Rollers	
	standard roller
R24	stainless steel, Ø 20 mm (for actuators 02, 05, 31, 35, 51, 52, 56, 57)
R25	technopolymer, Ø 35 mm (for actuators 31, 35, 51, 52, 56, 57)
R5	rubber, Ø 40 mm (for actuators 31, 35, 51, 52, 56, 57)
R26	rubber, Ø 50 mm (for actuators 31, 35, 51, 52, 56, 57)
R27	rubber, protruding, Ø 50 mm (for actuators 35 e 36)

Pre-installed cable glands	
	without cable gland (standard)
K23	cable gland for cables Ø 6...Ø 12 mm
K27	cable gland for cables Ø 3...Ø 7 mm
K50	M12 metal connector, 5 poles

Please contact our technical service for the complete list of possible combinations.