


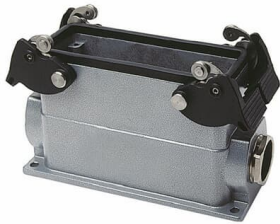

---

**PRODUCT-DETAILS****BB024EH100MV****B24 DBL LVR LKG BX BASE 1XPG29-1**

---

**General Information**

<b>Extended Product Type:</b>	BB024EH100MV
<b>Product ID:</b>	7TAA080030R0023
<b>Catalog Description:</b>	B24 DBL LVR LKG BX BASE 1XPG29-1
<b>Long Description:</b>	Double lever locking box base, 24 contacts with ground connection, NPT entry - 1 Inch x 1 Inch
<b>Display Name:</b>	BB024EH100MV

---

**Ordering**

<b>UPC:</b>	786209984708
<b>Country of Origin:</b>	Germany
<b>Selling Unit of Measure:</b>	each

---

**Container Information**

<b>Package Level 1 Units:</b>	10 EA
-------------------------------	-------

<b>Package Level 1 Width:</b>	256.54 mm 10.1 in
<b>Package Level 1 Height:</b>	160.02 mm 6.3 in
<b>Package Level 1 Depth / Length:</b>	312.42 mm 12.3 in

## Additional Information

<b>Brand / Label:</b>	Pos-E-Kon
<b>Effective Date:</b>	20110717
<b>Material:</b>	Die-Cast Aluminum Alloy
<b>Product Name:</b>	OTHER PARTS F/EQU IN 8535
<b>Standards:</b>	UL e215386, CSA 70013
<b>Surface Finishing:</b>	Epoxy Powder Coated
<b>Voltage Rating:</b>	600 VA °C

## External Classifications and Standards

<b>ETIM 7:</b>	EC000437 - Housing for rectangular connectors
<b>ETIM 8:</b>	EC000437 - Housing for rectangular connectors
<b>ETIM 9:</b>	EC000437 - Housing for rectangular connectors
<b>ETIM 10:</b>	EC000437 - Housing for rectangular connectors
<b>UNSPSC:</b>	39121424
<b>IDEA Granular Category Code (IGCC):</b>	4594 >> Terminal block covers

## Material Compliance

<b>RoHS Information:</b>	Following EU Directive 2011/65/EU and Amendment 2015/863 July 22, 2019
<b>WEEE Category:</b>	Product Not in WEEE Scope

## Categories

Products > Low Voltage Products and Systems > Installation Products > Wire Management and Connectivity > Pin & Sleeve Connectors

