


**AC & DC POWER SUPPLY: 120 VAC TO 24 VAC AND 24 VDC**

**PSH100A24DWB10**

Enclosed Power Supply, 100 VA (120 to 24 Vac) and **Switching** 120 to 24Vdc @ 2.5 Amp

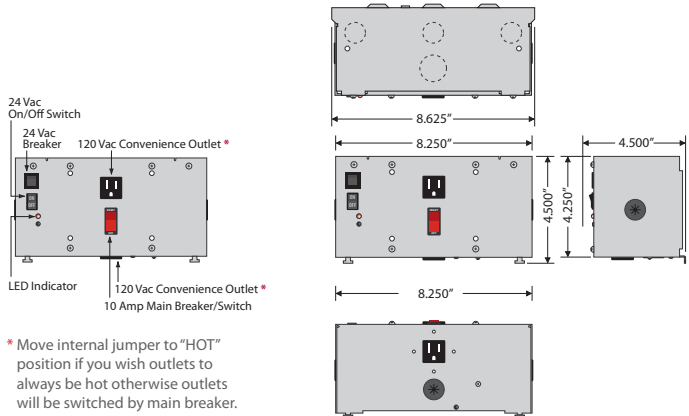

\* Move internal jumper to "HOT" position if you wish outlets to always be hot otherwise outlets will be switched by main breaker.



**SPECIFICATIONS**

- Transformer:** One 100 VA Split-Bobbin
- Voltage Input:** 120 Vac
- Frequency:** 50/60 Hz
- Over Current Protection:** Circuit Breaker
- 24 Vac ON/OFF:** Switch / Breaker (10 Amp)
- Main Breaker ON/OFF:** (Kills power to entire unit: Outlets, Aux. Output, & Transformer, and 24 Vdc)\*
- Dimensions:** 4.500" x 8.625" x 4.500"
- Weight:** 5.600 lbs.

- Input Wires:** Input Power Wires  
 BLK: 120 Vac  
 WHT: Neutral  
 GRN: Ground

- Output Wires:** DC Supply Output  
 WHT/RED: 24 Vdc  
 WHT/BLU: 24 Vdc COM

- Auxiliary Output  
 BLU: 120 Vac

**Notes:**  
 • This device is not certified for use as a Class 2 power source.

- Transformer Output  
 WHT/YEL: 24 Vac  
 WHT/BLU: 24 Vac COM

POWER SUPPLIES