


TRANSFORMER

TR100VA008

Transformer 100 VA, 480/277/240/208 to 120 Vac, Circuit Breaker, Foot and Dual Threaded Hub Mount

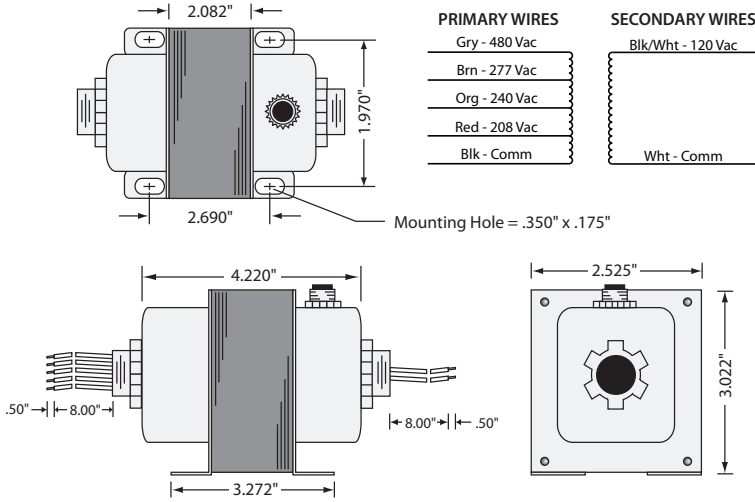

SPECIFICATIONS

- VA Rating:** 100
- Frequency:** 50/60 Hz
- Mounting:** Foot & Dual Threaded Hub
- Over Current Protection:** Circuit Breaker
- Dimensions:** 4.220" x 2.525" x 3.022" (w/ .500" NPT Hubs)
- Wire Length:** 8" Typical w/ .5" Strip
- Operating Temperature:** -30 to 140° F
 - MTBF:** 100,000 Hours @ 77° F
- Construction:** Split-Bobbin
- Weight:** 4.40 lbs.
- Approvals:** UL5085-2 Listed General Purpose, C-UL, CE, RoHS