
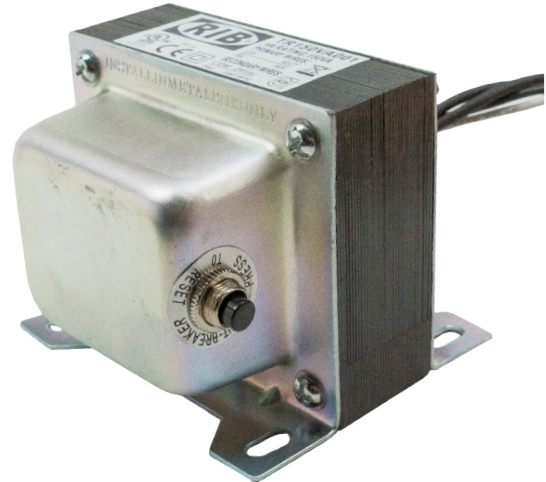


**TRANSFORMER**

**TR150VA001**

Transformer 150 VA, 120 to 24 Vac, Circuit Breaker, Foot and Single Threaded Hub Mount

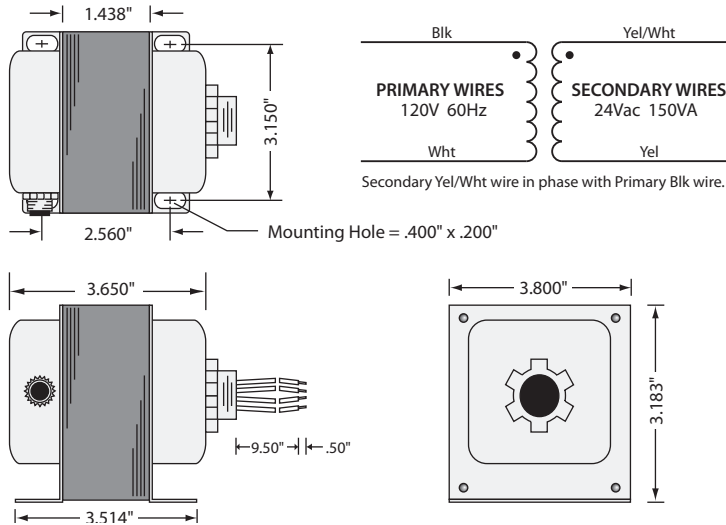

**SPECIFICATIONS**

- VA Rating:** 150
- Frequency:** 50/60 Hz
- Mounting:** Foot & Single Threaded Hub
- Over Current Protection:** Circuit Breaker
- Dimensions:** 3.650" x 3.800" x 3.183" (w/ .500" NPT Hub)
- Wire Length:** 9.5" Typical w/ .5" Strip
- Operating Temperature:** -30 to 140° F
  - MTBF:** 100,000 Hours @ 77° F
- Construction:** Split-Bobbin
- Weight:** 5.00 lbs.
- Approvals:** UL5085-2 Listed General Purpose, C-UL, CE, RoHS

TRANSFORMERS