
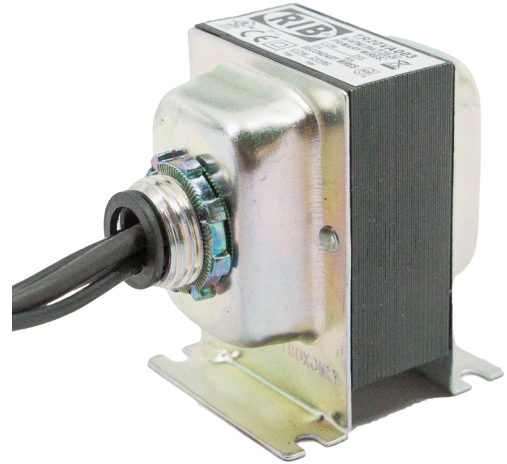


**TRANSFORMER**

**TR20VA003**

Transformer 20 VA, 24 to 24 Vac, Foot and Single Threaded Hub Mount

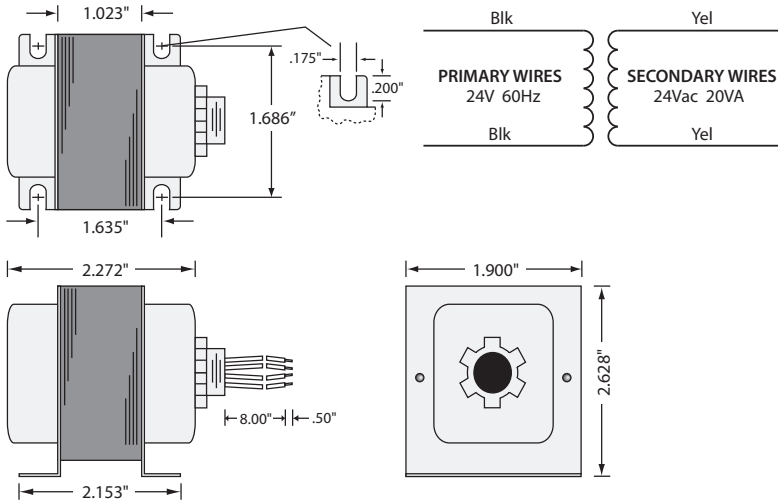

**SPECIFICATIONS**

- VA Rating:** 20
- Frequency:** 50/60 Hz
- Mounting:** Foot & Single Threaded Hub
- Over Current Protection:** Inherently Limited
- Dimensions:** 2.272" x 1.900" x 2.628" (w/ .500" NPT Hub)
- Wire Length:** 8" Typical w/ .5" Strip
- Operating Temperature:** -30 to 140° F
  - MTBF: 100,000 Hours @ 77° F
- Construction:** Split-Bobbin
- Weight:** 1.40 lbs.
- Approvals:** UL5085-2 Listed General Purpose C-UL, CE, RoHS