



**TRANSFORMER**

**TR40VA001US**




Transformer 40 VA, 120 to 24 Vac, Foot and Single Threaded Hub Mount



**Made in USA**  
Meets  
"Buy American"  
of ARRA 2009

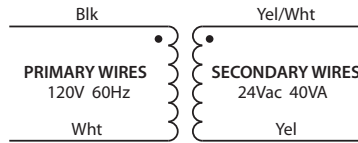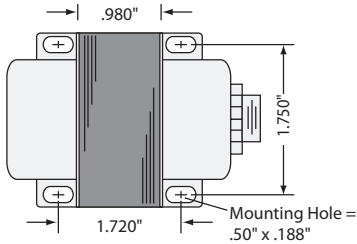

Secondary Yel/Wht wire in phase with Primary Blk wire.

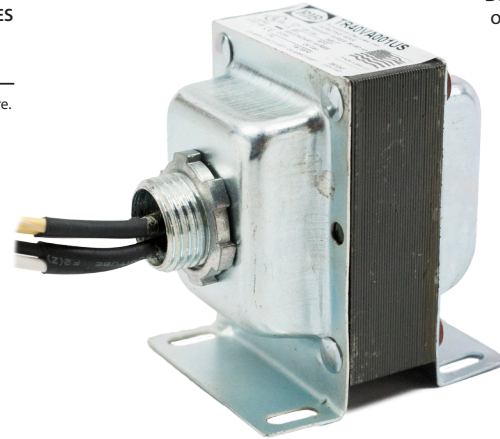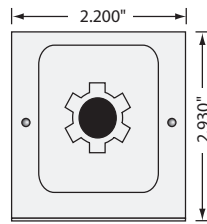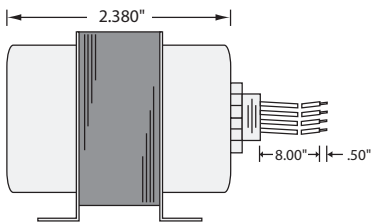

**SPECIFICATIONS**

- VA Rating:** 40
- Frequency:** 50/60 Hz
- Mounting:** Foot & Single Threaded Hub
- Over Current Protection:** Inherently Limited
- Dimensions:** 2.380" x 2.200" x 2.930" (w/ .500" NPT Hub)
- Wire Length:** 8" Typical w/ .5" Strip
- Operating Temperature:** -30 to 140° F
- MTBF:** 100,000 Hours @ 77° F
- Construction:** Split-Bobbin
- Weight:** 1.80 lbs.
- Approvals:** Class 2 UL5085-3 Listed, C-UL, CE, RoHS