



**TRANSFORMER**

**TR40VA002US**

Transformer 40 VA, 120 to 24 Vac, Foot and Dual Threaded Hub Mount



**Made in USA**  
Meets  
"Buy American"  
of ARRA 2009

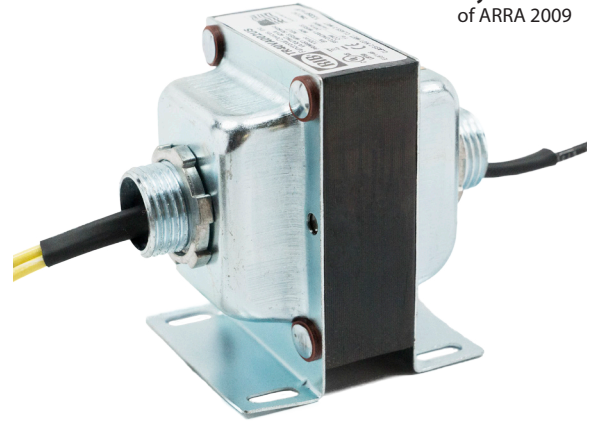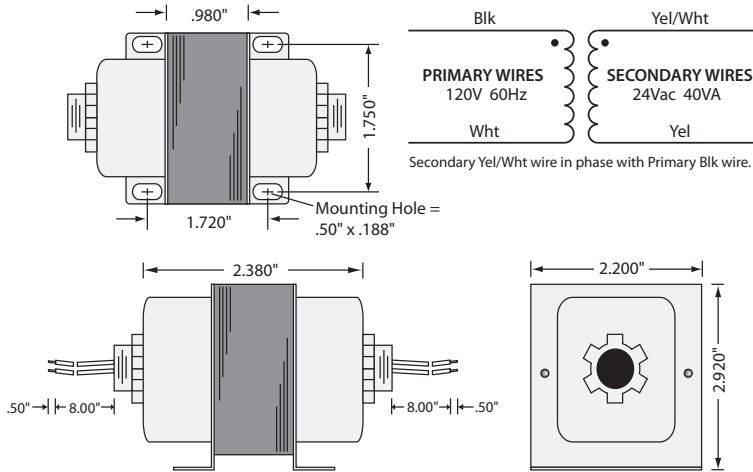

**SPECIFICATIONS**

- VA Rating:** 40
- Frequency:** 50/60 Hz
- Mounting:** Foot & Dual Threaded Hubs
- Over Current Protection:** Inherently Limited
- Dimensions:** 2.380" x 2.200" x 2.920" (w/ .500" NPT Hubs)
- Wire Length:** 8" Typical w/ .5" Strip
- Operating Temperature:** -30 to 140° F
  - MTBF:** 100,000 Hours @ 77° F
- Construction:** Split-Bobbin
- Weight:** 1.80 lbs.
- Approvals:** Class 2 UL5085-3 Listed, C-UL, CE, RoHS

TRANSFORMERS