
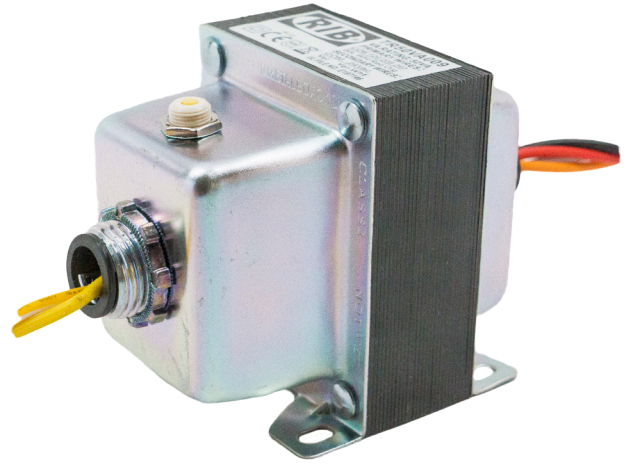


**TRANSFORMER**

**TR50VA009**

Transformer 50 VA, 240/208/120 to 24 Vac, Circuit Breaker, Foot and Dual Threaded Hub Mount

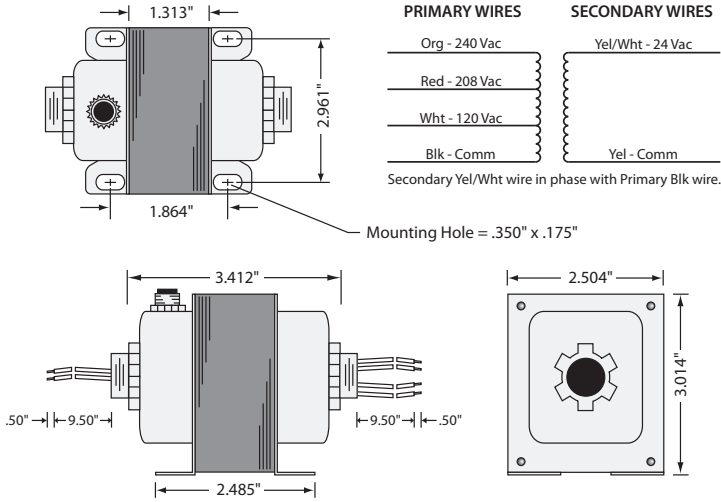

**SPECIFICATIONS**

- VA Rating:** 50
- Frequency:** 50/60 Hz
- Mounting:** Foot & Dual Threaded Hubs
- Over Current Protection:** Circuit Breaker
- Dimensions:** 3.412" x 2.504" x 3.014" (w/ .500" NPT Hubs)
- Wire Length:** 9.5" Typical w/ .5" Strip
- Operating Temperature:** -30 to 140° F
  - MTBF: 100,000 Hours @ 77° F
- Construction:** Split-Bobbin
- Weight:** 2.80 lbs.
- Approvals:** Class 2 UL5085-3 Listed, C-UL, CE, RoHS

TRANSFORMERS