





**TRANSFORMER**

**TR50VA022US**

Transformer 50 VA, 480/277/240/208/120 to 24 Vac, Circuit Breaker, Foot and Dual Threaded Hub Mount



**Made in USA**  
Meets  
"Buy American"  
of ARRA 2009

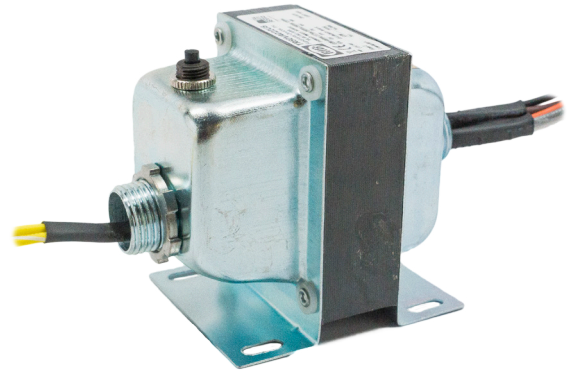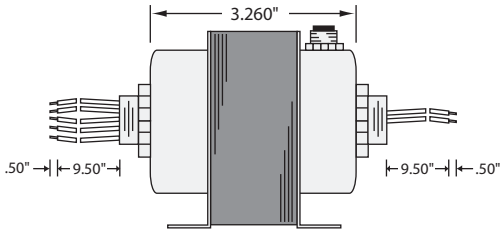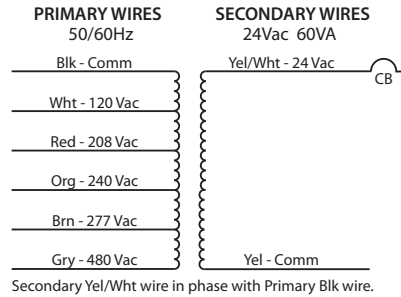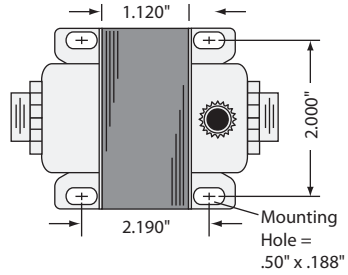

**SPECIFICATIONS**

- VA Rating:** 50
- Frequency:** 50/60 Hz
- Mounting:** Foot & Dual Threaded Hubs
- Over Current Protection:** Circuit Breaker
- Dimensions:** 3.260" x 2.525" x 3.290" (w/ .500" NPT Hubs)
- Wire Length:** 9.5" Typical w/ .5" Strip
- Operating Temperature:** -30 to 140° F
- MTBF:** 100,000 Hours @ 77° F
- Construction:** Split-Bobbin
- Weight:** 2.65 lbs.
- Approvals:** Class 2 UL5085-3 Listed, C-UL, CE, RoHS

TRANSFORMERS