

## Relay


### Contact Ratings

10 Amps @ 30VDC/240VAC  
 General Purpose  
 1.5 Amps @ 120 VAC  
 Inductive (Cos $\phi$ =0.35)  
 1HP @ 240VAC Motor  
 1/2HP @ 120VAC, Motor

### Specifications

Pick-Up Voltage: 75% of Rated Voltage  
 Drop-Out Voltage:  
     30% of rated AC Voltage  
     10% of rated DC Voltage  
 Max. Voltage: 110% of rated Voltage  
 Operating Time:  $\leq$ 20 milliseconds  
 Coil Power:  
      $\leq$ 1.6VA 50Hz  
      $\leq$ 1.5VA 60Hz  
      $\leq$ 1.0W DC  
 Temperature Rating: -10°C to 40°C  
 Contact Material:  
     Silver Cadmium Oxide (AgCdO)  
 Contact Resistance:  
     <0.050Ohms (before use)  
 Minimum Operating Current:  
     5mA@24VDC  
 Life: Mechanical:  
     50,000,000 Operations  
     Electrical: 1,300,000 Operations

### Ordering Information

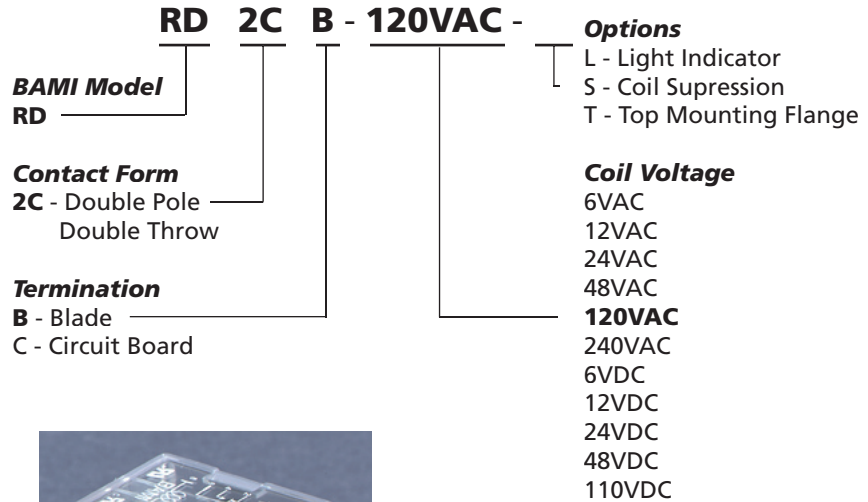


## Socket



### Specifications

Current Rating: 10 Amps  
 Voltage Rating: 250VAC  
 Mounting: DIN or Surface

### Connections

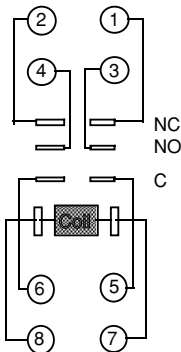

### Dimensions

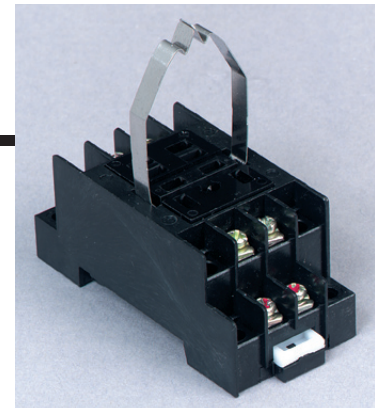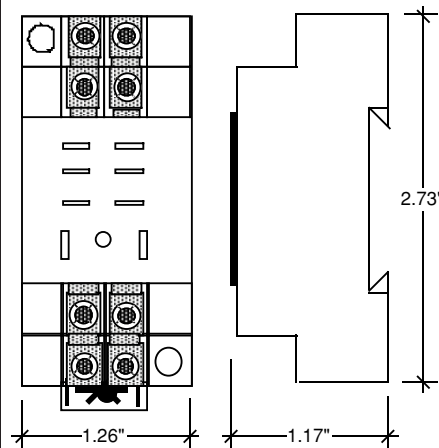

### Ordering Information

