



"Ice Cube" Relays and Sockets

BAMI

RG/SG

Relay

Contact Ratings

- 5 Amps @ 30VDC/240VAC
Double Pole, Gen. Purpose
- 3 Amps @ 30VDC/240VAC
Four Pole, General Purpose
- 1 Amps @ 120 VAC
Inductive (CosØ=.35)
- 1/4HP @ 240VAC Motor


Specifications

- Pick-Up Voltage: 75% of Rated Voltage
- Drop-Out Voltage:
30% of rated AC Voltage
10% of rated DC Voltage
- Max. Voltage: 110% of rated Voltage
- Operating Time: 20 milliseconds
- Coil Power:
1.9VA 50Hz
1.7VA 60Hz
1.2W DC
- Temperature Rating: -10°C to 40°C
- Contact Material: Silver (Ag)
- Contact Resistance:
<0.050 Ohms (before use)
- Minimum Operating Current:
5mA@24VDC
- Life: Mechanical:
50,000,000 Operations
- Electrical:
600,000 Operations

Ordering Information

RG 4C B - 120VAC -

<p>BAMI Model RG</p> <p>Contact Form 2C - Double Pole Double Throw 4C - Four Pole Double Throw</p> <p>Termination B - Blade C - Circuit Board</p>	<p>Options L - Light Indicator S - Coil Suppression T - Top Mounting Flange</p> <p>Coil Voltage 6VAC 12VAC 24VAC 48VAC 120VAC 240VAC 6VDC 12VDC 24VDC 48VDC 110VDC</p>
--	---

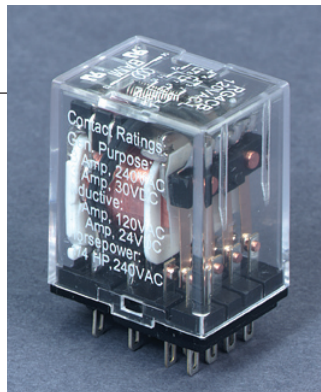


Socket



Specifications

- Current Rating: 5 Amps
- Voltage Rating: 250VAC
- Mounting: DIN or Surface

Dimensions

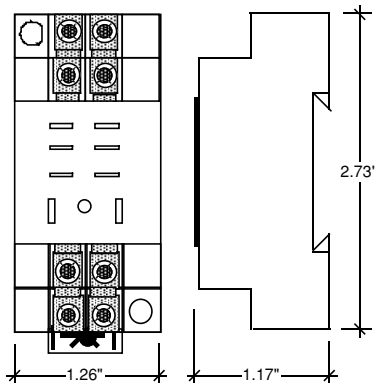

Connections

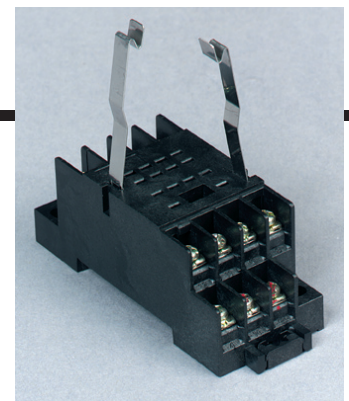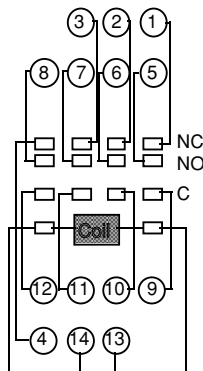

Ordering Information

SG - 14 B

<p>BAMI Model SG</p> <p>Number of Terminals 14 - 14 Terminals</p>	<p>Termination B - Blade C - Circuit Board</p>
---	---