


Rigid/Aluminum Conduit Bodies, Gaskets and Covers

Aluminum Conduit Bodies, Covers and Gaskets — B Series (continued)

T Style

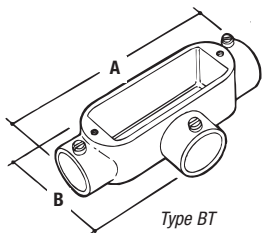

CAT. NO.	TRADE SIZE	A	B	STD. CTN.
BT-1	1/2"	3 3/8"	2 1/16"	50
BT-2	3/4"	4 3/8"	2 1/8"	50
BT-3	1"	5 3/8"	2 3/8"	25
BT-4	1 1/4"	7 1/4"	3 1/8"	10
BT-5	1 1/2"	7 3/4"	3 1/2"	10
BT-6	2"	9 1/2"	4"	5
BT-7*	2 1/2"	12 1/4"	5 5/8"	1
BT-8*	3"	12 1/2"	5 7/8"	1
BT-9*	3 1/2"	15"	6 3/8"	1
BT-10*	4"	15"	6 3/8"	1

* Threaded Hubs shipped with cover.

Price includes cost of cover and body.

UL® File No. E-28688.

Aluminum Covers with Stainless Steel Screws

- SCV = Stamped aluminum
- CV = Die cast aluminum
- Steel zinc plated screws



CAT. NO.	CONDUIT SIZE	STD. CTN.
CV-1	1/2"	250
CV-2	3/4"	250
CV-3	1"	250
CV-4	1 1/4"–1 1/2"	50
CV-5	2"	25
CV-6	2 1/2"–3"	5
CV-7	3 1/2"–4"	5
SCV-1	1/2"	250
SCV-2	3/4"	250
SCV-3	1"	250
SCV-4	1 1/4"–1 1/2"	250
SCV-5	2"	100

UL® File No. E-28688.

Gaskets — Composition



Fiber Gasket

CAT. NO.	CONDUIT SIZE	STD. CTN.
GKV-1	1/2"	100
GKV-2	3/4"	50
GKV-3	1"	25
GKV-4	1 1/4"–1 1/2"	25
GKV-5	2"	25
GKV-6	2 1/2"–3"	5
GKV-7	3 1/2"–4"	5

Gaskets — Neoprene

- Fiber or neoprene material



Neoprene Gasket

CAT. NO.	CONDUIT SIZE	STD. CTN.
GKN-1	1/2"	100
GKN-2	3/4"	50
GKN-3	1"	25
GKN-4	1 1/4"–1 1/2"	25
GKN-5	2"	25
GKN-6	2 1/2"–3"	5
GKN-7	3 1/2"–4"	5