


COMPONENT PART NUMBERS

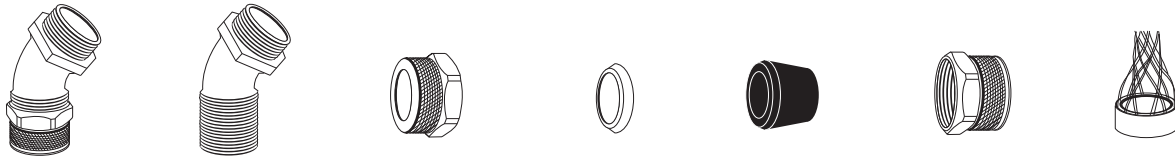

CORD CONNECTORS

WIRE MESH GRIPS

PICO-LINK

MICRO-LINK

ETHERLINK

MINI-LINK

MULTI-PORT BOXES

BUS SYSTEM PRODUCTS

| Cord Grip Less Bushing | Body Only | Nut Only** | Washer Only | Bushing Only | Nut for Mesh Only | Mesh Only |
|------------------------|-------------|------------|-------------|--------------|-------------------|-----------|
| RSR-45100-W | RSR-45100-B | RSR-100-N | SW-100 | SRB-103 | *** | *** |
| RSR-45100-W | RSR-45100-B | RSR-100-N | SW-100 | SRB-104 | RSR-100-ND | R-104-D |
| RSR-45100-W | RSR-45100-B | RSR-100-N | SW-100 | SRB-105 | RSR-100-ND | R-106-D |
| RSR-45100-W | RSR-45100-B | RSR-100-N | SW-100 | SRB-106 | RSR-100-ND | R-106-D |
| RSR-45100-W | RSR-45100-B | RSR-100-N | SW-100 | SRB-107 | RSR-100-ND | R-108-D |
| RSR-45100-W | RSR-45100-B | RSR-100-N | SW-100 | SRB-108 | RSR-100-ND | R-108-D |
| RSR-45100-W | RSR-45100-B | RSR-100-N | SW-100 | SRB-109 | RSR-100-ND | R-110-D |
| RSR-45100-W | RSR-45100-B | RSR-100-N | SW-100 | SRB-110* | RSR-100-ND | R-110-D |
| RSR-45200-W | RSR-45200-B | RSR-200-N | SW-200 | SRB-208 | RSR-200-ND | R-210-D |
| RSR-45200-W | RSR-45200-B | RSR-200-N | SW-200 | SRB-209 | RSR-200-ND | R-210-D |
| RSR-45200-W | RSR-45200-B | RSR-200-N | SW-200 | SRB-210 | RSR-200-ND | R-210-D |
| RSR-45200-W | RSR-45200-B | RSR-200-N | SW-200 | SRB-211 | RSR-200-ND | R-212-D |
| RSR-45200-W | RSR-45200-B | RSR-200-N | SW-200 | SRB-212 | RSR-200-ND | R-212-D |
| RSR-45200-W | RSR-45200-B | RSR-200-N | SW-200 | SRB-213* | RSR-200-ND | R-214-D |
| RSR-45300-W | RSR-45300-B | RSR-300-N | SW-300 | SRB-309 | RSR-300-ND2 | R-210-D |
| RSR-45300-W | RSR-45300-B | RSR-300-N | SW-300 | SRB-310 | RSR-300-ND2 | R-210-D |
| RSR-45300-W | RSR-45300-B | RSR-300-N | SW-300 | SRB-311 | RSR-300-ND2 | R-212-D |
| RSR-45300-W | RSR-45300-B | RSR-300-N | SW-300 | SRB-312 | RSR-300-ND2 | R-212-D |
| RSR-45300-W | RSR-45300-B | RSR-300-N | SW-300 | SRB-313 | RSR-300-ND | R-314-D |
| RSR-45300-W | RSR-45300-B | RSR-300-N | SW-300 | SRB-314 | RSR-300-ND | R-314-D |
| RSR-45300-W | RSR-45300-B | RSR-300-N | SW-300 | SRB-315 | RSR-300-ND | R-316-D |
| RSR-45300-W | RSR-45300-B | RSR-300-N | SW-300 | SRB-316 | RSR-300-ND | R-316-D |
| RSR-45400-W | RSR-45400-B | RSR-500-N | SW-500 | SRB-511 | *** | *** |
| RSR-45400-W | RSR-45400-B | RSR-500-N | SW-500 | SRB-513 | *** | *** |
| RSR-45400-W | RSR-45400-B | RSR-500-N | SW-500 | SRB-514 | RSR-500-ND | R-516-D |
| RSR-45400-W | RSR-45400-B | RSR-500-N | SW-500 | SRB-516 | RSR-500-ND | R-516-D |
| RSR-45400-W | RSR-45400-B | RSR-500-N | SW-500 | SRB-518 | RSR-500-ND | R-518-D |
| RSR-45400-W | RSR-45400-B | RSR-500-N | SW-500 | SRB-520 | RSR-500-ND | R-520-D |
| RSR-45400-W | RSR-45400-B | RSR-500-N | SW-500 | SRB-522* | RSR-500-ND | R-522-D |
| RSR-45500-W | RSR-45500-B | RSR-500-N | SW-500 | SRB-511 | *** | *** |
| RSR-45500-W | RSR-45500-B | RSR-500-N | SW-500 | SRB-513 | *** | *** |
| RSR-45500-W | RSR-45500-B | RSR-500-N | SW-500 | SRB-514 | RSR-500-ND | R-516-D |
| RSR-45500-W | RSR-45500-B | RSR-500-N | SW-500 | SRB-516 | RSR-500-ND | R-516-D |
| RSR-45500-W | RSR-45500-B | RSR-500-N | SW-500 | SRB-518 | RSR-500-ND | R-518-D |
| RSR-45500-W | RSR-45500-B | RSR-500-N | SW-500 | SRB-520 | RSR-500-ND | R-520-D |
| RSR-45500-W | RSR-45500-B | RSR-500-N | SW-500 | SRB-522 | RSR-500-ND | R-522-D |

**Nuts sold as components are marked UL/CSA

***Contact Remke for mesh availability of this part number

