


	Length	Wire Gauge (AWG)	Straight Plug Non-Braided	Straight Plug Braided*	90° Plug Non-Braided	90 Plug Braided*	Mating Male Receptacle
	2M/6.6 FT.	#22 (PVC)	303A0066J	303A0066H	303C0066J	303C0066H	303P0010P
	4M/13.1 FT.	#22 (PVC)	303A0131J	303A0131H	303C0131J	303C0131H	303P0010P
	5M/16.4 FT.	#22 (PVC)	303A0164J	303A0164H	303C0164J	303C0164H	303P0010P
	2M/6.6 FT.	#22 (PVC)	304A0066J	304A0066H	304C0066J	304C0066H	304P0010P
	4M/13.1 FT.	#22 (PVC)	304A0131J	304A0131H	304C0131J	304C0131H	304P0010P
	5M/16.4 FT.	#22 (PVC)	304A0164J	304A0164H	304C0164J	304C0164H	304P0010P
	2M/6.6 FT.	#22 (PVC)	305A0066J	305A0066H	305C0066J	305C0066H	305P0010P
	4M/13.1 FT.	#22 (PVC)	305A0131J	305A0131H	305C0131J	305C0131H	305P0010P
	5M/16.4 FT.	#22 (PVC)	305A0164J	305A0164H	305C0164J	305C0164H	305P0010P

	Length	Wire Gauge (AWG)	Straight Plug Non-Braided	Straight Plug Braided*	90° Plug Non-Braided	90 Plug Braided*	Mating Female Receptacle
	2M/6.6 FT.	#22 (PVC)	303E0066J	303E0066H	303F0066J	303F0066H	303S0010P
	4M/13.1 FT.	#22 (PVC)	303E0131J	303E0131H	303F0131J	303F0131H	303S0010P
	5M/16.4 FT.	#22 (PVC)	303E0164J	303E0164H	303F0164J	303F0164H	303S0010P
	2M/6.6 FT.	#22 (PVC)	304E0066J	304E0066H	304F0066J	304F0066H	304S0010P
	4M/13.1 FT.	#22 (PVC)	304E0131J	304E0131H	304F0131J	304F0131H	304S0010P
	5M/16.4 FT.	#22 (PVC)	304E0164J	304E0164H	304F0164J	304F0164H	304S0010P
	2M/6.6 FT.	#22 (PVC)	305E0066J	305E0066H	305F0066J	305F0066H	305S0010P
	4M/13.1 FT.	#22 (PVC)	305E0131J	305E0131H	305F0131J	305F0131H	305S0010P
	5M/16.4 FT.	#22 (PVC)	305E0164J	305E0164H	305F0164J	305F0164H	305S0010P




Length	Wire Gauge (AWG)	Straight Plug Non-Braided	Straight Plug Braided*	90° Plug Non-Braided	90 Plug Braided*	Mating Male Receptacle
2M/6.6 FT.	#22 (PUR)	503A0066L	503A0066AL	503C0066L	503C0066AL	303P0010P
4M/13.1 FT.	#22 (PUR)	503A0131L	503A0131AL	503C0131L	503C0131AL	303P0010P
5M/16.4 FT.	#22 (PUR)	503A0164L	503A0164AL	503C0164L	503C0164AL	303P0010P
2M/6.6 FT.	#22 (PUR)	504A0066L	504A0066AL	504C0066L	504C0066AL	304P0010P
4M/13.1 FT.	#22 (PUR)	504A0131L	504A0131AL	504C0131L	504C0131AL	304P0010P
5M/16.4 FT.	#22 (PUR)	504A0164L	504A0164AL	504C0164L	504C0164AL	304P0010P
2M/6.6 FT.	#22 (PUR)	505A0066L	505A0066AL	505C0066L	505C0066AL	305P0010P
4M/13.1 FT.	#22 (PUR)	505A0131L	505A0131AL	505C0131L	505C0131AL	305P0010P
5M/16.4 FT.	#22 (PUR)	505A0164L	505A0164AL	505C0164L	505C0164AL	305P0010P


Length	Wire Gauge (AWG)	Straight Plug Non-Braided	Straight Plug Braided*	90° Plug Non-Braided	90 Plug Braided*	Mating Female Receptacle
2M/6.6 FT.	#22 (PUR)	503E0066L	503E0066AL	503F0066L	503F0066AL	303S0010P
4M/13.1 FT.	#22 (PUR)	503E0131L	503E0131AL	503F0131L	503F0131AL	303S0010P
5M/16.4 FT.	#22 (PUR)	503E0164L	503E0164AL	503F0164L	503F0164AL	303S0010P
2M/6.6 FT.	#22 (PUR)	504E0066L	504E0066AL	504F0066L	504F0066AL	304S0010P
4M/13.1 FT.	#22 (PUR)	504E0131L	504E0131AL	504F0131L	504F0131AL	304S0010P
5M/16.4 FT.	#22 (PUR)	504E0164L	504E0164AL	504F0164L	504F0164AL	304S0010P
2M/6.6 FT.	#22 (PUR)	505E0066L	505E0066AL	505F0066L	505F0066AL	305S0010P
4M/13.1 FT.	#22 (PUR)	505E0131L	505E0131AL	505F0131L	505F0131AL	305S0010P
5M/16.4 FT.	#22 (PUR)	505E0164L	505E0164AL	505F0164L	505F0164AL	305S0010P

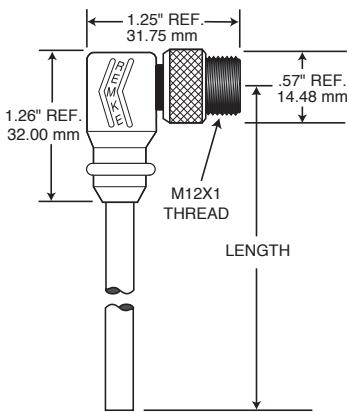

MALE 90°

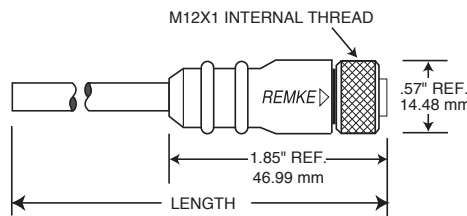

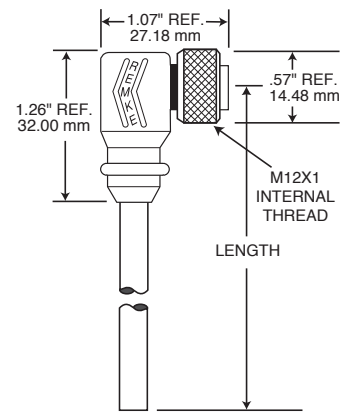


FEMALE STRAIGHT



FEMALE 90°






## MALE

RECEPTACLE PART NUMBERS					
Number of Poles	Male Contact Rotation	Wiring Color Code	Wire Gauge (AWG)	1/2" NPT (Fig. A)	M14 x 1 (Fig. B)
3		1-Brown 2-Not Used 3-Blue 4-Black	#22 (PVC)	303P0010P	303T0010P
4		1-Brown 2-White 3-Blue 4-Black	#22 (PVC)	304P0010P	304T0010P
5		1-Brown 2-White 3-Blue 4-Black 5-Gray	#22 (PVC)	305P0010P	305T0010P

## NOTES:

Add Suffix 'N' for #18 AWG | Add Suffix 'AS' for #24/1C PVC.

## FEMALE

RECEPTACLE PART NUMBERS					
Number of Poles	Female Contact Rotation	Wiring Color Code	Wire Gauge (AWG)	1/4" NPT (Fig. C)	Back Panel Mount (#18 AWG) (Fig. D)
3		1-Brown 2-Not Used 3-Blue 4-Black	#22 (PVC)	303S0010P	303W0010N
4		1-Brown 2-White 3-Blue 4-Black	#22 (PVC)	304S0010P	304W0010N
5		1-Brown 2-White 3-Blue 4-Black 5-Gray	#22 (PVC)	305S0010P	305W0010N

## NOTES:

Add Suffix 'AS' for #24/1C PVC.

